


Rectangular shank to CoroTurn® SL adapter

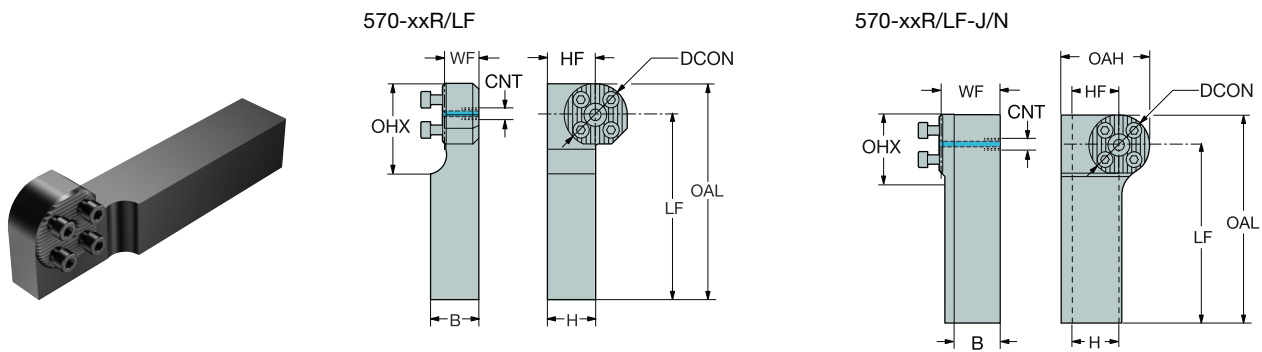

Metric version

CZC _{MS}	CZC _{WS}	OHX	CNSC	Ordering code	Dimensions												CP BarPSI	Kg
					DCON	B	H	LF	WF	HF	OAH	RADH	RADW	CNT				
20 x 20	25	25	2	570-25R/LF-2020	25	20	20	94	15	20		20	15	G1/8"	70	0.3		
	32	29	2	570-32R/LF-2020	32	20	20	97	18	20		20	18	G1/8"	70	0.4		
	32	26	2	570-32R/LF-2020J	32	20	20	97	27	20	36	20	27	G1/8"	70	0.6		
25 x 25	25	26	2	570-25R/LF-2525	25	25	25	119	18	25		25	18	G1/8"	70	0.6		
	32	32	2	570-32R/LF-2525	32	25	25	115	18	25		25	18	G1/8"	70	0.6		
	32	25	2	570-32R/LF-2525N	32	25	25	119	32	25	47	25	32	G1/8"	70	0.6		
40	30	2	570-40R/LF-2525N	40	25	25	111	32	25	51	25	32	G1/8"	70	0.8			
	32	30	2	570-32R/LF-3232	32	32	32	135	26	32		32	26	G1/8"	70	1.2		
32 x 32	32	30	2	570-32R/LF-3232	32	32	32	135	26	32		32	26	G1/8"	70	1.2		
	40	36	2	570-40R/LF-3232	40	32	32	134	26	32		32	26	G1/8"	70	1.3		

Inch version

CZC _{MS}	CZC _{WS}	OHX	CNSC	Ordering code	Dimensions, inch												CP BarPSI	Lbs
					DCON	B	H	LF	WF	HF	OAH	RADH	RADW	CNT				
3/4 x 3/4	25	.984	2	570-25R/LF-12	.984	.750	.750	3.785	.591	.750		.750	.591	1/8-27 NPSF	1015	0.6		
	32	1.102	2	570-32R/LF-12	1.260	.750	.750	3.844	.709	.750		.750	.709	1/8-27 NPSF	1015	0.8		
	32	.984	2	570-32R/LF-12J	1.260	.750	.750	3.923	1.045	.750	1.629	.750	1.045	G1/8"	1015	1.4		
1 x 1	25	1.024	2	570-25R/LF-16	.984	1.000	1.000	4.803	.709	1.000		1.000	.709	1/8-27 NPSF	1015	1.5		
	32	1.260	2	570-32R/LF-16	1.260	1.000	1.000	4.648	.709	1.000	1.630	1.000	.709	1/8-27 NPSF	1015	1.4		
	32	.984	2	570-32R/LF-16N	1.260	1.000	1.000	4.648	1.295	1.000	1.879	1.000	1.295	G1/8"	1015	1.4		
40	30	1.181	2	570-40R/LF-16N	1.575	1.000	1.000	4.478	1.295	1.000	2.047	1.000	1.295	G1/8"	1015	1.7		
	32	1.220	2	570-32R/LF-20	1.260	1.250	1.250	5.648	1.024	1.250		1.250	1.024	1/8-27 NPSF	1015	2.8		
1 1/4 x 1 1/4	32	1.220	2	570-32R/LF-20	1.260	1.250	1.250	5.648	1.024	1.250		1.250	1.024	1/8-27 NPSF	1015	2.8		
	40	1.181	2	570-40R/LF-20	1.575	1.250	1.250	5.382	1.024	1.250		1.250	1.024	1/8-27 NPSF	1015	3.3		

To correspond with coupling size, CZC_{WS} for respective CoroCut® SL and T-Max Q-Cut® SL blades.
 Right 0° fits left hand blade, right 45° fits right hand blade.
 Left and right 90° fit both left and right hand blade.
 Neutral 90° fits both left and right hand blade.

J or N in code = reinforced adapter with increased support areas. No coolant through possible.

N = Neutral, R = Right hand, L = Left hand

