


GPYパッキン

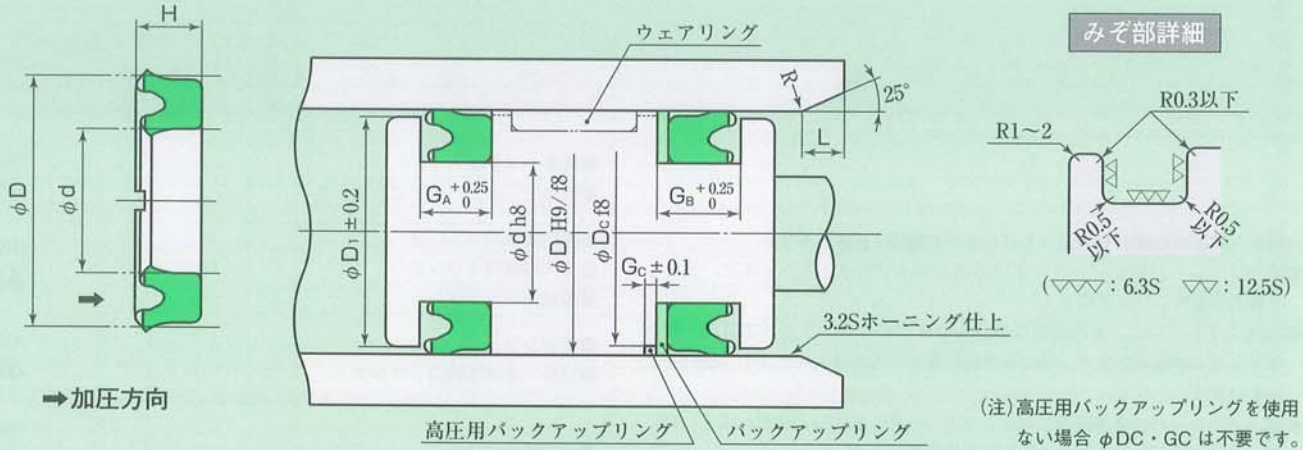

GPYパッキン寸法表

単位：mm

呼び番号 標準(RN 919)	パッキンおよびみぞ寸法									併用標準バック 呼び番号	併用高圧バック 呼び番号
	D	d	H	GA	GB	GC	D ₁	D _c	L		
GPY- 32 22 6.2	32	22	6.2	7	9	2.5	31	28	4		
GPY- 40	40	30	6.2	7	9	2.5	39	36	4	TC-GPY- 40	PE-GPY- 40
GPY- 45	45	35	6.2	7	9	2.5	44	41	4	TC-GPY- 45	PE-GPY- 45
GPY- 50	50	40	6.2	7	9	2.5	49	46	4	TC-GPY- 50	PE-GPY- 50
GPY- 55	55	45	6.2	7	9	2.5	54	51	4	TC-GPY- 55	PE-GPY- 55
GPY- 60	60	50	6.2	7	9	2.5	59	56	4	TC-GPY- 60	PE-GPY- 60
GPY- 63	63	53	6.2	7	9	2.5	62	59	4	TC-GPY- 63	PE-GPY- 63
GPY- 65	65	52	7.7	8.5	11	3	63.5	59	5	TC-GPY- 65	PE-GPY- 65
GPY- 70	70	57	7.7	8.5	11	3	68.5	64	5	TC-GPY- 70	PE-GPY- 70
GPY- 75	75	62	7.7	8.5	11	3	73.5	69	5	TC-GPY- 75	PE-GPY- 75
GPY- 80	80	65	9.2	10	12.5	3	78.5	74	5	TC-GPY- 80	PE-GPY- 80
GPY- 85	85	70	9.2	10	12.5	3	83.5	79	5	TC-GPY- 85	PE-GPY- 85
GPY- 95	90	75	9.2	10	12.5	3	88.5	84	5	TC-GPY- 90	PE-GPY- 90
GPY- 100	100	80	12	13	16	3.5	98	93	6	TC-GPY- 100	PE-GPY- 100
GPY- 110	110	90	12	13	16	3.5	108	103	6	TC-GPY- 110	PE-GPY- 110
GPY- 120	120	100	12	13	16	3.5	118	113	6	TC-GPY- 120	PE-GPY- 120
GPY- 125	125	105	12	13	16	3.5	123	118	6	TC-GPY- 125	PE-GPY- 125
GPY- 130	130	110	12	13	16	3.5	128	123	6	TC-GPY- 130	PE-GPY- 130
GPY- 140	140	120	12	13	16	3.5	138	133	6	TC-GPY- 140	PE-GPY- 140
GPY- 150	150	125	16	17	20	4	148	142	7	TC-GPY- 150	PE-GPY- 150
GPY- 160	160	135	16	17	20	4	158	152	7	TC-GPY- 160	PE-GPY- 160
GPY- 180	180	155	16	17	20	4	178	172	7	TC-GPY- 180	PE-GPY- 180
GPY- 200	200	175	16	17	20	4	198	192	7	TC-GPY- 200	PE-GPY- 200
GPY- 250	250	225	16	17	20	4	248	242	7	TC-GPY- 250	PE-GPY- 250

★ご注文・お問い合わせは、呼び番号にてご指示下さい。

★表中・呼び番号が色地のものは、在庫しております。

呼び番号 誤記訂正

【誤】 GPY-95 【正】 GPY-90