


GNYパッキン

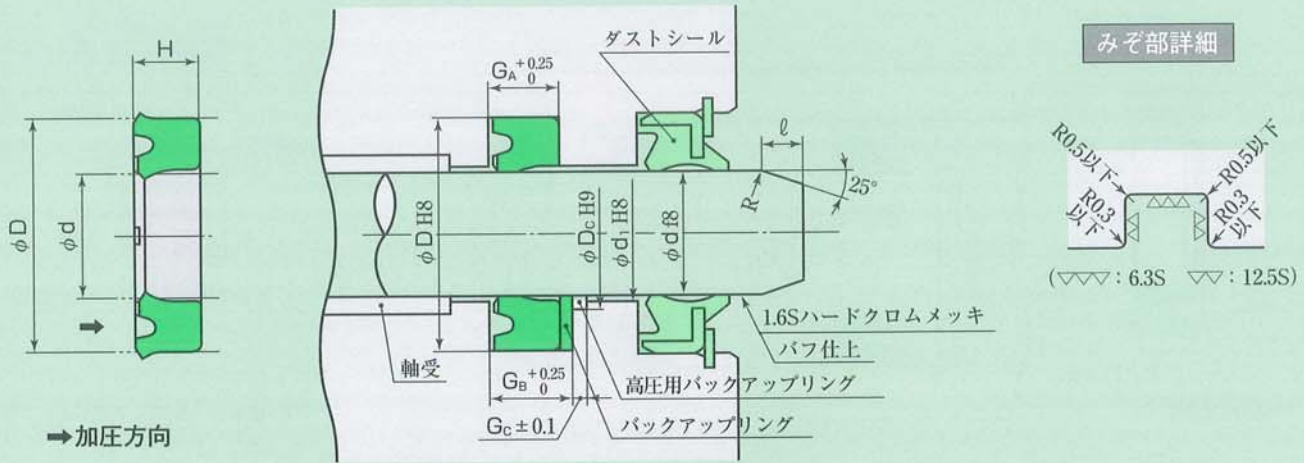

GNYパッキン寸法表

単位: mm

呼び番号 標準(RN 919)	パッキンおよびみぞ寸法									併用標準バック 呼び番号	併用高圧バック 呼び番号
	d	D	H	GA	GB	GC	DC	d ₁ (参考)	ℓ		
GNY- 18	18	26	5	6	7.5	2	21	18.5	3.5	TC-GNY- 18	PE-GNY- 18
GNY- 20	20	28	5	6	7.5	2	23	20.5	3.5	TC-GNY- 20	PE-GNY- 20
GNY- 22	22	30	5	6	7.5	2	25	22.5	3.5	TC-GNY- 22	PE-GNY- 22
GNY- 25	25	33	5	6	7.5	2	28	25.5	3.5	TC-GNY- 25	PE-GNY- 25
GNY- 28	28	36	5	6	7.5	2	31	28.5	3.5	TC-GNY- 28	PE-GNY- 28
GNY- 30	30	40	6	7	9	2.5	34	30.5	4	TC-GNY- 30	PE-GNY- 30
GNY- 32	32	42	6	7	9	2.5	36	32.5	4	TC-GNY- 32	PE-GNY- 32
GNY- 35	35	45	6	7	9	2.5	39	35.5	4	TC-GNY- 35	PE-GNY- 35
GNY- 36	36	46	6	7	9	2.5	40	36.5	4	TC-GNY- 36	PE-GNY- 36
GNY- 40	40	50	6	7	9	2.5	44	40.5	4	TC-GNY- 40	PE-GNY- 40
GNY- 45	45	55	6	7	9	2.5	49	45.5	4	TC-GNY- 45	PE-GNY- 45
GNY- 50	50	63	8	9	11.5	3	56	50.5	5	TC-GNY- 50	PE-GNY- 50
GNY- 55	55	68	8	9	11.5	3	61	55.6	5	TC-GNY- 55	PE-GNY- 55
GNY- 56	56	69	8	9	11.5	3	62	56.6	5	TC-GNY- 56	PE-GNY- 56
GNY- 60	60	73	8	9	11.5	3	66	60.6	5	TC-GNY- 60	PE-GNY- 60
GNY- 63	63	76	8	9	11.5	3	69	63.6	5	TC-GNY- 63	PE-GNY- 63
GNY- 65	65	78	8	9	11.5	3	71	65.6	5	TC-GNY- 65	PE-GNY- 65
GNY- 70	70	85	9	10	12.5	3	76	70.6	5	TC-GNY- 70	PE-GNY- 70
GNY- 75	75	90	9	10	12.5	3	81	75.6	5	TC-GNY- 75	PE-GNY- 75
GNY- 80	80	95	9	10	12.5	3	86	80.6	5	TC-GNY- 80	PE-GNY- 80
GNY- 90	90	105	9	10	12.5	3	96	90.6	5	TC-GNY- 90	PE-GNY- 90
GNY- 100	100	120	12	13	16	3.5	107	100.6	6	TC-GNY- 100	PE-GNY- 100
GNY- 110	110	130	12	13	16	3.5	117	110.6	6	TC-GNY- 110	PE-GNY- 110
GNY- 125	125	145	12	13	16	3.5	132	125.7	6	TC-GNY- 125	PE-GNY- 125
GNY- 140	140	160	12	13	16	3.5	147	140.7	6	TC-GNY- 140	PE-GNY- 140
GNY- 160	160	180	12	13	16	3.5	167	160.7	6	TC-GNY- 160	PE-GNY- 160
GNY- 180	180	200	12	13	16	3.5	187	180.7	6	TC-GNY- 180	PE-GNY- 180

★ご注文・お問い合わせは、呼び番号にてご指示下さい。

★表中・呼び番号が色地のものは、在庫しております。