


TSNYパッキン

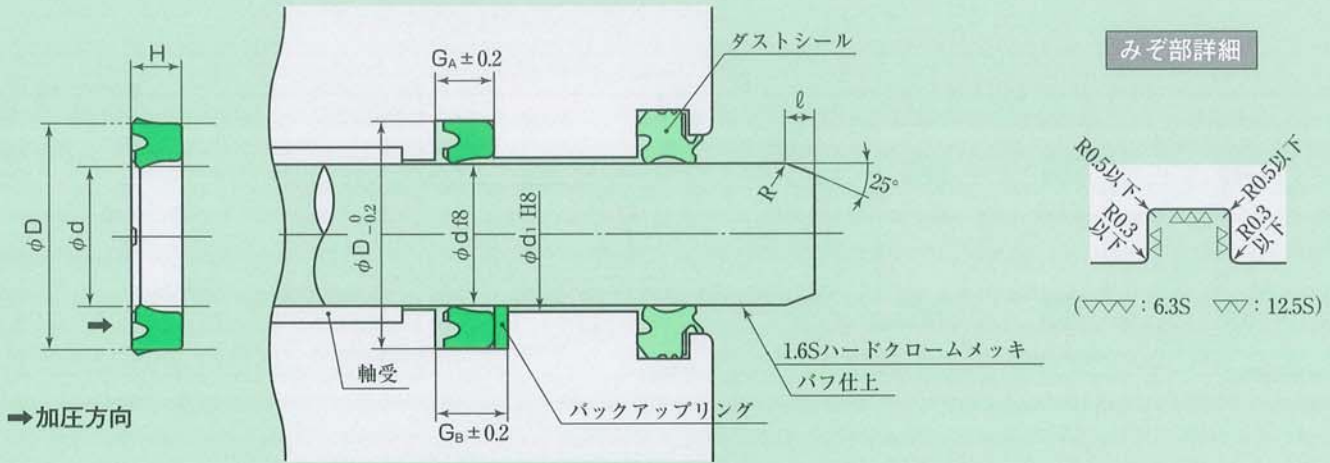

TSNYパッキン寸法表

単位: mm

呼び番号 標準 (RN809)	パッキンおよびみぞ寸法							併用バックアップリング (PT111)
	d	D	H	GA	GB	d1(参考)	ℓ	
TSNY- 14	14	22	5	5.7	6.7	14.4	2.5	TCS- 22 × 14
TSNY- 18	18	26	5	5.7	6.7	18.4	2.5	TCS- 26 × 18
TSNY- 20	20	28	5	5.7	6.7	20.4	2.5	TCS- 28 × 20
TSNY- 25	25	33	5	5.7	6.7	25.4	2.5	TCS- 33 × 25
TSNY- 28	28	35.5	5	5.7	6.7	28.4	2.5	TCS- 35.5 × 28
TSNY- 30	30	40	6	7	8.5	30.5	3	TCS- 40 × 30
TSNY- 31.5	31.5	41.5	6	7	8.5	32	3	TCS- 41.5 × 31.5
TSNY- 35	35	45	6	7	8.5	35.5	3	TCS- 45 × 35
TSNY- 35.5	35.5	45	6	7	8.5	36	3	TCS- 45 × 35.5
TSNY- 40	40	50	6	7	8.5	40.5	3	TCS- 50 × 40
TSNY- 45	45	55	6	7	8.5	45.5	3	TCS- 55 × 45
TSNY- 45A	45	56	7	8	9.5	45.5	3	TCS- 56 × 45
TSNY- 50	50	60	6	7	8.5	50.5	3	TCS- 60 × 50
TSNY- 55	55	65	6	7	8.5	55.6	3	TCS- 65 × 55
TSNY- 56	56	66	6	7	8.5	56.6	3	TCS- 66 × 56
TSNY- 60	60	70	6	7	8.5	60.6	3	TCS- 70 × 60
TSNY- 60A	60	71	7	8	9.5	60.6	3	TCS- 71 × 60
TSNY- 63	63	73	6	7	8.5	63.6	3	TCS- 73 × 63
TSNY- 65	65	75	6	7	8.5	65.6	3	TCS- 75 × 65
TSNY- 70A	70	85	9	10	12	70.6	4	TCS- 85 × 70
TSNY- 70C	70	80	6	7	8.5	70.6	4	TCS- 80 × 70
TSNY- 75	75	85	6	7	8.5	75.6	4	TCS- 85 × 75
TSNY- 75A	75	90	9	10	12	75.6	4	TCS- 90 × 75
TSNY- 80A	80	95	9	10	12	80.6	4	TCS- 95 × 80
TSNY- 80C	80	90	6	7	8.5	80.6	4	TCS- 90 × 80
TSNY- 85	85	100	9	10	12	85.6	4	TCS- 100 × 85
TSNY- 90	90	105	9	10	12	90.6	4	TCS- 105 × 90
TSNY- 95	95	110	9	10	12	95.6	4	TCS- 110 × 95
TSNY- 100	100	115	9	10	12	100.6	4	TCS- 115 × 100
TSNY- 105	105	120	9	10	12	105.6	4	TBC- 120 × 105
TSNY- 110	110	125	9	10	12	110.6	4	TBC- 125 × 110
TSNY- 115B	115	130	8.5	9.5	11.5	115.6	4	TCS- 130 × 115
TSNY- 125	125	140	9	10	12	125.7	4	TCS- 140 × 125
TSNY- 140	140	155	9	10	12	140.7	4	TCS- 155 × 140
TSNY- 150	150	165	9	10	12	150.7	4	TCS- 165 × 150
TSNY- 160	160	175	9	10	12	160.7	4	TCS- 175 × 160
TSNY- 180	180	200	12	13	15.5	180.7	5.5	TCS- 200 × 180

★ご注文・お問い合わせは、呼び番号にてご指示下さい。

★表中・呼び番号が色地のものは、在庫しております。