


PSペンタシール

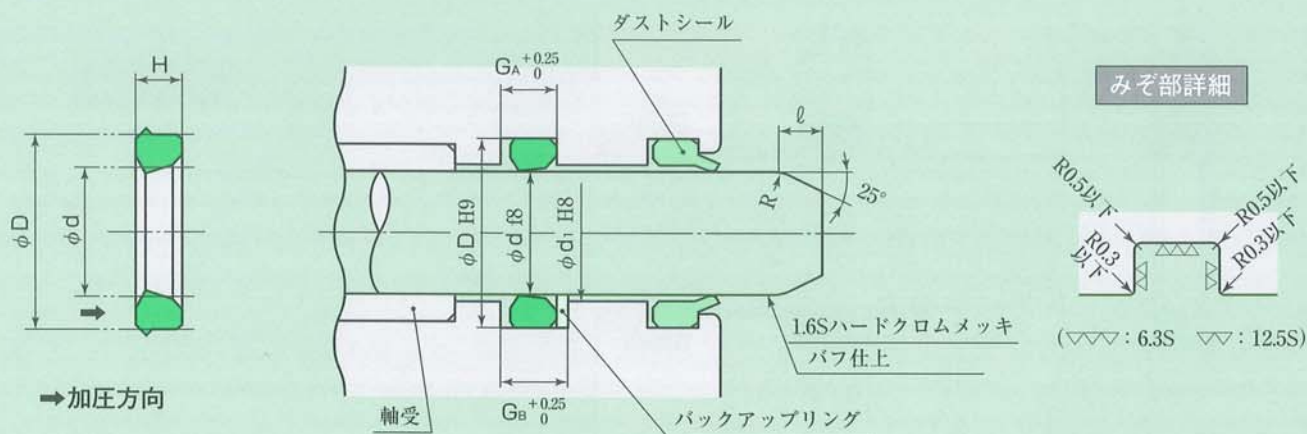

PSペンタシール寸法表

単位：mm

呼び番号		パッキンおよびみぞ寸法						
標準(RN 906)	耐熱用(RF 905)	d	D	H	G_A	G_B	d_1 (参考)	ℓ
PS- 3		3	6	2	2.5	3.9	3.2	1.5
PS- 4		4	7	2	2.5	3.9	4.2	1.5
PS- 5		5	8	2	2.5	3.9	5.2	1.5
PS- 6		6	9	2	2.5	3.9	6.2	1.5
PS- 7		7	10	2	2.5	3.9	7.2	1.5
PS- 8		8	11	2	2.5	3.9	8.2	1.5
PS- 9		9	12	2	2.5	3.9	9.2	1.5
PS- 10		10	13	2	2.5	3.9	10.2	1.5
PS- 10A		10	14	2.9	3.2	4.4	10.3	1.5
PS- 11.2		11.2	15.2	2.9	3.2	4.4	11.5	1.5
PS- 12		12	16	2.9	3.2	4.4	12.3	1.5
PS- 12.5		12.5	16.5	2.9	3.2	4.4	12.8	1.5
PS- 14		14	18	2.9	3.2	4.4	14.3	1.5
PS- 15	PS- 15F	15	19	2.9	3.2	4.4	15.3	1.5
PS- 16		16	20	2.9	3.2	4.4	16.3	1.5
PS- 18		18	22	2.9	3.2	4.4	18.3	1.5
PS- 20		20	24	2.9	3.2	4.4	20.3	1.5
PS- 22		22	26	2.9	3.2	4.4	22.3	1.5
PS- 22A		22	28	4.3	4.7	6	22.3	3
PS- 22.4		22.4	28.4	4.3	4.7	6	22.7	3
PS- 24		24	30	4.3	4.7	6	24.3	3
PS- 25	PS- 25F	25	31	4.3	4.7	6	25.3	3
PS- 26		26	32	4.3	4.7	6	26.3	3
PS- 28	PS- 28F	28	34	4.3	4.7	6	28.3	3
PS- 30		30	36	4.3	4.7	6	30.3	3
PS- 31		31	37	4.3	4.7	6	31.3	3
PS- 31.5		31.5	37.5	4.3	4.7	6	31.8	3
PS- 32	PS- 32F	32	38	4.3	4.7	6	32.3	3
PS- 34		34	40	4.3	4.7	6	34.3	3
PS- 35		35	41	4.3	4.7	6	35.3	3

★ご注文・お問合せは、呼び番号にてご指示下さい。

★表中 呼び番号が色地のものは、在庫しております。