

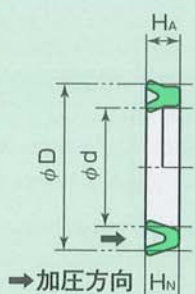


MYパッキン


MYAタイプ

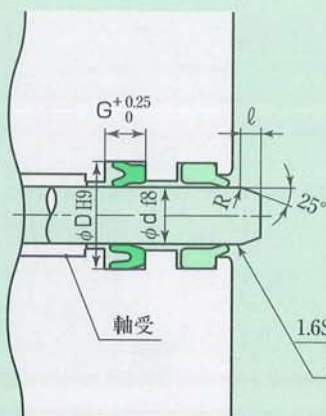

MYNタイプ

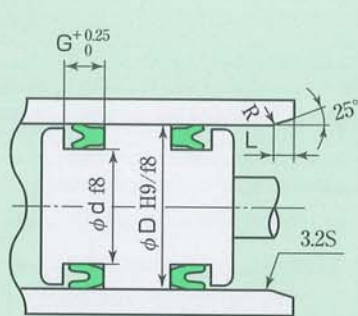

みぞ部詳細

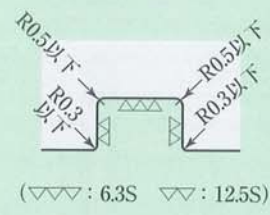

MYパッキン寸法表

単位：mm

呼 び 番 号			パッキンおよびみぞ寸法				
標準 (RK 703)	一般 (RN 716)	耐熱 (RF 704)	d	D	HA	HN	G
MYA- 3	MYN- 3	MYC- 3F	3	6	2.1	2.0	2.5
MYA- 4	MYN- 4	MYH- 4F	4	7	2.1	2.0	2.5
MYA- 5	MYN- 5	MYH- 5F	5	8	2.1	2.0	2.5
MYA- 6	MYN- 6	MYH- 6F	6	9	2.1	2.0	2.5
MYA- 7	MYN- 7	MYH- 7F	7	10	2.1	2.0	2.5
MYA- 8	MYN- 8	MYH- 8F	8	11	2.1	2.0	2.5
MYA- 9	MYN- 9	MYH- 9F	9	12	2.1	2.0	2.5
MYA- 10	MYN- 10	MYH- 10F	10	13	2.1	2.0	2.5
MYA- 10A	MYN- 10A	MYH- 10AF	10	14	2.8	2.7	3.2
MYA- 11	MYN- 11	MYN- 11F	11	15	2.8	2.7	3.2
MYA- 11.2			11.2	15.2	2.8	2.7	3.2
MYA- 12	MYN- 12	MYH- 12F	12	16	2.8	2.7	3.2
MYA- 12.5	MYN- 12.5	MYH- 12.5F	12.5	16.5	2.8	2.7	3.2
MYA- 14	MYN- 14	MYH- 14F	14	18	2.8	2.7	3.2
MYA- 15	MYN- 15		15	19	2.8	2.7	3.2
MYA- 16	MYN- 16	MYH- 16F	16	20	2.8	2.7	3.2
MYA- 18	MYN- 18	MYH- 18F	18	22	2.8	2.7	3.2
MYA- 20	MYN- 20	MYH- 20F	20	24	2.8	2.7	3.2
MYA- 21	MYN- 21	MYH- 21F	21	25	2.8	2.7	3.2
MYA- 22	MYN- 22	MYH- 22F	22	26	2.8	2.7	3.2
MYA- 24	MYN- 24	MYH- 24F	24	30	4.2	4.0	4.7
MYA- 34	MYN- 34	MYH- 34F	34	40	4.2	4.0	4.7

★ご注文・お問合せは、呼び番号にてご指示下さい。
 ★表中 呼び番号が色地のものは、在庫しております。