
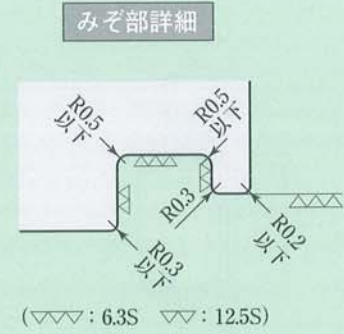
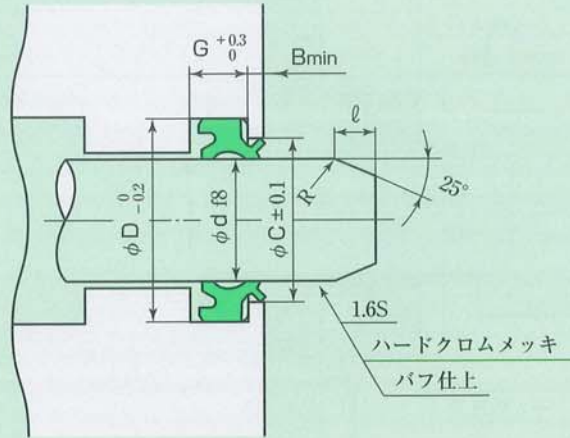


SCKスクレーパ

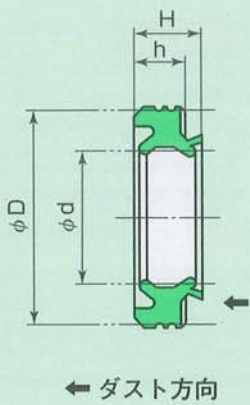

SCKスクレーパ寸法表

単位：mm

呼び番号 標準 (RN 814)	スクレーパおよびみぞ寸法						
	d	D	H	h	C	G	B
SCK- 18	18	30	7.7	5.8	24	6	3
SCK- 20	20	32	7.7	5.8	26	6	3
SCK- 25	25	37	7.7	5.8	31	6	3
SCK- 28	28	40	7.7	5.8	34	6	3
SCK- 30	30	42	7.7	5.8	36	6	3
SCK- 32	32	44	8.7	6.8	38	7	3
SCK- 35	35	47	8.7	6.8	41	7	3
SCK- 40	40	52	8.7	6.8	46	7	3
SCK- 45	45	57	8.7	6.8	51	7	3
SCK- 50	50	62	8.7	6.8	56	7	3
SCK- 55	55	69	10	7.7	62	8	3
SCK- 60	60	74	10	7.7	67	8	3
SCK- 65	65	79	10	7.7	72	8	3
SCK- 70	70	84	10	7.7	77	8	3
SCK- 75	75	89	10	7.7	82	8	3
SCK- 80	80	94	10	7.7	87	8	3
SCK- 85	85	99	10	7.7	92	8	3
SCK- 90	90	104	10	7.7	97	8	3
SCK- 95	95	109	10	7.7	102	8	3
SCK- 100	100	114	10	7.7	107	8	3
SCK- 105	105	121	12	8.7	113	9	4
SCK- 110	110	126	12	8.7	118	9	4
SCK- 115	115	131	12	8.7	123	9	4
SCK- 120	120	136	12	8.7	128	9	4
SCK- 125	125	141	12	8.7	133	9	4
SCK- 130	130	146	12	8.7	138	9	4
SCK- 132	132	148	12	8.7	140	9	4
SCK- 140	140	160	14	9.7	150	10	5
SCK- 160	160	180	14	9.7	170	10	5

★ご注文・お問合せは、呼び番号にてご指示下さい。

★表中 呼び番号が色地のものは、在庫しております。