




# SCBスクレーパ

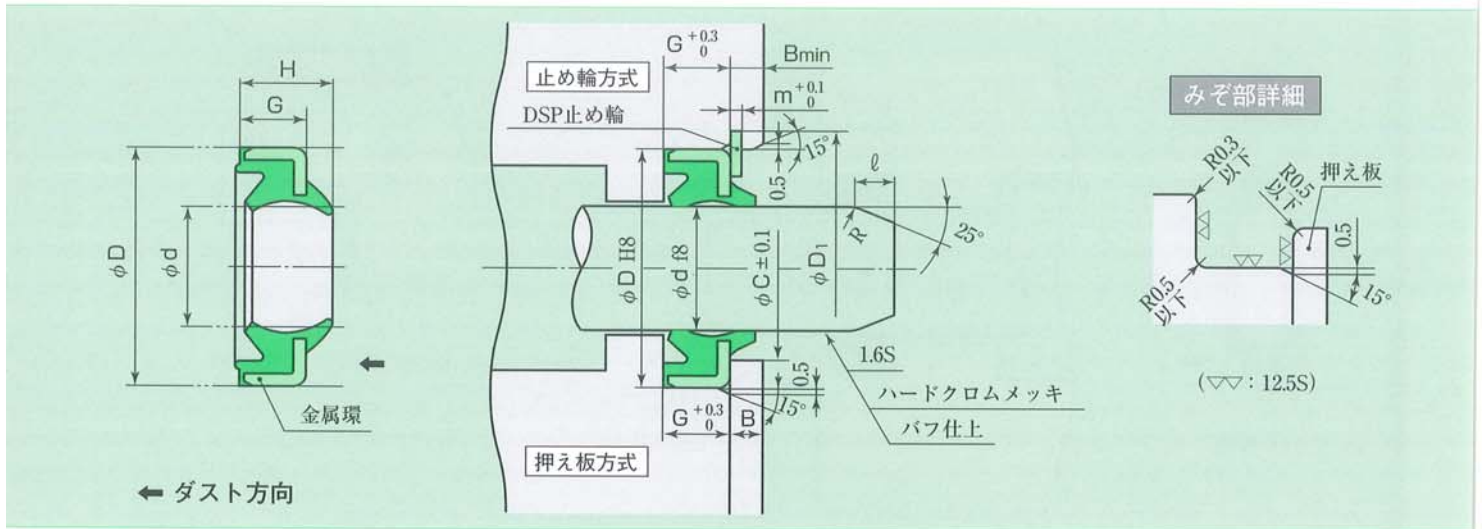

SCBスクレーパ寸法表

単位: mm

呼び番号 標準 (RN 807)	スクレーパおよびみぞ寸法								止め輪 呼び番号
	d	D	H	G	C	B	D <sub>1</sub>	m	
SCB- 8	8	18	8	5	14	3	18.8±0.1	0.7	DSP- 8
SCB- 10	10	20	8	5	16	3	21 ±0.1	0.7	DSP- 10
SCB- 12 22 8	12	22	8	5	17	3	23 ±0.1	0.7	DSP- 12
SCB- 12.5	12.5	23	8	5	19	3	24 ±0.1	0.7	DSP- 12.5
SCB- 14	14	24	8	5	19	3	25 ±0.1	0.7	DSP- 14
SCB- 15	15	25	8	5	21	3	26 ±0.1	0.7	DSP- 15
SCB- 16	16	26	8	5	21	3	27 ±0.1	0.7	DSP- 16
SCB- 18	18	30	9	6	24	3	31.5±0.1	0.8	DSP- 18
SCB- 20	20	32	9	6	26	3	33.5±0.1	0.8	DSP- 20
SCB- 22 32 9	22	32	9	6	28	3	33.5±0.1	0.8	DSP- 22×32
SCB- 22	22	34	9	6	28	3	35.5±0.1	0.8	DSP- 22
SCB- 22.4	22.4	34.4	9	6	29.4	3	35.9±0.1	0.8	DSP- 22.4
SCB- 25	25	37	9	6	31	3	38.5±0.1	0.8	DSP- 25
SCB- 28	28	40	9	6	34	3	41.5±0.1	0.8	DSP- 28
SCB- 30	30	42	9	6	36	3	43.5±0.1	0.8	DSP- 30
SCB- 30 45 9	30	45	9	6	37	3			
SCB- 31.5	31.5	44	10	7	39	3	45.5±0.1	0.8	DSP- 31.5
SCB- 32	32	44	10	7	39	3	45.5±0.1	0.8	DSP- 32
SCB- 34 46 10	34	46	10	7	41	3	47.5±0.1	0.8	DSP- 34
SCB- 35	35	47	10	7	41	3	49 ±0.15	1.0	DSP- 35
SCB- 35.5	35.5	47.5	10	7	42.5	3	49.5±0.15	1.0	DSP- 35.5
SCB- 40	40	52	10	7	46	3	54 ±0.15	1.0	DSP- 40
SCB- 45	45	57	10	7	51	3	59 ±0.15	1.0	DSP- 45
SCB- 50	50	62	10	7	56	3	64 ±0.15	1.0	DSP- 50
SCB- 55	55	69	11	8	62	4	71.5±0.15	1.1	DSP- 55
SCB- 56	56	70	11	8	64	4	72.5±0.15	1.1	DSP- 56
SCB- 60	60	74	11	8	67	4	76.5±0.15	1.1	DSP- 60
SCB- 63	63	77	11	8	71	4	79.5±0.15	1.1	DSP- 63
SCB- 65	65	79	11	8	72	4	81.5±0.15	1.1	DSP- 65
SCB- 70	70	84	11	8	77	4	86.5±0.15	1.1	DSP- 70
SCB- 71	71	85	11	8	79	4	87.5±0.15	1.1	DSP- 71
SCB- 75	75	89	11	8	82	4	91.5±0.15	1.1	DSP- 75
SCB- 78 92 11	78	92	11	8	86	4			
SCB- 80	80	94	11	8	87	4	96.5±0.15	1.1	DSP- 80
SCB- 85	85	99	11	8	92	4	101.5±0.15	1.1	DSP- 85
SCB- 90	90	104	11	8	97	4	106.5±0.15	1.1	DSP- 90
SCB- 95	95	109	11	8	102	4	111.5±0.15	1.1	DSP- 95

★ご注文・お問合せは、呼び番号にてご指示下さい。

★表中 呼び番号が色地のものは、在庫しております。