




# SWAウェアリング

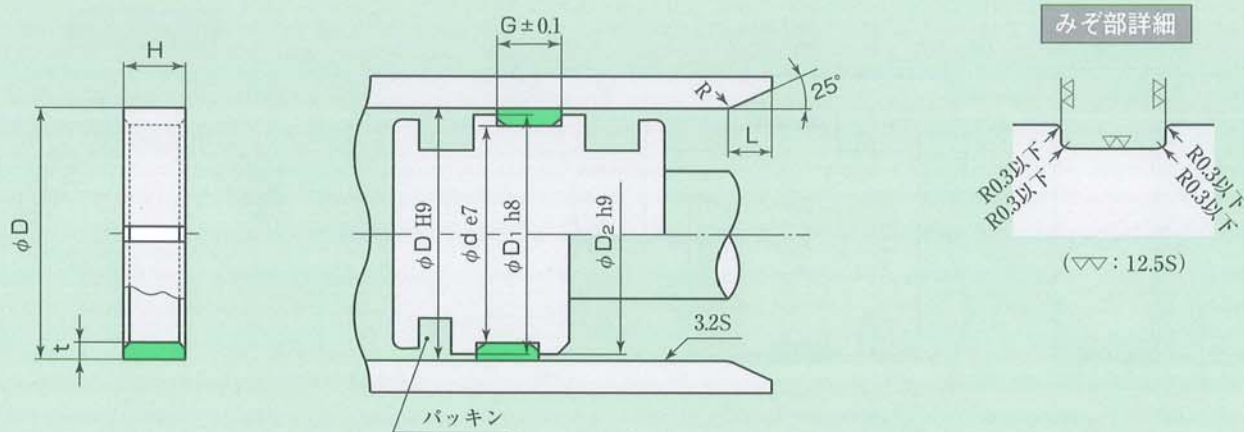

SWAウェアリング寸法表

単位：mm

| 呼び寸法<br>標準(PB 201) | ウェアリングおよびみぞ寸法 |     |    |     |    |                |                |
|--------------------|---------------|-----|----|-----|----|----------------|----------------|
|                    | D             | d   | H  | t   | G  | D <sub>1</sub> | D <sub>2</sub> |
| SWA- 20            | 20            | 17  | 3  | 1.5 | 3  | 19.5           | 19             |
| SWA- 25            | 25            | 22  | 3  | 1.5 | 3  | 24.5           | 24             |
| SWA- 30            | 30            | 27  | 4  | 1.5 | 4  | 29.5           | 29             |
| SWA- 32            | 32            | 29  | 4  | 1.5 | 4  | 31.5           | 31             |
| SWA- 35            | 35            | 32  | 4  | 1.5 | 4  | 34.5           | 34             |
| SWA- 40            | 40            | 36  | 5  | 2   | 5  | 39.5           | 39             |
| SWA- 45            | 45            | 41  | 5  | 2   | 5  | 44.5           | 44             |
| SWA- 50            | 50            | 46  | 5  | 2   | 5  | 49.5           | 49             |
| SWA- 55            | 55            | 51  | 5  | 2   | 5  | 54.5           | 54             |
| SWA- 60            | 60            | 56  | 6  | 2   | 6  | 59.5           | 59             |
| SWA- 63            | 63            | 59  | 6  | 2   | 6  | 62.4           | 62             |
| SWA- 65            | 65            | 61  | 6  | 2   | 6  | 64.4           | 64             |
| SWA- 70            | 70            | 66  | 6  | 2   | 6  | 69.4           | 69             |
| SWA- 75            | 75            | 71  | 6  | 2   | 6  | 74.4           | 74             |
| SWA- 80            | 80            | 76  | 8  | 2   | 8  | 79.4           | 79             |
| SWA- 85            | 85            | 81  | 8  | 2   | 8  | 84.4           | 84             |
| SWA- 90            | 90            | 86  | 8  | 2   | 8  | 89.4           | 89             |
| SWA- 95            | 95            | 91  | 8  | 2   | 8  | 94.4           | 94             |
| SWA- 100           | 100           | 95  | 10 | 2.5 | 10 | 99.4           | 98             |
| SWA- 120           | 120           | 115 | 10 | 2.5 | 10 | 119.4          | 118            |
| SWA- 125           | 125           | 120 | 10 | 2.5 | 10 | 124.3          | 123            |
| SWA- 140           | 140           | 134 | 15 | 3   | 15 | 139.3          | 138            |
| SWA- 150           | 150           | 144 | 15 | 3   | 15 | 149.3          | 148            |
| SWA- 160           | 160           | 154 | 15 | 3   | 15 | 159.3          | 158            |
| SWA- 180           | 180           | 174 | 15 | 3   | 15 | 179.3          | 178            |
| SWA- 200           | 200           | 194 | 20 | 3   | 20 | 199.2          | 198            |
| SWA- 250           | 250           | 244 | 20 | 3   | 20 | 249.2          | 248            |

★ご注文・お問合せは、呼び番号にてご指示下さい。  
★表中・呼び番号が色地のものは在庫しております。