


# PGリング(PGRO) 【ピストン用】

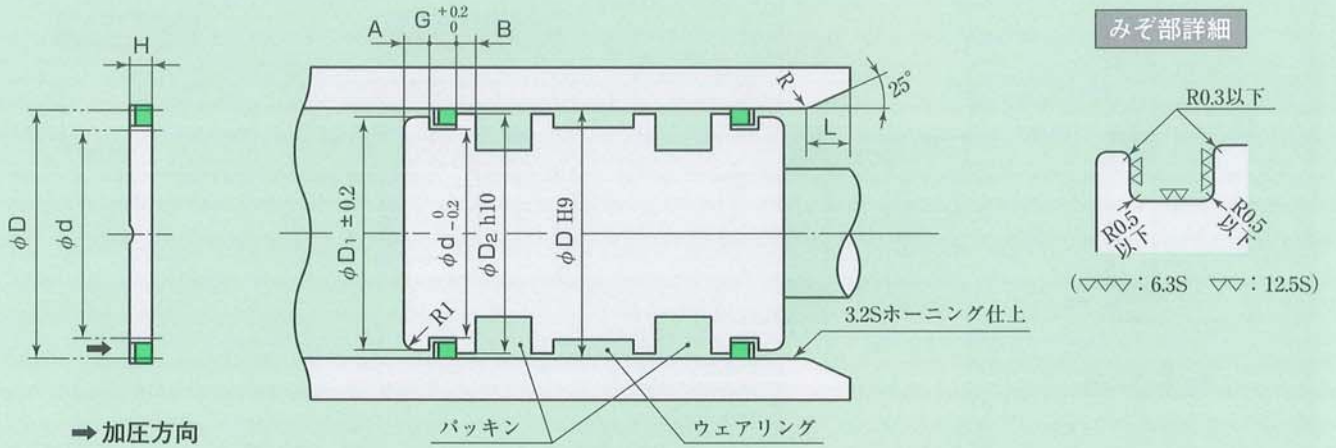

## PGリング(PGRO)寸法表

単位：mm

呼び番号	パッキンおよびみぞ寸法								
	標準 (PT 111)	D	d	H	G	D <sub>1</sub>	D <sub>2</sub>	A	B
PGRO- 30		30	24	3	3.5	29	29.5	3	3.5
PGRO- 31.5		31.5	25.5	3	3.5	30.5	31	3	3.5
PGRO- 35		35	29	3	3.5	34	34.5	3	3.5
PGRO- 35.5		35.5	29.5	3	3.5	34.5	35	3	3.5
PGRO- 40		40	33	3.4	4	39	39.5	3	3.5
PGRO- 45		45	38	3.4	4	44	44.5	3	3.5
PGRO- 50		50	43	3.4	4	49	49.5	3	3.5
PGRO- 55		55	48	3.4	4	54	54.4	3	3.5
PGRO- 56		56	49	3.4	4	55	55.4	3	3.5
PGRO- 60		60	53	3.4	4	59	59.4	3	3.5
PGRO- 63		63	56	3.4	4	62	62.4	3	3.5
PGRO- 65		65	58	3.4	4	64	64.4	3	3.5
PGRO- 70		70	62	3.8	4.5	69	69.4	4	4
PGRO- 71		71	63	3.8	4.5	70	70.4	4	4
PGRO- 75		75	67	3.8	4.5	74	74.4	4	4
PGRO- 80		80	72	3.8	4.5	79	79.4	4	4
PGRO- 90		90	82	3.8	4.5	89	89.4	4	4
PGRO- 100		100	90	4.5	5.5	98	99.4	4	5
PGRO- 110		110	100	4.5	5.5	108	109.4	4	5
PGRO- 112		112	102	4.5	5.5	110	111.4	4	5
PGRO- 120		120	110	4.5	5.5	118	119.4	4	5
PGRO- 125		125	115	4.5	5.5	123	124.3	4	5
PGRO- 140		140	130	4.5	5.5	138	139.3	4	5
PGRO- 150		150	138	5.5	6.5	148	149.3	5	6
PGRO- 160		160	148	5.5	6.5	158	159.3	5	6
PGRO- 170		170	158	5.5	6.5	168	169.3	5	6
PGRO- 180		180	168	5.5	6.5	178	179.3	5	6
PGRO- 200		200	188	5.5	6.5	198	199.3	5	6
PGRO- 224		224	212	5.5	6.5	222	223.2	5	6
PGRO- 250		250	238	5.5	6.5	248	249.2	5	6

★ご注文・お問合せは、呼び番号にてご指示下さい。

★表中・呼び番号が色地のものは在庫しております。