

# Scaffolding Castors

<SJ: with Screwjack/SC: with Stem>

RoHS compliant products.

## POINT

- Original safety structure ① and ②.

Safety structure ①



High resistance to sideways load.

Safety structure ②



Protective stopper device; securely locks wheel without leaving a scratch.

- Screwjack with level adjustable handle.
- SISIKU's unique point - **Box style wheel**.
- Smooth swiveling thanks to **double bearing** in the swivel head.
- WW (BR White) and WUW (Antibacterial UR white); suitable for indoor use thanks to floor saving and non-marking characteristics.

Products with certification No.140493 by Scaffolding and Construction Equipment Association of Japan.

## USE EXAMPLE

- For working such as painting and decoration at an elevated spot with workstand, rolling tower and tower lift.
- For moving equipment
- For stage and studio setting.

- ◎Suitable for the pipe in diameter  $42.7 \pm 0.25$  used for scaffold other than lower type.
- ◎We'll accept your custom-order. Please feel free to contact us. (Use "Specification Form for Custom-designed castor" at the end of this catalog.)
- ◎Please feel free to ask about the product weight for each item.



**SJ** Swivel with screwjack



SJ-100

SJ-130

SJ-150

SJ-200

SJ-250

- Color/Finish; Zinc plated
- Size 100mm/250mm: not authorized by SCEA.
- WUW wheel: not authorized by SCEA.

**SC** Swivel with stem



SC-100

SC-130

SC-150

SC-200

SC-250

- Color/Finish; Zinc plated
- Size 100mm/250mm: not authorized by SCEA.
- WUW wheel: not authorized by SCEA.

## WHEELS

ベアリング変更 JBB→CB

JBB ...Radial ball bearing

See P.62 to P.71 for detailed description.



CW (SBR)  
<Made in China>

NB φ100, φ130, φ150 and φ200.  
NB SJ/SC-250 come with W wheel




W (SBR)



WW (BR)

- Cold resistance (-40°C~+90°C)
- Floor saving and non-marking.

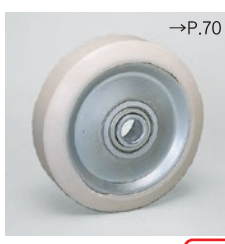

WUW (Antibacterial UR/White)

- Antibacterial effect. High elasticity. Oil resistant.
- Floor saving, non-marking