


# ストレートタイプアダプター

● Material : Plated steel, Stainless Steel  
● 材質 : SS(三価クロメートメッキ)・SUS304

## SR-14 (同径)

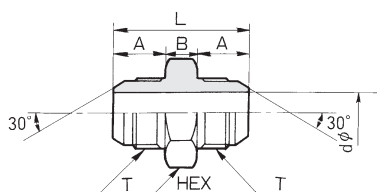


接続口金具 : SR-04

\*印のSUSは受注生産

呼び径	ねじT	Amm	Bmm	dφmm	Lmm	HEXmm	
						SUS	SS
* 3	G 1/8	13.0	6	4.0	32	14	
6	G 1/4	16.0	8	5.5	40	19	
9	G 3/8	17.5	8	7.0	43	22	
12	G 1/2	20.0	10	10.0	50	27	
19	G 3/4	21.5	12	16.0	55	32	36
25	G 1	22.5	12	22.0	57	38	41
32	G 1 1/4	27.0	14	28.0	68	46	50
38	G 1 1/2	27.0	14	34.0	68	50	60
50	G 2	30.0	17	45.0	77	63	70
* 65	G 2 1/2	43.0	17	56.0	103	80	
* 75	G 3	43.0	18	68.0	104	90	

## SR-14 (異径)

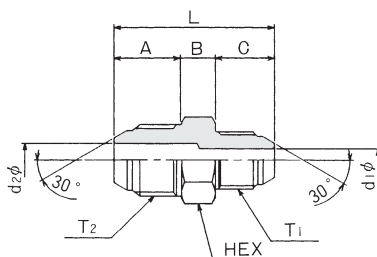


接続口金具 : SR-04

\*印及びSUSは受注生産

呼び径	ねじT <sub>1</sub>	ねじT <sub>2</sub>	Amm	Bmm	Cmm	d <sub>1</sub> φmm	d <sub>2</sub> φmm	Lmm	HEXmm
3×6	G 1/8	G 1/4	16.0	8	13.0	4.0	5.5	37.0	14
6×9	G 1/4	G 3/8	17.5	8	16.0	5.5	7.0	41.5	19
9×12	G 3/8	G 1/2	20.0	10	17.5	7.0	10.0	47.5	22
12×19	G 1/2	G 3/4	21.5	12	20.0	10.0	16.0	53.5	32
19×25	G 3/4	G 1	22.5	12	21.5	16.0	22.0	56.0	38
* 25×32	G 1	G 1 1/4	27.0	14	22.5	22.0	28.0	63.5	46
* 32×38	G 1 1/4	G 1 1/2	27.0	14	27.0	28.0	28.0	68.0	50
* 38×50	G 1 1/2	G 2	30.0	14	27.0	33.0	33.0	71.0	60

## SR-14 (異径)

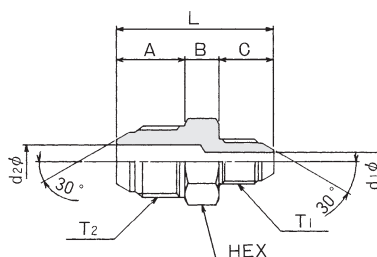

接続口金具 : SR-04

SUSは受注生産

呼び径	ねじT <sub>1</sub>	ねじT <sub>2</sub>	Amm	Bmm	Cmm	d <sub>1</sub> φmm	d <sub>2</sub> φmm	Lmm	HEXmm
3×9	G 1/8	G 3/8	17.5	8	13.0	4.0	7.0	38.5	19
6×12	G 1/4	G 1/2	20.0	10	16.0	5.5	10.0	46.0	22
9×19	G 3/8	G 3/4	21.5	12	17.5	7.0	16.0	51.0	32
12×25	G 1/2	G 1	22.5	12	20.0	10.0	22.0	54.5	38

(注意) 予告なしに、品質・性能・改善のため寸法を変更する事があります。