


ホース口金具(SS)

●材質：SS(三価クロメートメッキ)
 ※低・中圧ゴムホース口金具は形状及び寸法が異なる場合があります。


SR-01 管用テーパ雄ねじ

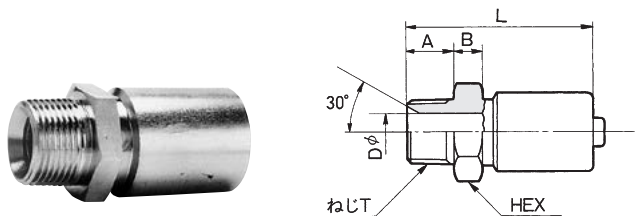

接続アダプター：SR-07・SR-08・SR-17・SR-18

呼び径	ねじT	Amm	Bmm	Dφmm	1W-Lmm	2W-Lmm	HEXmm	外筒内径mm	
								1W	2W
6	R ¼	13	6	4.0	50	54	19	14.5	16.0
9	R ⅜	15	8	6.5	56	63	22	18.5	20.0
12	R ½	18	8	9.5	64	71	27	21.5	23.0
19	R ¾	20	10	15.0	75	85	36	29.0	32.0
25	R 1	22	12	21.5	89	97	41	37.0	38.0
32	R 1¼	25	14	28.0	97	106	50	44.5	48.0
38	R 1½	25	14	33.0	99	114	60	54.0	56.0
50	R 2	30	16	44.0	111	125	70	66.0	67.0

SR-02 管用平行雄ねじ

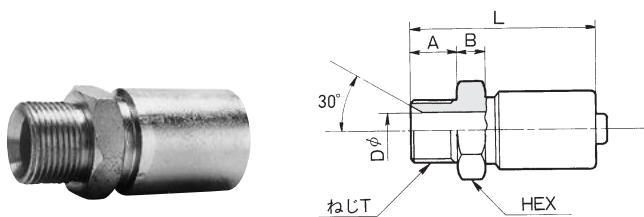


接続アダプター：SR-06・SR-08・SR-10

受注生産

呼び径	ねじT	Amm	Bmm	Dφmm	1W-Lmm	2W-Lmm	HEXmm	外筒内径mm	
								1W	2W
6	G ¼	13	6	4.0	50	54	19	14.5	16.0
9	G ⅜	15	8	6.5	56	63	22	18.5	20.0
12	G ½	18	8	9.0	64	71	27	21.5	23.0
19	G ¾	20	10	15.0	75	85	36	29.0	32.0
25	G 1	22	12	21.0	89	97	41	37.0	38.0
32	G 1¼	24	14	28.0	96	105	50	44.5	48.0
38	G 1½	24	14	33.0	98	113	60	54.0	56.0
50	G 2	30	16	44.0	109	123	70	66.0	67.0


SR-04 管用平行雄ねじ

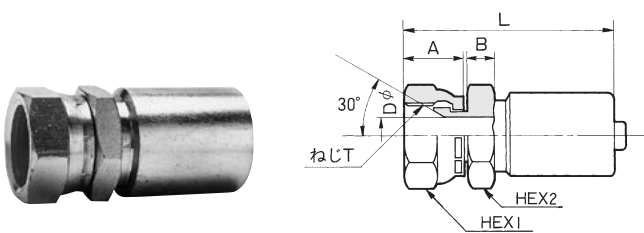

接続アダプター：SR-13・SR-14・SR-17・SR-33・SR-35

呼び径	ねじT	Amm	Bmm	Dφmm	1W-Lmm	2W-Lmm	HEX1mm	HEX2mm	外筒内径mm	
									1W	2W
6	G ¼	17	6	4.0	54	58	19	17	14.5	16.0
9	G ⅜	19	8	6.5	60	67	22	19	18.5	20.0
12	G ½	21	8	9.5	68	74	27	24	21.5	23.0
19	G ¾	24	10	15.0	79	89	36	36	29.0	32.0
25	G 1	26	12	21.5	93	101	41	41	37.0	38.0
32	G 1¼	30	14	28.0	102	111	50	46	44.5	48.0
38	G 1½	33	14	33.0	107	122	60	50	54.0	56.0
50	G 2	35	16	44.0	116	130	70	63	66.0	67.0

SR-05 管用平行雄ねじ

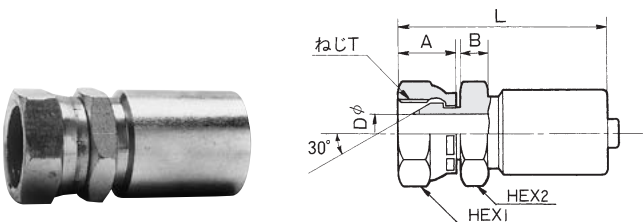

接続アダプター：SR-07・SR-09・SR-11・SR-34・SR-36

呼び径	ねじT	Amm	Bmm	Dφmm	1W-Lmm	2W-Lmm	HEX1mm	HEX2mm	外筒内径mm	
									1W	2W
6	G ¼	17	6	4.0	54	58	19	17	14.5	16.0
9	G ⅜	19	8	6.5	60	67	22	19	18.5	20.0
12	G ½	21	8	9.5	68	74	27	24	21.5	23.0
19	G ¾	24	10	15.0	79	89	36	36	29.0	32.0
25	G 1	26	12	21.5	93	101	41	41	37.0	38.0
32	G 1¼	30	14	28.0	102	111	50	46	44.5	48.0
38	G 1½	33	14	33.0	107	122	60	50	54.0	56.0
50	G 2	35	16	44.0	116	130	70	63	66.0	67.0

(注意) 予告なしに、品質・性能・改善のため寸法を変更する事があります。