


## SK式回転アダプター


●材質：SS(三価クロメートメッキ)

## SKL-30

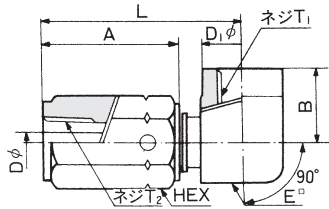


| 呼び径 | ネジT <sub>1</sub> | ネジT <sub>2</sub> | Lmm | Amm | Bmm | Dφmm | D <sub>1</sub> φmm | E <sup>□</sup> mm | HEXmm |
|-----|------------------|------------------|-----|-----|-----|------|--------------------|-------------------|-------|
| 6   | Rc 1/4           | Rc 1/4           | 47  | 33  | 18  | 5    | 19                 | 19                | 19    |
| 9   | Rc 3/8           | Rc 3/8           | 54  | 38  | 18  | 7    | 24                 | 23                | 22    |
| 12  | Rc 1/2           | Rc 1/2           | 63  | 42  | 26  | 10   | 30                 | 30                | 27    |
| 19  | Rc 3/4           | Rc 3/4           | 71  | 46  | 30  | 16   | 36                 | 36                | 36    |
| 25  | Rc 1             | Rc 1             | 76  | 48  | 36  | 21   | 40                 | 45                | 41    |

## SKL-31

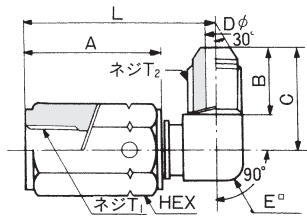


| 呼び径 | ネジT <sub>1</sub> | ネジT <sub>2</sub> | Lmm | Amm | Bmm | Cmm | Dφmm | E <sup>□</sup> mm | HEXmm |
|-----|------------------|------------------|-----|-----|-----|-----|------|-------------------|-------|
| 6   | Rc 1/4           | G 1/4            | 46  | 33  | 16  | 25  | 5    | 14                | 19    |
| 9   | Rc 3/8           | G 3/8            | 52  | 38  | 18  | 27  | 7    | 19                | 22    |
| 12  | Rc 1/2           | G 1/2            | 60  | 42  | 20  | 32  | 10   | 22                | 27    |
| 19  | Rc 3/4           | G 3/4            | 68  | 46  | 22  | 37  | 16   | 30                | 36    |
| 25  | Rc 1             | G 1              | 74  | 48  | 23  | 41  | 21   | 36                | 41    |

## SKL-32

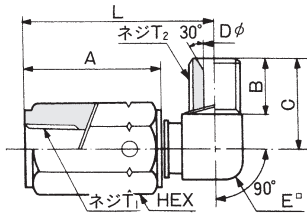


| 呼び径 | ネジT <sub>1</sub> | ネジT <sub>2</sub> | Lmm | Amm | Bmm | Cmm | Dφmm | E <sup>□</sup> mm | HEXmm |
|-----|------------------|------------------|-----|-----|-----|-----|------|-------------------|-------|
| 6   | Rc 1/4           | G 1/4            | 46  | 33  | 13  | 21  | 5    | 14                | 19    |
| 9   | Rc 3/8           | G 3/8            | 52  | 38  | 15  | 25  | 7    | 19                | 22    |
| 12  | Rc 1/2           | G 1/2            | 60  | 42  | 17  | 29  | 10   | 22                | 27    |
| 19  | Rc 3/4           | G 3/4            | 68  | 46  | 20  | 35  | 16   | 30                | 36    |
| 25  | Rc 1             | G 1              | 74  | 48  | 22  | 40  | 21   | 36                | 41    |

## SKL-33

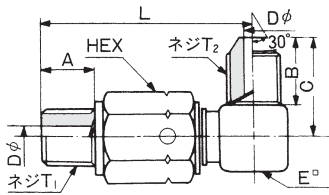


| 呼び径 | ネジT <sub>1</sub> | ネジT <sub>2</sub> | Lmm | Amm | Bmm | Cmm | Dφmm | E <sup>□</sup> mm | HEXmm |
|-----|------------------|------------------|-----|-----|-----|-----|------|-------------------|-------|
| 6   | R 1/4            | G 1/4            | 52  | 13  | 16  | 24  | 5    | 14                | 19    |
| 9   | R 3/8            | G 3/8            | 57  | 15  | 18  | 28  | 7    | 19                | 22    |
| 12  | R 1/2            | G 1/2            | 66  | 18  | 20  | 32  | 10   | 22                | 27    |
| 19  | R 3/4            | G 3/4            | 74  | 20  | 22  | 37  | 16   | 30                | 36    |
| 25  | R 1              | G 1              | 82  | 22  | 23  | 41  | 21   | 36                | 41    |

## SKL-34

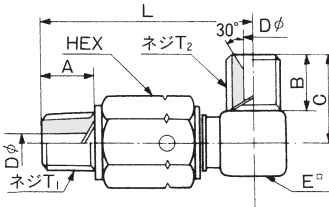

| 呼び径 | ネジT <sub>1</sub> | ネジT <sub>2</sub> | Lmm | Amm | Bmm | Cmm | Dφmm | E <sup>□</sup> mm | HEXmm |
|-----|------------------|------------------|-----|-----|-----|-----|------|-------------------|-------|
| 6   | R 1/4            | G 1/4            | 52  | 13  | 13  | 21  | 5    | 14                | 19    |
| 9   | R 3/8            | G 3/8            | 57  | 15  | 15  | 25  | 7    | 19                | 22    |
| 12  | R 1/2            | G 1/2            | 66  | 18  | 17  | 29  | 10   | 22                | 27    |
| 19  | R 3/4            | G 3/4            | 74  | 20  | 20  | 35  | 16   | 30                | 36    |
| 25  | R 1              | G 1              | 82  | 22  | 22  | 40  | 21   | 36                | 41    |

## SKL-35

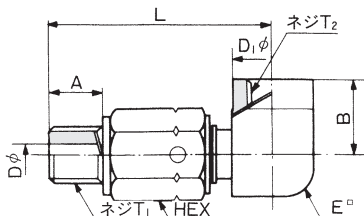

| 呼び径 | ネジT <sub>1</sub> | ネジT <sub>2</sub> | Lmm | Amm | Bmm | Cmm | Dφmm | E <sup>□</sup> mm | HEXmm |
|-----|------------------|------------------|-----|-----|-----|-----|------|-------------------|-------|
| 6   | R 1/4            | Rc 1/4           | 53  | 13  | 18  | 5   | 19   | 19                | 19    |
| 9   | R 3/8            | Rc 3/8           | 59  | 15  | 18  | 7   | 23   | 24                | 22    |
| 12  | R 1/2            | Rc 1/2           | 69  | 18  | 26  | 10  | 30   | 30                | 27    |
| 19  | R 3/4            | Rc 3/4           | 77  | 20  | 30  | 16  | 36   | 36                | 36    |
| 25  | R 1              | Rc 1             | 84  | 22  | 36  | 21  | 40   | 40                | 41    |

(注意) 予告なしに、品質・性能・改善のため寸法を変更する事があります。