


超硬バー

CARBIDE BURS SUPER

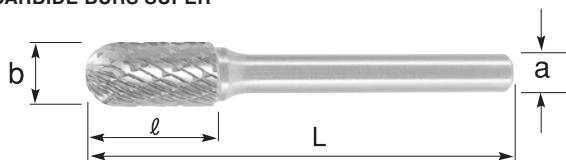

■シャフト径 a φ3mm (オール超硬)

(mm)

形状	品番 (W.cut)	品番 (S.cut)	b	ℓ	L	メーカー希望 小売価格
	SB1A01	SB1A01S	1.5	6	38	1,360
	SB1A02	SB1A02S	2.5	11	38	1,360
	SB1A03	SB1A03S	3.0	14	38	1,360
	SB1A01E	SB1A01ES	3.0	14	38	1,360
	SB2A01	SB2A01S	2.5	11	38	1,360
	SB2A02	SB2A02S	3.0	14	38	1,360
	SB3A01	SB3A01S	3.0	12.7	38	1,360
	SB3A02	SB3A02S	3.0	6	38	1,360
	SB4A01	SB4A01S	3.0	9.5	38	1,360
	SB4A02	SB4A02S	3.0	6	38	1,360
	SB4A03	SB4A03S	3.0	12.7	38	1,360
	SB5A01	SB5A01S	3.0 ⁷	16	38	1,360
	SB5A02	SB5A02S	3.0 ¹²	8.9	38	1,360
	SB5A03	SB5A03S	3.0 ¹⁴	11	38	1,360
	SB6A01	SB6A01S	3.0	5.5	38	1,360
	SB7A01	SB7A01S	3.0 ⁸	12.7	38	1,360
	SB7A02	SB7A02S	3.0 ⁸	9.5	38	1,360
	SB8A01	SB8A01S	2.5	2.3	38	1,360
	SB8A02	SB8A02S	3.0	2.5	38	1,360
	SB49A01	SB49A01S	3.0 ⁹⁰	1.5	38	1,360
	SB50A01	SB50A01S	3.0 ⁹⁰	2.5	38	1,360
	SB51A01	SB51A01S	3.0	6.3	38	1,360
	SB52A01	SB52A01S	3.0 ¹⁰	4	38	1,360

■シャフト径 a φ3mm (オール超硬)

(mm)

形状	品番 (W.cut)	品番 (S.cut)	b	ℓ	L	メーカー希望 小売価格
	SB1D01	SB1D01S	4.0	12.7	38	3,540
	SB1D02	SB1D02S	5.0	12.7	38	3,730
	SB2D03	SB2D03S	4.0	12.7	38	3,540
	SB2D04	SB2D04S	5.0	12.7	38	3,730
	SB3D08	SB3D08S	5.0	12.7	38	3,730
	SB4D09	SB4D09S	5.0	12.7	38	3,730
	SB5D12	SB5D12S	5.0 ¹⁶	12.7	38	3,730
	SB6D07	SB6D07S	5.0	7.1	38	3,730
	SB7D11	SB7D11S	5.0 ¹⁴	12.7	38	3,730
	SB8D05	SB8D05S	4.0	3.4	38	3,540
	SB8D06	SB8D06S	5.0	4.7	38	3,730
	SB51D10	SB51D10S	5.0	9.5	38	3,730
	SB52D13	SB52D13S	5.0 ¹⁰	6.3	38	3,730

■シャフト径 a φ3mm

(mm)

形状	品番 (W.cut)	品番 (S.cut)	b	ℓ	L	メーカー希望 小売価格
	SB1B01	SB1B01S	6.3	12.7	50	2,220
	SB1B02E	SB1B02ES	6.3	4.7	43	2,220
	SB2B03	SB2B03S	6.3	12.7	50	2,220
	SB3B06	SB3B06S	6.3	12.7	50	2,220
	SB4B07	SB4B07S	6.3	12.7	50	2,220
	SB5B08	SB5B08S	6.3 ²²	12.7	54	2,220
	SB6B05	SB6B05S	6.3	9.5	47	2,220
	SB8B04	SB8B04S	6.3	5.0	44	2,220
	SB52B09	SB52B09S	6.3 ¹⁰	6.0	44	2,220

マイクロエアーグラインダー & 先端工具類

MICRO AIR GRINDERS & TIPPED TOOLS