
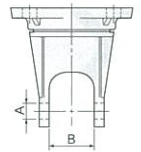
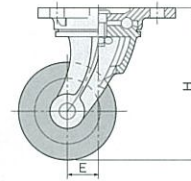


Ductile Caster for Heavy Loads

TBR

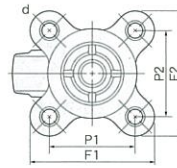

unit:mm

Wheel diameter	Type	Material	Load capacity	Total Height	Bolt hole spacing	Plate dimension	Hub length	Offset	Bolt hole diameter	Axle bore diameter
100	100×50TBR B	Rubber (with bearing)	140kg	145	104×104	136×136	69	40	11	17
	100×65TBR B		180kg				80			
	100×50TBR ULB	Urethane (with bearing)	340kg				69			
125	125×50TBR B	Rubber (with bearing)	180kg	178.5	110×110	142×142	69	45	11	25
	125×65TBR B		220kg				80			
	125×50TBR ULB	Urethane (with bearing)	400kg				69			
	125×50TBR FB	Metal (with bearing)	400kg				69			
	125×65TBR FB		470kg				80			
150	150×50TBR B	Rubber (with bearing)	210kg	205	125×125	161×161	69	50	14	25
	150×65TBR B		250kg				80			
	150×75TBR B		310kg				94			
	150×50TBR ULB	Urethane (with bearing)	440kg				69			
	150×65TBR ULB		590kg				80			
	150×75TBR ULB		720kg				94			
	150×50TBR FB	Metal (with bearing)	440kg				69			
	150×65TBR FB		590kg				80			
150×75TBR FB	720kg		94							
180	180×50TBR B	Rubber (with bearing)	250kg	235	125×125	161×161	69	55	14	25
	180×65TBR B		280kg				80			
	180×75TBR B		350kg				94			
200	200×50TBR B	Rubber (with bearing)	280kg	260	136×136	172×172	69	60	14	25
	200×65TBR B		320kg				80			
	200×75TBR B		380kg				94			
	200×90TBR B		510kg				104			
	200×50TBR ULB	Urethane (with bearing)	650kg				69			
	200×65TBR ULB		720kg				80			
	200×75TBR ULB		880kg				94			
	200×90TBR ULB		1000kg				104			
200×75TBR FB	Metal (with bearing)	880kg	94							
250	250×65TBR B	Rubber (with bearing)	400kg	315	155×155	195×195	80	65	14	30
	250×75TBR B		470kg				94			
	250×90TBR B		580kg				105			
	250×65TBR ULB	Urethane (with bearing)	900kg				80			
	250×75TBR ULB		1070kg				94			
	250×90TBR ULB		1270kg				105			
	250×65TBR FB	Metal (with bearing)	900kg				80			
250×75TBR FB	1070kg		94							
300	300×75TBR B	Rubber (with bearing)	540kg	365	170×170	210×210	94	75	16	30
	300×90TBR B		620kg				105			
	300×100TBR B		900kg				120			
	300×75TBR ULB	Urethane (with bearing)	1210kg	94						
	300×90TBR ULB		1450kg	105						
	300×100TBR ULB		1610kg	120						
300×75TBR FB	Metal (with bearing)	1210kg	94							