


TW·TWN SERIES

Color Type

Series	Color code	Top cover	Bottom cover
TW	G	Light gray	Light gray
	B	Black	Black
TWN	W	Off-white	Off-white

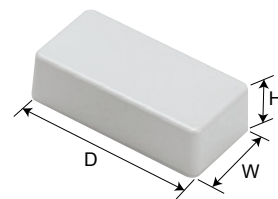

TW Standard

ABS UL94HB

Part no. / Dimensions

• Please suffix color code of G or B at the ending of part number □ when ordering TW series.

Part no.	W	H	D	Screw size, pcs		Weight(g)
TW 4-2- 5□	35	20	50	M2.6×12	2 pcs	13.5
TW 4-2- 6□	35	20	60	M2.6×12	2 pcs	15.5
TW 4-2- 8□	40.3	20	80.3	M2.6×12	2 pcs	22
TW 5-2- 5□	50	15	50	M2.6×12	4 pcs	18
TW 5-3- 5□	50	25	50	M2.6×12	4 pcs	22
TW 5-2- 7□	50	15	70	M2.6×12	4 pcs	22
TW 5-3- 7□	50	27.5	70	M2.6×12	4 pcs	29
TW 5-4- 7□	50	40	70	M2.6×12	4 pcs	35
TW 5-3- 9□	45	25	90	M3×12	4 pcs	30.5
TW 5-3-10□	50	30	100	M3×12	4 pcs	45.5
TW 7-2-11□	70	20	105	M2.6×14	4 pcs	56.5
TW 7-4-11□	70	35	105	M2.6×14	4 pcs	70
TW 7-5-11□	70	50	105	M2.6×14	4 pcs	83
TW 7-3-13□	65	25.8	130	M3×16	4 pcs	76
TW 7-5-13□	65	50.1	130	M3×16	4 pcs	100
TW 8-2- 8□	80	20	80	M2.6×12	4 pcs	49
TW 8-4- 8□	80	40	80	M2.6×12	4 pcs	65
TW 9-4- 17□	85.5	35.5	170	M3×16	4 pcs	133
TW 9-6- 17□	85.5	60.5	170	M3×16	4 pcs	168
TW11-5-22□	110	45.3	220	M3×16	4 pcs	223
TW11-8-22□	110	75.3	220	M3×16	4 pcs	277
TW13-3-13□	125	25	125	M3×16	4 pcs	135
TW13-5-13□	125	45	125	M3×16	4 pcs	165.5
TW13-3-18□	125	25	175	M3×16	4 pcs	184.5
TW13-5-18□	125	45	175	M3×16	4 pcs	218
TW13-7-18□	125	65	175	M3×16	4 pcs	254

TWN Flame-resistant

ABS UL94V-1 / UL94V-0

Part no. / Dimensions

Part no.	W	H	D	UL-class	Screw size, pcs		Weight(g)
TWN 4-2- 5W	35	20	50	UL94V-1	M2.6×12	2 pcs	16.5
TWN 4-2- 6W	35	20	60	UL94V-1	M2.6×12	2 pcs	18
TWN 4-2- 8W	40.3	20	80.3	UL94V-1	M2.6×12	2 pcs	26
TWN 5-2- 7W	50	15	70	UL94V-1	M2.6×12	4 pcs	24.5
TWN 5-3- 7W	50	27.5	70	UL94V-1	M2.6×12	4 pcs	33
TWN 5-4- 7W	50	40	70	UL94V-1	M2.6×12	4 pcs	39.5
TWN 5-3- 9W	45	25	90	UL94V-1	M3×16	4 pcs	35
TWN 7-2-11W	70	20	105	UL94V-0	M2.6×14	4 pcs	64.5
TWN 7-4-11W	70	35	105	UL94V-0	M2.6×14	4 pcs	80
TWN 7-5-11W	70	50	105	UL94V-0	M2.6×14	4 pcs	94.5
TWN 7-3-13W	65	25.8	130	UL94V-0	M3×16	4 pcs	85
TWN 7-5-13W	65	50.1	130	UL94V-0	M3×16	4 pcs	115.5
TWN 8-2- 8W	80	20	80	UL94V-0	M2.6×12	4 pcs	55.5
TWN 8-4- 8W	80	40	80	UL94V-0	M2.6×12	4 pcs	75
TWN 9-4-17W	85.5	35.5	170	UL94V-0	M3×16	4 pcs	151
TWN 9-6-17W	85.5	60.5	170	UL94V-0	M3×16	4 pcs	191
TWN11-5-22W	110	45.3	220	UL94V-0	M3×16	4 pcs	254
TWN11-8-22W	110	75.3	220	UL94V-0	M3×16	4 pcs	316
TWN13-3-13W	125	25	125	UL94V-0	M3×16	4 pcs	156.5
TWN13-5-13W	125	45	125	UL94V-0	M3×16	4 pcs	190
TWN13-3-18W	125	25	175	UL94V-0	M3×16	4 pcs	206.5
TWN13-5-18W	125	45	175	UL94V-0	M3×16	4 pcs	249
TWN13-7-18W	125	65	175	UL94V-0	M3×16	4 pcs	290.5