


Color code

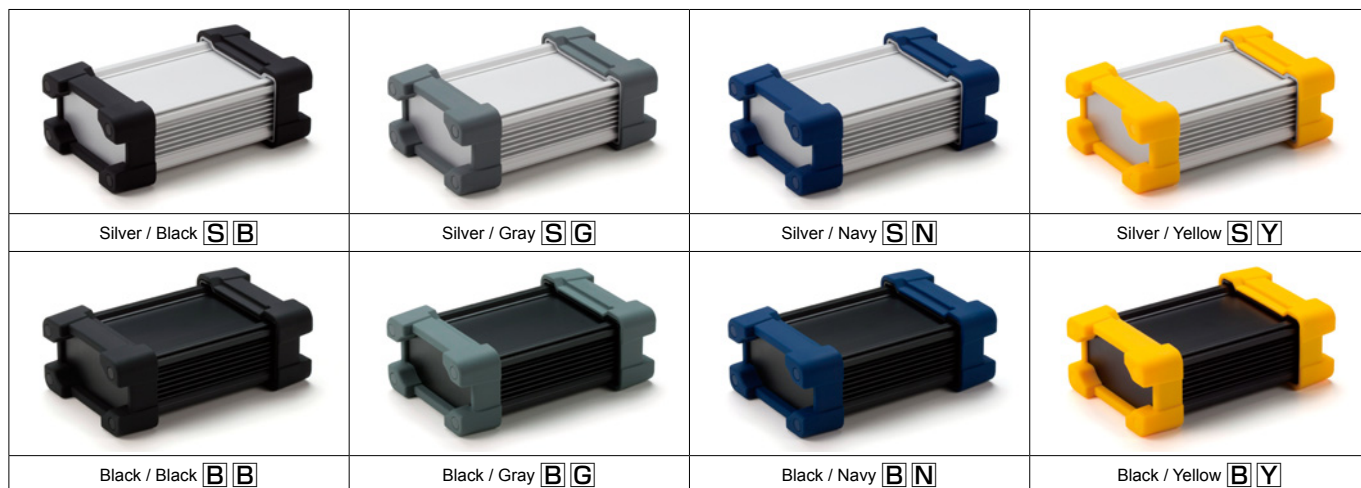

Ordering Number

For example, ordering AWP 7-7-8 Black enclosure and Navy silicone protector.

Part No. : **AWP7-7-8** **B** **N**

Fill out a color code SB, SG, SN, SY, BB, BG, BN or BY.

※ Thermal resistance test condition

- Ambient air cooling
- Heat-sink fins are vertically set to the ground at 60 degrees C
- Anodized aluminium extrusion
- Put a heat source on all the inner side surface of heat-sink fins

Part no. / Dimensions

Part no.	W	H	D	※ Thermal resistance rate (°C/W)
AWP 7-7-8	72.4(65.8)	73.6(65.8)	104 (80)	4.41
AWP 7-7-11	72.4(65.8)	73.6(65.8)	134(110)	3.5
AWP 7-7-15	72.4(65.8)	73.6(65.8)	174(150)	2.83
AWP 7-7-20	72.4(65.8)	73.6(65.8)	224(200)	2.33
AWP 7-7-25	72.4(65.8)	73.6(65.8)	274(250)	2.02
AWP 8-5-9	87.4(80.8)	53.6(45.8)	114 (90)	5.97
AWP 8-5-12	87.4(80.8)	53.6(45.8)	139(115)	5.01
AWP 8-5-14	87.4(80.8)	53.6(45.8)	164(140)	4.37
AWP 8-5-18	87.4(80.8)	53.6(45.8)	199(175)	3.76
AWP 9-9-10	93.9(86.3)	95.1(86.3)	130(100)	3.1
AWP 9-9-13	93.9(86.3)	95.1(86.3)	155(125)	2.63
AWP 9-9-17	93.9(86.3)	95.1(86.3)	200(170)	2.12
AWP 9-9-22	93.9(86.3)	95.1(86.3)	250(220)	1.79
AWP 9-9-28	93.9(86.3)	95.1(86.3)	305(275)	1.54
AWP11-6-11	113.9(106.3)	65.1(56.3)	140(110)	4.52
AWP11-6-15	113.9(106.3)	65.1(56.3)	180(150)	3.62
AWP11-6-19	113.9(106.3)	65.1(56.3)	220(190)	3.08
AWP11-6-24	113.9(106.3)	65.1(56.3)	270(240)	2.64
NEW AWP12-8-11	127.6(120)	80.1(71.3)	135(105)	3.6
NEW AWP12-8-14	127.6(120)	80.1(71.3)	170(140)	2.93
NEW AWP12-8-17	127.6(120)	80.1(71.3)	209.5(179.5)	2.47
NEW AWP12-8-22	127.6(120)	80.1(71.3)	245(215)	2.18
AWP16-9-14	163.9(156.3)	90.1(81.3)	165(135)	2.64
AWP16-9-18	163.9(156.3)	90.1(81.3)	205(175)	2.2
AWP16-9-23	163.9(156.3)	90.1(81.3)	255(225)	1.86
AWP16-9-28	163.9(156.3)	90.1(81.3)	305(275)	1.63
NEW AWP21-9-17	213.9(206.3)	90.1(81.3)	202(170)	2.3
NEW AWP21-9-21	213.9(206.3)	90.1(81.3)	242(210)	1.99
NEW AWP21-9-26	213.9(206.3)	90.1(81.3)	292(260)	1.72
NEW AWP21-9-31	213.9(206.3)	90.1(81.3)	342(310)	1.54

• numbers in () shows enclosure size.

AWP Exploded view

See page 127 to 130 for the dimensions.

