


CF SERIES

CF SLOPED ENCLOSURE

Technical data
Protection class IP40

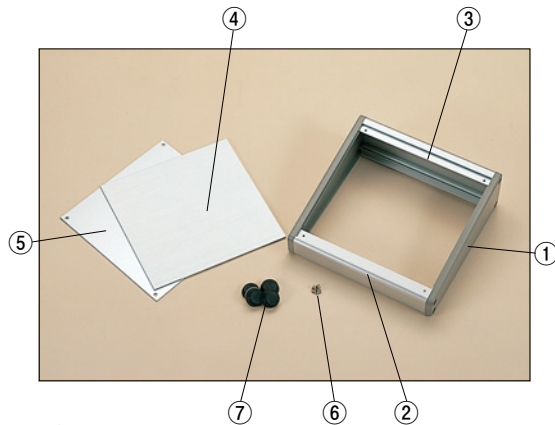

FEATURE

- Very simple design box has 10° inclination for superior operability.
- Both slide panel and screwed panel can be used as the front panel.
- Suitable for console or control device.

Components

Ref. #	Part name	Pcs	Material	Color / Finish
1	Side plate	2	ABS (UL94V-0)	Black · Gray
2	Front frame	1	Aluminium extrusion	Silver · Black / Anodized
3	Rear frame	1	Aluminium extrusion	Silver · Black / Anodized
4	Slide panel	1	Aluminium t1.5	Black painted
			Aluminium t1.5	Silver anodized hair-line finish
5	Screwed panel	1	Aluminium t1.5	Black painted
			Aluminium t1.5	Silver anodized hair-line finish
6	Screw	1 set	Steel	Black trivalent chromate · Nickel painted
7	Rubber feet	4	Rubber	Black

Color Type

Color code	Frame color	Side plate
BB	Black	Black
GS	Silver	Gray

Part no. / Dimensions

Part no.	W	H1	H2	D	a	Weight(kg)
CF 7-11□□	70	28.4	48.3	111	57	0.15
CF 11-11□□	110	28.4	48.3	111	97	0.21
CF 16-11□□	160	28.4	48.3	111	147	0.29
CF 22-11□□	220	28.4	48.3	111	207	0.38
CF 28-11□□	280	28.4	48.3	111	267	0.47
CF 12-18□□	120	32.4	66.2	181.3	104	0.38
CF 18-18□□	180	32.4	66.2	181.3	164	0.53
CF 27-18□□	270	32.4	66.2	181.3	254	0.76
CF 35-18□□	350	32.4	66.2	181.3	334	0.97
CF 43-18□□	430	32.4	66.2	181.3	414	1.17

• Please suffix color code at the end of part number □□ when ordering CF series.

Part no.	W	H1	H2	D	a	Weight(kg)
CF 15-23□□	150	39.6	79.7	230.9	131	0.52
CF 21-23□□	210	39.6	79.7	230.9	191	0.7
CF 27-23□□	270	39.6	79.7	230.9	251	0.88
CF 36-23□□	360	39.6	79.7	230.9	341	1.14
CF 45-23□□	450	39.6	79.7	230.9	431	1.41
CF 21-28□□	210	49.8	98.6	281	191	0.93
CF 28-28□□	280	49.8	98.6	281	261	1.17
CF 36-28□□	360	49.8	98.6	281	341	1.46
CF 45-28□□	450	49.8	98.6	281	431	1.77