


BFL · CK · MT SERIES

Optional parts


BFL PLASTIC MOUNTING BRACKET

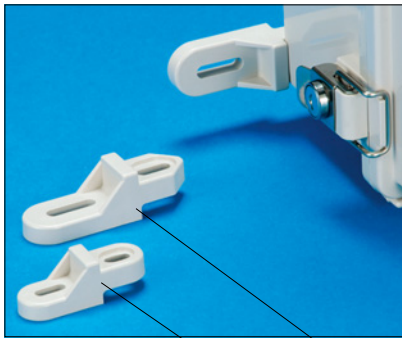

FEATURE

Color G Color S

- Very high strength by glass fiber reinforced PC.

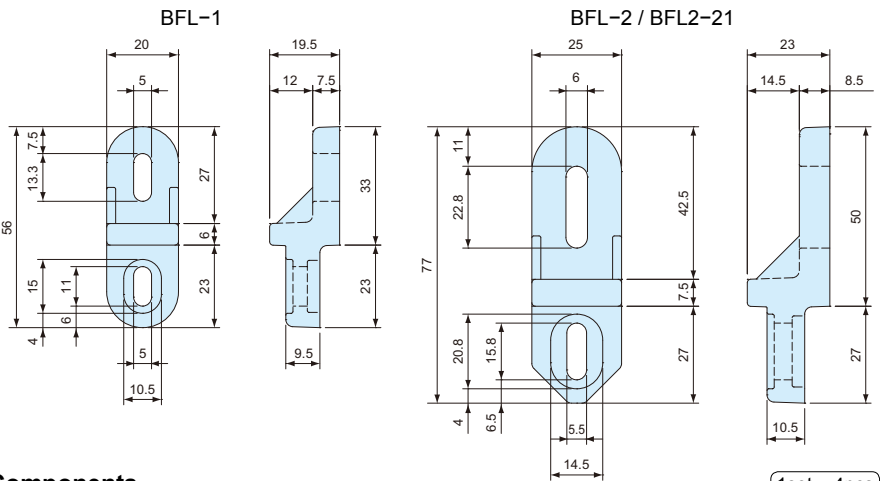

1set = 4pcs

Color Type

Color code	Color
G	White gray
S	Light gray

Components

Part name	Material	Color	Pcs
Mounting bracket	Glass fiber reinforced PC	White gray · Light gray	4
Screw	Stainless steel	Unfinished	4



Part no.

- Please suffix color code at the end of part number □ when ordering BFL series.

Part no.	Suitable box	Screw size
BFL-1□	BCAP · K · R, BCPC · K · R 0912, 1015, 1121, 1126, 1315, 1318, 1621, 1626, 1722, 1727, 212113	M4×12
BFL-2□	BCAP · K · R, BCPC · K · R 1928, 2030, 2535, 2828, 2838, 3030, 3040, 3535, 3545, 4050, 4060, 5060	M5×12
BFL-2-21□	BCAP · K · R, BCPC · K · R 212110	M4×12

- Do not fit for BCAP1515. Use CK-35P instead.

CK MOUNTING BRACKET

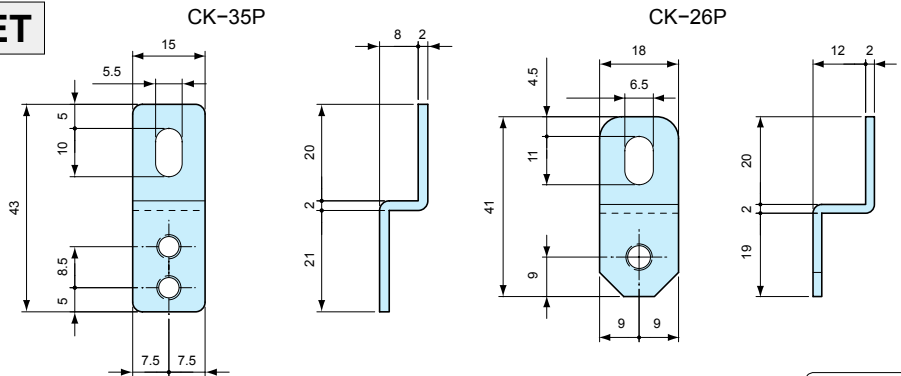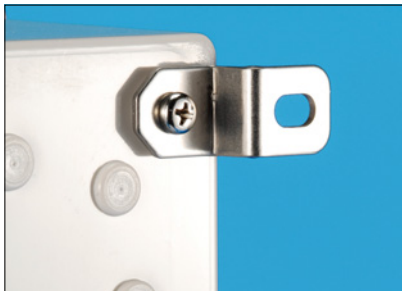

1set = 4pcs

Components

Part name	Pcs	Material	Finish
Mounting bracket	4	Stainless steel	Barrel finish
Screw	4	Stainless steel	Unfinished

Part no.

Part no.	Suitable box	Screw
CK-35P	BCAP · K · R, BCPC · K · R 0912, 1015, 1121, 1126, 1315, 1318, 1515, 1621, 1626, 1722, 1727, 2121	M4×10
CK-26P	BCAP · K · R, BCPC · K · R 1928, 2030, 2535, 2828, 2838, 3030, 3040, 3535, 3545, 4050, 4060	M5×10

MT MOUNTING SCREW



- Tapping screw for M4, M5 boss.

Part no.

1pack = 20pcs

Part no.	Pcs	Material	Finish
MT4-8T	20	Steel M4, tapping	Trivalent chromate
MT5-8T	20	Steel M5, tapping	Trivalent chromate

Available box list

Part no.	Suitable box
MT4-8T	BCAP · K · R, BCPC · K · R 0912, 1015, 1121, 1126, 1315, 1318, 1515, 1621, 1626, 1722, 1727, 1928, 2121
MT5-8T	BCAP · K · R, BCPC · K · R 2030, 2535, 2828, 2838, 3030, 3040, 3535, 3545, 4050, 4060, 5060, 5070, 6080