


STB·STC SERIES

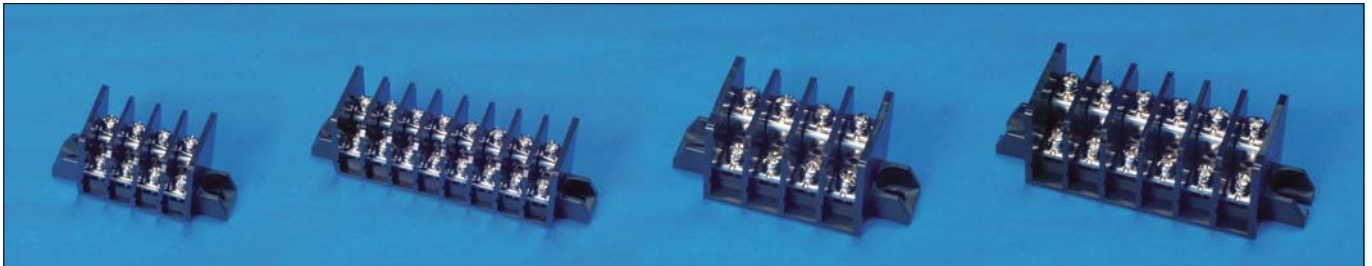

STB TERMINAL BLOCK




- Best fit terminal blocks for SPCM, SPCP series enclosures.

Components

Ref. #	Part name	Pcs	Material	Color / Finish
1	Bass	1	PBT (UL94V-0)	Black
2	Terminal	1	Brass	Nickel plated
3	Terminal screw	2×P	steel 814=M3×8/815=M4×10	Nickel plated
—	Mounting screw	2	steel M4×10 Tapping	Trivalent chromate

STB Dimensions


STB814-□P

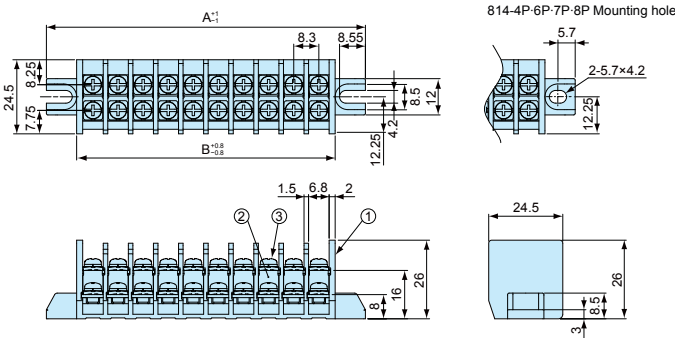

Specification

- | | |
|--------------------------|----------------|
| 1. Electrical Rting | 300V 30A |
| 2. Insulation Resistance | DC500V 1000MΩ~ |
| 3. Withstand Voltage | AC2500V |
| 4. Operating Temp Range | -25°C~+80°C |
| 5. Storage Temp Range | -25°C~+80°C |

STB815-□P

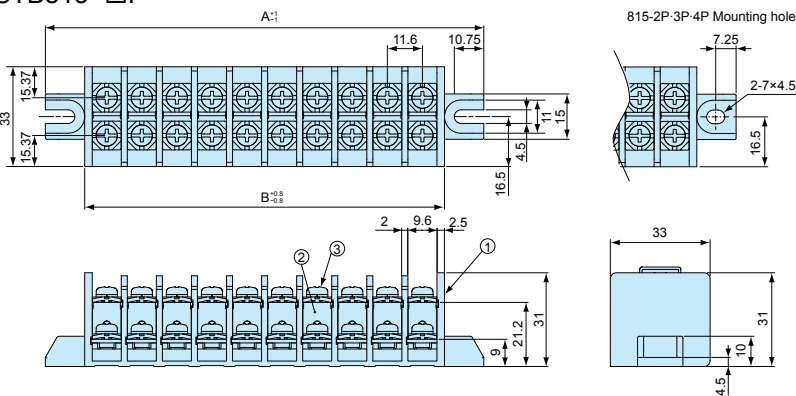

Specification

- | | |
|--------------------------|--------------------------------|
| 1. Electrical Rting | 300V 30A
(600V 30A JIS IEC) |
| 2. Insulation Resistance | DC500V 1000MΩ~ |
| 3. Withstand Voltage | AC2500V |
| 4. Operating Temp Range | -25°C~+80°C |
| 5. Storage Temp Range | -25°C~+80°C |

Part no. / Dimensions

Part no.	P (Number of poles)	A	B	Suitable SPCM · SPCP enclosure W×D size
STB814-3P	3	47.4	27.4	75×125
STB814-4P	4	55.7	35.7	100×100
STB814-6P	6	72.3	52.3	175×175
STB814-7P	7	80.6	60.6	100×100
STB814-8P	8	88.9	68.9	75×125, 125×125
STB814-9P	9	97.2	77.2	125×125, 125×175, 175×250
STB814-10P	10	105.5	85.5	125×175, 175×250
STB815-2P	2	52.2	26.2	75×125
STB815-3P	3	63.8	37.8	100×100
STB815-4P	4	75.4	49.4	125×125
STB815-6P	6	98.6	72.6	125×125, 125×175, 175×250
STB815-10P	10	145	119	175×175, 175×250