


DR-B (ネジ軸タイプ) RoHS

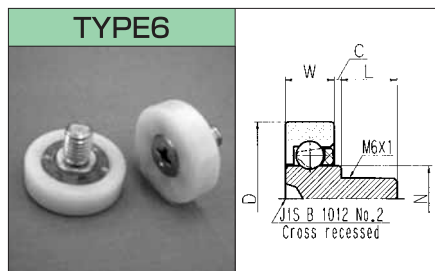

Code	Part No.	D _{-0.1} [mm]	W _{-0.2} [mm]	C ^{±0.4} [mm]	L ^{±0.5} [mm]	N [mm]	Load*1 [N] (kgf)	Type	Q'ty [pcs/box]	Gross Weight [kg/box]
020200	DR-19-B0.5	19	6	0.5	8	(8.2)	49 (5)	6	2,000	12.5
020207	DR-19-B1-14	19	6	1	14	(8.2)	49 (5)	6	1,500	11.1
020208	DR-19-B1.5	19	6	1.5	8	(8.2)	49 (5)	6	2,000	12.9
020212	DR-19-B3.5	19	6	3.5	8	(8.2)	49 (5)	6	1,500	11.0
020404	DR-22-B0.5-4.5	22	7	0.5	4.5	(9.5)	196 (20)	6	1,000	8.4
020400	DR-22-B0.5	22	7	0.5	8	(9.5)	196 (20)	6	1,000	9.8
020408	DR-22-B1-10	22	7	1	10	(9.5)	196 (20)	6	1,000	9.5
020428	DR-22-B3-10.5	22	7	3	10.5	(9.5)	196 (20)	6	1,000	11.5
020427	DR-22-B3.6-12.4	22	7	3.6	12.4	(9.5)	196 (20)	6	1,000	10.9
020415	DR-22-B3.6-14.5	22	7	3.6	14.5	(9.5)	196 (20)	6	1,000	11.9
020600	DR-24-B0.5	24	7	0.5	8	(9.5)	196 (20)	6	1,000	10.4
020608	DR-24-B3-10.5	24	7	3	10.5	(9.5)	196 (20)	6	1,000	11.7
020702	DR-26-B0.5-4.5	26	7	0.5	4.5	(9.5)	196 (20)	6	1,000	9.7
020700	DR-26-B0.5	26	7	0.5	8	(9.5)	196 (20)	6	1,000	10.1
020720	DR-26-B3-10.5	26	7	3	10.5	(9.5)	196 (20)	6	800	10.7
020719	DR-26-B3.6-12.4	26	7	3.6	12.4	(9.5)	196 (20)	6	800	11.3
020714	DR-26-B5-11	26	7	5	11	(9.5)	196 (20)	6	800	8.8
020800	DR-28-B0.5	28	7	0.5	8	(9.5)	196 (20)	6	500	6.7
020803	DR-28-B2-15	28	7	2	15	(9.5)	196 (20)	6	500	6.7
020805	DR-28-B3-10.5	28	7	3	10.5	(9.5)	196 (20)	6	500	6.9
021000	DR-30-B0.5	30	7	0.5	8	(9.5)	196 (20)	6	500	6.8
021005	DR-30-B3-10.5	30	7	3	10.5	(9.5)	196 (20)	6	500	7.6
021004	DR-30-B3.6-12.4	30	7	3.6	12.4	(9.5)	196 (20)	6	500	12.5

*1 許容荷重 (毎分300回 回転時) Allowable Load at 300min⁻¹ (300r.p.m)

*2 上記以外のサイズ・形状につきましては、弊社までご相談ください。

Each limiting size can be changed for practical application. Please ask our engineer for further information.