


IDS (高荷重/金属インサート成形品) RoHS

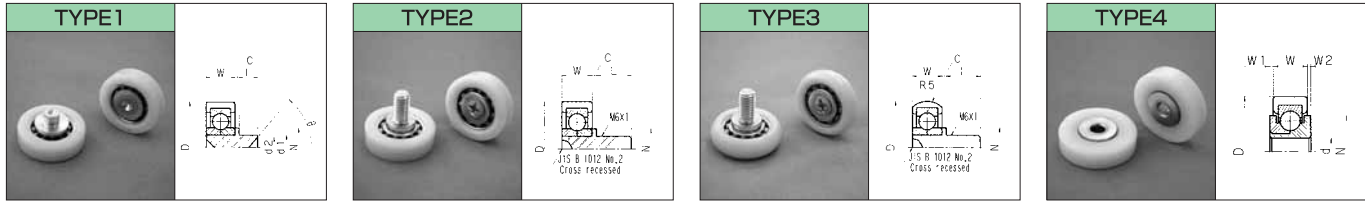


| Code | Part No. | D ^{±0.1} [mm] | d ^{+0.1} ₀ [mm] | d1 ⁰ _{-0.1} [mm] | W ^{±0.2} [mm] | C ^{±0.4} [mm] | L ^{±0.2} [mm] | (d2×θ) ^{*1} | W1 ^{*1} [mm] | W2 ^{*1} [mm] | N [mm] | Load ^{*2} [N] (kgf) | Type | Q'ty [pcs/box] | Gross Weight [kg/box] |
|--------|-------------------|---------------------------------|--|---|---------------------------|---------------------------|---------------------------|----------------------|--------------------------|--------------------------|-----------|---------------------------------|------|-------------------|--------------------------|
| 221400 | IDS-22-A1 | 22 | — | 5 | 7 | 1 | 3.5 | φ2.5×90° | — | — | (11.0) | 392 (40) | 1 | 1,000 | 12.4 |
| 221401 | IDS-22-A2.5 | 22 | — | 5 | 7 | 2.5 | 3.5 | nothing | — | — | (9.0) | 392 (40) | 1 | 1,000 | 14.0 |
| 221403 | IDS-22-A3.4-4.5 | 22 | — | 5.1 | 7 | 3.4 | 4.5 | φ2.5×90° | — | — | (9.5) | 392 (40) | 1 | 1,000 | 13.4 |
| 221450 | IDS-26-A1.5 | 26 | — | 6 | 8 | 1.5 | 3.5 | φ5.5×90° | — | — | (11.0) | 588 (60) | 1 | 800 | 15.5 |
| 221504 | IDS-22-B1.5-8 | 22 | — | — | 7 | 1.5 | 8 ^{±0.5} | — | — | — | (11.0) | 392 (40) | 2 | 1,000 | 13.2 |
| 221501 | IDS-22-B1.5-11 | 22 | — | — | 7 | 1.5 | 11 ^{±0.5} | — | — | — | (11.0) | 392 (40) | 2 | 1,000 | 15.3 |
| 221505 | IDS-22-B4-7 | 22 | — | — | 7 | 4 | 7 ^{±0.5} | — | — | — | (9.5) | 392 (40) | 2 | 1,000 | 14.5 |
| 221518 | IDS-22-B11 | 22 | — | — | 7 | 11 | 8 ^{±0.5} | — | — | — | (9.5) | 392 (40) | 2 | 1,000 | 18.6 |
| 221600 | IDS-26-B2-11 | 26 | — | — | 8 | 2 | 11 ^{±0.5} | — | — | — | (11.0) | 588 (60) | 2 | 500 | 10.2 |
| 221603 | IDS-26-B5-9 | 26 | — | — | 8 | 5 ^{±0.5} | 9 ^{±0.5} | — | — | — | (9.5) | 588 (60) | 2 | 500 | 11.1 |
| 221650 | IDS-30-B2-11 | 30 | — | — | 9 | 2 | 11 ^{±0.5} | — | — | — | (11.0) | 588 (60) | 2 | 500 | 12.1 |
| 221700 | IDS0-26-B2-11 | 26 ⁰ _{-0.2} | — | — | 8 | 2 | 11 ^{±0.5} | — | — | — | (11.0) | 588 (60) | 3 | 500 | 10.2 |
| 221901 | IDS-26-H6.35W0.8 | 26 | 6.35 | — | 8 | — | — | — | 0.8 | 0.8 | (17.0) | 294 (30) | 4 | 800 | 16.3 |
| 221954 | IDS-35-H6.35W0.26 | 35 ⁰ _{-0.1} | 6.35 | — | 9 | — | — | — | 0.26 | 0.26 | (17.0) | 294 (30) | 4 | 500 | 13.3 |

*1 参考値 Reference Dimension
 *2 許容荷重 (毎分300回 回転時) Allowable Load at 300min⁻¹ (300r.p.m)
 *3 上記以外のサイズ・形状につきましては、弊社までご相談ください。 Each limiting size can be changed for practical application. Please ask our engineer for further information.

DT (JISベアリング インサート成形品)

特長 1.金属ベアリングをポリアセタール樹脂でインサート成形したベアリングです。
 2.回転精度 (振れとガタツキが小さい) に優れています。
 3.高荷重での走行音を小さくすることができます。
 FEATURE 1. It is the bearing which carried out insert molding of the steel bearings by polyacetal resin.
 2. Run-out and clearance of the bearings are small.
 3. Operation noise of the bearings for high load is silent by insert molding of polyacetal resin.

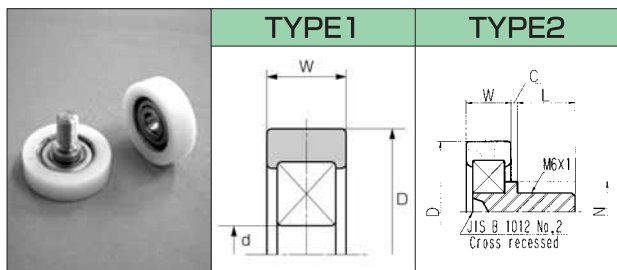

| Code | Part No. | D ^{±0.15} [mm] | d [mm] | W ^{±0.2} [mm] | C ^{±0.4} [mm] | L ^{±0.5} [mm] | N [mm] | TYPE |
|--------|---------------------|----------------------------|-----------|---------------------------------|---------------------------|---------------------------|-----------|------|
| 110070 | DT-22-688ZZ | 22 ^{±0.1} | (8) | -7 ⁰ _{-0.2} | — | — | — | 1 |
| 110056 | DT-26-H6-626ZZ | 26 | (6) | 8 | — | — | — | 1 |
| 110058 | DT-26-BH0.5-626ZZ | 26 | — | 8 | 0.5 | 8 | (10.0) | 2 |
| 110057 | DT-26-BH2-9.5-626ZZ | 26 | — | 8 | 2 | 9.5 | (10.0) | 2 |
| 110060 | DT-26-BH4-626ZZ | 26 | — | 8 | 4 | 8 | (10.0) | 2 |
| 110059 | DT-26-BH6-14-626ZZ | 26 | — | 8 | 6 | 14 | (10.0) | 2 |

※仕様は、弊社までご相談ください。 ※Please ask our engineer for further information.
 ※他のサイズでも製作検討致します。 ※Each limiting size can also be supplied.
 ※上記は受注生産品です。 ※These products manufactured to order.

トックベアリング株式会社 TOK BEARING CO.,LTD.

本社・東京営業所 TOKYO OFFICE / TEL 03-3969-1534 FAX 03-3969-9354 大阪営業所 OSAKA OFFICE / TEL 06-6368-8721 FAX 06-6368-8725
 名古屋営業所 NAGOYA OFFICE / TEL 052-735-3081 FAX 052-735-3116