


Acrylic Levels

The number next to the logo mark indicates items in stock for each brand.

TRUSCO Stock **38,650** Items

Pocket Level

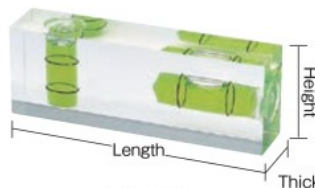


PL-25-70

- Features**
- Compact size convenient to carry.
- Use**
- To measure narrow measurement surface without use of magnet.
- Specs**
- Precision: within $\pm 2.5\text{mm/m} = \pm 0.1433^\circ$
 - Sensitivity: $0.5\text{mm/m} = 0.0286^\circ$
- Materials**
- Main Body: Acrylic Plastic (PMMA)
- Origin**
- Japan

SK Stock **1,103** Items

Mini Level

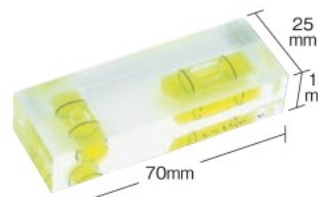

CT-70

- Features**
- Two directions: X and Y can be measured simultaneously.
- Use**
- To measure horizontally.
- Specs**
- Precision $\pm 1.5\text{mm/m}$
 - Sensitivity: 0.5mm/m
- Materials**
- Main Body: Acrylic Plastic (PMMA)
- Origin**
- Japan

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
229-7167	PL-25-70	¥1,157	¥1,250	70 x 25 x 15	None	10	30
229-7175	PL-25-100	¥1,324	¥1,430	100 x 25 x 15	None	10	43
229-7183	PL-35-70	¥1,371	¥1,480	70 x 35 x 15	None	10	42
229-7191	PL-35-100	¥1,472	¥1,590	100 x 35 x 15	None	10	60

Contact us: 0120-509-849 <http://www.orange-book.com/>


Order Unit: 1 Piece NIIGATASEIKI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
377-4996	CT-70	¥2,160	¥2,000	70 x 25 x 15	None	1	29

Contact us: 0256-31-5660 <http://www.sokuteikougou.com/>

Ebisu Stock **154** Items

Flat Level

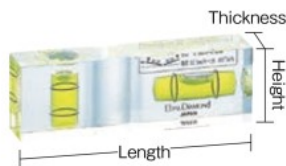

ED-FL

- Features**
- All sides can be used as measurement sides.
 - Since it is transparent, it can measure by seeing through.
 - Small and convenient for carrying.
- Use**
- For horizontal, vertical, right angle measurement.
- Specs**
- Precision: Within $\pm 2.50\text{mm/m} = \pm 0.1432^\circ$
 - Sensitivity: $0.50\text{mm/m} = 0.0286^\circ$
- Materials**
- Main Body: Acrylic Plastic (PMMA)
- Origin**
- Japan

Ebisu Stock **154** Items

Crystal Level



ED-10CL



ED-10CLS

- Features**
- All sides can be used as measurement sides.
 - Since it is transparent, it can measure by seeing through.
 - Small and convenient for carrying.
- Use**
- For horizontal, vertical, right angle measurement.
- Specs**
- Precision: Within $\pm 2.50\text{mm/m} = \pm 0.1432^\circ$
 - Sensitivity: $0.50\text{mm/m} = 0.0286^\circ$
- Materials**
- Main Body: Acrylic Plastic (PMMA)
- Origin**
- Japan

Order Unit: 1 Piece Ebisu Co. Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
410-5478	ED-FL	¥1,418	¥1,750	75 x 25 x 15	None	6	31
410-5486	ED-FLM	¥1,499	¥1,850	75 x 26 x 15	1 Side	6	36

Contact us: 0120-18-5133 <http://www.ebisu-level.co.jp/>


Order Unit: 1 Piece Ebisu Co. Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
410-4633	ED-10CL	¥1,418	¥1,750	100 x 15 x 15	None	6	25
410-4650	ED-10CLS	¥2,025	¥2,500	100 x 40 x 15	None	6	69
410-4641	ED-10CLM	¥1,499	¥1,850	100 x 15 x 16	1 Side	6	32
410-4668	ED-10CLSM	¥2,106	¥2,600	100 x 41 x 15	1 Side	6	75

Contact us: 0120-18-5133 <http://www.ebisu-level.co.jp/>

KOD

Rectangle Column Level with Mounting Holes (with attaching hole)

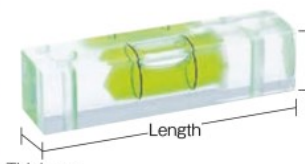

PH-25

- Features**
- Precision is excellent by acrylic scraping processing.
 - With attaching holes.
 - To measure horizontally.
- Use**
- To measure horizontally.
- Materials**
- Main Body: Acrylic Plastic (PMMA)
- Origin**
- Japan

Item No.	Precision	Sensitivity
PH-25	1.33mm/m=0.0764°	91°/2mm
PH-30	1.33mm/m=0.0764°	91°/2mm
PH-40	0.5mm/m=0.0286°	34°/2mm
PH-50	0.5mm/m=0.0286°	34°/2mm
PH-60	0.5mm/m=0.0286°	34°/2mm
PH-70	0.5mm/m=0.0286°	34°/2mm


Order Unit: 1 Piece AKATSUKI MFG.CO.LTD.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
410-0018	PH-25	¥824	¥1,220	25 x 8 x 8	None	1	1.8
410-0026	PH-30	¥810	¥1,200	30 x 10 x 10	None	1	3.3
410-0034	PH-40	¥843	¥1,250	40 x 13 x 13	None	1	10.0
410-0042	PH-50	¥897	¥1,330	50 x 15 x 15	None	1	13.0
410-0051	PH-60	¥932	¥1,380	60 x 15 x 15	None	1	14.0
410-0069	PH-70	¥966	¥1,430	70 x 15 x 15	None	1	17.0

Contact us: 0773-42-1001 <http://www.kod-level.co.jp/>

KOD

2 Way Flat Level with Mounting Holes (with attaching hole)

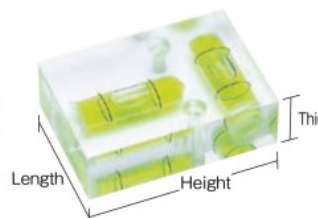

PTH-30

- Features**
- Optimum for attaching machines or equipment.
 - 2-axis vial.
- Use**
- To measure horizontally.
- Specs**
- Precision: $0.5\text{mm/m} = 0.0286^\circ$ (for PTH-30, $1.3\text{mm/m} = 0.0764^\circ$)
 - Sensitivity: $34^\circ/2\text{mm}$ (for PTH-30, $91^\circ/2\text{mm}$)
- Materials**
- Main Body: Acrylic Plastic (PMMA)
- Origin**
- Japan

Order Unit: 1 Piece AKATSUKI MFG.CO.LTD.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	L x H x Thickness (mm)	Magnet	SPQ (piece)	Weight (g)
417-0156	PTH-30	¥999	¥1,480	20 x 30 x 10	None	1	7
417-0164	PTH-40	¥1,020	¥1,510	25 x 40 x 13	None	1	14
417-0172	PTH-50	¥1,032	¥1,530	35 x 50 x 15	None	1	29
417-0181	PTH-70	¥1,074	¥1,590	25 x 70 x 15	None	1	29

Contact us: 0773-42-1001 <http://www.kod-level.co.jp/>