


Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

Milling Vise




MF-150

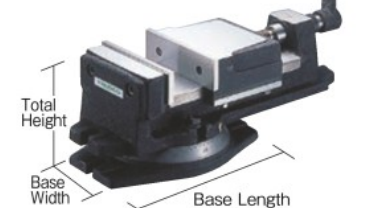

KV-150 (with rotating base)



 MFKV150001 (cap set)




MFKV130003 (handle)



MFKV130004 (shaft)

 - Features**
- Durability and durable design across each part.
 - Mounted on a milling machine, mainly used for rough machining.
- Materials** •Ordinary cast iron (FC250) **Origin** •Taiwan



Warning

- There is no guide block as well as the hole for mounting the guide block. Please fix with jigs such as T jack nut, stat bolt, etc.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length x Total Width x Total Height (mm)	Opening Width (mm)	Opening (mm)	Opening Depth (mm)	Max Tightening Power (kN)	SPQ (piece)	Weight (kg)
121-6309	MF-100	¥ 30,243	¥ 32,670	310 x 123 x 84	102	65	35	7.84	1	8
121-6317	MF-130	¥ 42,055	¥ 45,430	382 x 148 x 98	132	82	37	9.80	1	12
121-6325	MF-150	¥ 45,415	¥ 49,060	465 x 183 x 109	153	112	43	12.74	1	21
121-6333	MF-200	¥ 100,810	¥ 108,900	608 x 233 x 145	204	146	63	16.66	1	43

With Rotating Base **Features** •The upper vise part can be rotated 360° left and right.

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Vise Length x Vise Width (mm)	Base Length x Base Width x Total Height (mm)	Opening Width (mm)	Opening (mm)	Opening Depth (mm)	Max Tightening Power (kN)	SPQ (piece)	Weight (kg)
121-6406	KV-100	¥ 34,520	¥ 37,290	310 x 123	175 x 123 x 112	102	65	35	7.84	1	10
121-8280	KV-125	¥ 46,332	¥ 50,050	382 x 148	209 x 148 x 131	132	82	37	9.80	1	17
121-6422	KV-150	¥ 52,951	¥ 57,200	465 x 183	257 x 183 x 150	153	112	43	12.74	1	27
121-6431	KV-200	¥ 104,883	¥ 113,300	608 x 233	350 x 233 x 189	204	150	63	16.66	1	57

Cap Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Compatible Model	SPQ (set)	Weight (g/set)
342-6815	MFKV100001	¥ 5,350	¥ 5,780	MF-100, KV-100	1	650
342-6823	MFKV130001	¥ 5,962	¥ 6,440	MF-130, KV-125	1	860
342-6831	MFKV150001	¥ 6,879	¥ 7,430	MF-150, KV-150	1	1260
342-6840	MFKV200001	¥ 8,655	¥ 9,350	MF-200, KV-200	1	2890

Handle

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Model	Opposite Side Dimension (mm)	SPQ (piece)	Weight (g)
414-9726	MFKV100003	¥ 2,240	¥ 2,420	MF-100, KV-100	15.5	1	453
414-9742	MFKV130003	¥ 2,240	¥ 2,420	MF-130, KV-125	15.5	1	467
414-9769	MFKV150003	¥ 2,343	¥ 2,530	MF-150, KV-150	17.0	1	631
414-9785	MFKV200003	¥ 4,073	¥ 4,400	MF-200, KV-200	22.0	1	1113

Shaft

Order Unit: 1 Piece

(Price revision date: Jan, 2017)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Model	SPQ (piece)	Weight (g)
414-9734	MFKV100004	¥ 4,073	¥ 4,400	MF-100, KV-100	1	343
414-9751	MFKV130004	¥ 5,804	¥ 6,270	MF-130, KV-125	1	427
414-9777	MFKV150004	¥ 6,211	¥ 6,710	MF-150, KV-150	1	678
414-9793	MFKV200004	¥ 9,521	¥ 10,285	MF-200, KV-200	1	1321

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Lead Vice (square shaft)



LV-125N

- Features**
- A strong body that holds strong tightening force.

- Materials** •Main Body: Cast Iron
•Shaft, Handle, Cap: Steel Material **Origin** •Taiwan

Mounting Hole Diameter (mm)
14

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length x W x H (mm)	Opening Width (mm)	Opening (mm)	Opening Depth (mm)	Mounting Dimension (mm)		Clamping Force (kN)	SPQ (piece)	Weight (kg)
								G	H			
287-0746	LV-100N	¥ 19,754	¥ 21,340	350 x 165 x 175	104	110	76	74	128	20	1	14.0
287-0754	LV-125N	¥ 28,003	¥ 30,250	445 x 176 x 204	129	140	83	91	141	25	1	22.0
287-0762	LV-150N	¥ 39,204	¥ 42,350	500 x 198 x 217	154	190	86	116	154	30	1	29.6
819-1317	LV-200N	¥ 86,091	¥ 93,000	520 x 215 x 245	206	220	105	125	152	60	1	38.5

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Drilling Machine Vise F Type



FV-125

- Features**
- Made of cast iron which is hard to break even in strong work.
 - A handle bar that does not fall out.

- Materials** •Main Body: Cast Iron
•Cap: Steel Material **Origin** •Taiwan



Warning

- Sole plane processing is not precisely finished.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length x W x H (mm)	Opening Width (mm)	Opening (mm)	Opening Depth (mm)	Mounting Dimension (mm)	Clamping Force (kN)	SPQ (piece)	Weight (kg)
125-6921	FV-75	¥ 6,567	¥ 7,095	160 x 136 x 58	77	80	30	110	8.0	6	2.7
125-6939	FV-100	¥ 7,766	¥ 8,390	180 x 160 x 63	100	100	32	130	10.0	6	3.6
125-6947	FV-125	¥ 12,016	¥ 12,980	225 x 193 x 71	125	129	38	158	12.5	4	5.8
125-6955	FV-150	¥ 15,006	¥ 16,210	255 x 221 x 80	151	150	40	182	15.0	2	8.2

Contact us:0120-509-849 <http://www.orange-book.com/>