




Stock
38,650
Items

C-Clamp (BAHCO type)

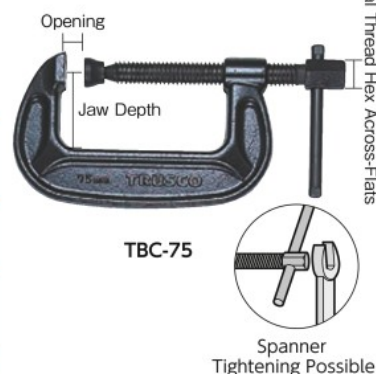

TBC-75

Spanner
Tightening Possible

- Features** • A tool to pinch and fix a work piece between two opposite surfaces during work piece processing and assembly work.
- Specs** • Black finish coating
• Forged product
- Materials** • Carbon Steel (S55C)
- Accessories** • Screw
• Cap
• Ring
- Origin** • Japan

Warning
• Impact wrench can not be used.



Example

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Opening (mm)	Jaw Depth (mm)	External Thread Hex Across-Flats (mm)	Clamping Pressure (kN)	SPQ (piece)	Weight (kg)
230-2845	TBC-25	¥1,509	¥1,630	25	26	12	17.6	6	0.23
230-2853	TBC-38	¥1,759	¥1,900	38	30	12	19.4	6	0.28
230-2861	TBC-50	¥2,027	¥2,190	50	36	14	20.5	6	0.42
230-2870	TBC-75	¥2,629	¥2,840	75	46	14	26.4	6	0.80
230-2888	TBC-100	¥3,990	¥4,310	100	56	14	30.3	6	1.20
230-2896	TBC-125	¥5,156	¥5,570	125	66	17	35.2	2	2.00
230-2900	TBC-150	¥6,786	¥7,330	150	76	19	39.2	2	2.85
234-1174	TBC-200	¥9,803	¥10,590	200	95	22	44.1	2	4.30

Cap/Ring

Order Unit: 1 Piece

TBC-25-CR
(Cap/Ring)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Length (mm)	Compatible Model	SPQ (piece)	Weight (g)
490-1967	TBC-25-CR	¥381	¥470	15.9	9.6	TBC-25	5	9
490-1975	TBC-38-CR	¥437	¥540	15.9	9.6	TBC-38	5	9
490-1983	TBC-50-CR	¥502	¥620	15.9	9.6	TBC-50	5	9
490-1991	TBC-75-CR	¥632	¥780	18.0	12.5	TBC-75	5	13
490-2009	TBC-100-CR	¥713	¥880	21.8	14.0	TBC-100	5	22
490-2017	TBC-125-CR	¥802	¥990	23.8	17.0	TBC-125	5	28
490-2025	TBC-150-CR	¥981	¥1,210	26.8	20.0	TBC-150	5	44
490-2033	TBC-200-CR	¥1,102	¥1,360	29.8	21.5	TBC-200	5	60

Screw/Cap/Ring

Order Unit: 1 Piece


TBC-25-NCR
(Screw/Cap/Ring)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Screw Diameter (mm)	Length (mm)	Compatible Model	SPQ (piece)	Weight (g)
490-1827	TBC-25-NCR	¥1,004	¥1,240	15.9	9.8	85.0	TBC-25	5	62
490-1835	TBC-38-NCR	¥1,166	¥1,440	15.9	9.8	101.5	TBC-38	5	72
490-1843	TBC-50-NCR	¥1,377	¥1,700	15.9	11.8	115.5	TBC-50	5	108
490-1851	TBC-75-NCR	¥1,782	¥2,200	18.0	13.8	154.0	TBC-75	5	196
490-1860	TBC-100-NCR	¥2,657	¥3,280	21.8	15.7	189.0	TBC-100	5	284
490-1878	TBC-125-NCR	¥3,524	¥4,350	23.8	17.8	222.0	TBC-125	5	416
490-1886	TBC-150-NCR	¥4,860	¥6,000	26.8	19.8	258.5	TBC-150	5	624
490-1894	TBC-200-NCR	¥6,723	¥8,300	29.8	21.9	316.0	TBC-200	5	912

Contact us:0120-509-849 <http://www.orange-book.com/>

Stock
1,160
Items

C-Clamp (BAHCO type)

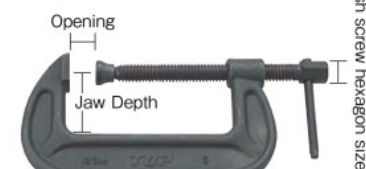

SC-125

- Features** • Strong, precise, durable for long time use.
• Enables speedy operation because of the attached handle.
• Enables safe use without break and twist.
- Materials** • Carbon Steel
- Origin** • Japan

Order Unit: 1 Piece

(Price revision date: Apr, 2016) TOP KOGYO Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Opening (mm)	Jaw Depth (mm)	Push screw hexagon size (mm)	Guaranteed load (t)	SPQ (piece)	Weight (kg)
396-2547	SC-25	¥1,620	¥2,100	25	25	12	2.4	6	0.22
396-2571	SC-38	¥1,890	¥2,450	40	32	12	2.5	6	0.32
396-2580	SC-50	¥2,199	¥2,850	52	37	14	2.6	6	0.45
396-2598	SC-75	¥2,854	¥3,700	77	45	14	2.8	6	0.80
396-2504	SC-100	¥4,281	¥5,550	102	56	17	3.0	6	1.20
396-2512	SC-125	¥5,593	¥7,250	126	65	19	3.3	2	2.00
396-2521	SC-150	¥7,059	¥9,150	153	76	22	3.6	2	2.80
396-2539	SC-200	¥11,070	¥14,350	200	96	24	4.0	2	3.90
396-2555	SC-250	¥19,787	¥25,650	252	111	26	6.0	1	5.50
396-2563	SC-300	¥34,329	¥44,500	305	125	27	7.0	1	10.50

Contact us:0256-33-1681 <http://www.toptools.co.jp/>