


TRUSCO Stock 38,650 Items

Stainless Steel C-Clamp (BAHCO type)

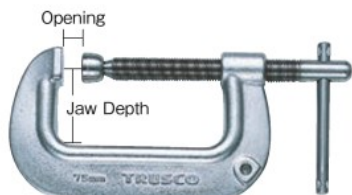

- Features**
- Made of SS304 difficult to rust and corrode.
 - A tool to pinch and fix a workpiece between 2 opposite surfaces during workpiece processing and assembly work.
- Materials**
- Body: Stainless steel (SUS304)
 - Jaw/screw: Stainless steel (SUS304)
- Origin**
- Japan



TSC-75



TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece


| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Max Opening (mm) | Jaw Depth (mm) | Clamping Pressure (kN) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------|----------------|------------------------|-------------|-------------|
| 234-1247 | TSC-25 | ¥ 4,619 | ¥ 4,990 | 25 | 27 | 2.6 | 6 | 0.34 |
| 234-1255 | TSC-50 | ¥ 5,721 | ¥ 6,180 | 50 | 38 | 3.5 | 6 | 0.47 |
| 234-1263 | TSC-75 | ¥ 8,118 | ¥ 8,770 | 75 | 46 | 5.2 | 6 | 0.84 |
| 234-1271 | TSC-100 | ¥ 12,154 | ¥ 13,130 | 100 | 56 | 8.8 | 6 | 1.47 |

Contact us: 0120-509-849 <http://www.orange-book.com/>


LOBTEX Stock 1,809 Items

Stainless Steel C-Clamp (BAHCO type)

- Features**
- Made of stainless steel resistant to rust and corrosion, optimum for food factory, ocean relation and chemical factory.
 - There is nothing wrong with it in continuous salt water spray testing for 120 hours.
 - The swing angle of the movable jaw is 20°.
 - The movable jaw can be attached again when it comes off.
- Materials**
- Main body: Stainless steel (SUS329J1) forged product
 - Jaw/screw: Stainless steel (SUS304)
- Origin**
- Japan

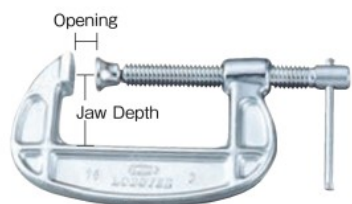

B75S

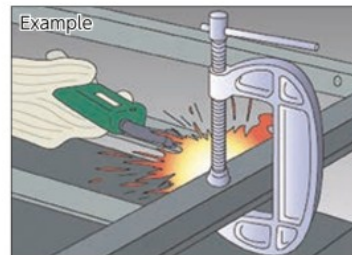

(Price revision date: Jan, 2016) LOBTEX Co.Ltd.

Order Unit: 1 Piece


| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Max Opening (mm) | Jaw Depth (mm) | Clamping Pressure (kN) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------|----------------|------------------------|-------------|-------------|
| 295-5873 | B25S | ¥ 4,685 | ¥ 4,960 | 25.0 | 19 | - | 6 | 0.13 |
| 295-5881 | B38S | ¥ 5,144 | ¥ 5,440 | 38.0 | 26 | - | 6 | 0.17 |
| 295-5890 | B50S | ¥ 5,805 | ¥ 6,140 | 50.0 | 34 | - | 6 | 0.32 |
| 295-5903 | B75S | ¥ 7,743 | ¥ 8,190 | 75.0 | 46 | - | 6 | 0.74 |
| 295-5911 | B100S | ¥ 11,448 | ¥ 12,110 | 100.0 | 60 | - | 6 | 1.50 |

Contact us: 072-980-1111 <http://www.lobtex.co.jp/>


LOBTEX Stock 1,809 Items

C-Clamp (C Type)

- Features**
- The jaw is deeper and the depth is sufficient compared with the conventional C-clamp.
 - The head can be securely tightened with a hexagonal wrench.
 - Optimum for heavy weight object installation.
 - The handle is removable.
- Materials**
- Special Steel (main body: forged product)
- Origin**
- Japan

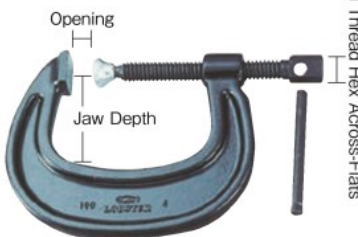

C100

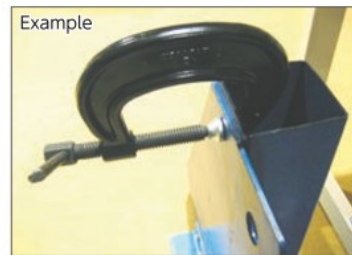

(Price revision date: Jan, 2016) LOBTEX Co.Ltd.

Order Unit: 1 Piece

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Max Opening (mm) | Jaw Depth (mm) | External Thread Hex Across-Flats (mm) | Clamping Pressure (kN) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|------------------|----------------|---------------------------------------|------------------------|-------------|-------------|
| 125-0639 | C50 | ¥ 3,875 | ¥ 4,100 | 50 | 65.0 | 19 | - | 6 | 0.92 |
| 125-0647 | C75 | ¥ 4,860 | ¥ 5,140 | 75 | 79.0 | 21 | - | 6 | 1.53 |
| 125-0655 | C100 | ¥ 6,885 | ¥ 7,290 | 100 | 99.0 | 23 | - | 3 | 2.55 |
| 125-0663 | C125 | ¥ 9,888 | ¥ 10,460 | 125 | 125.0 | 26 | - | 3 | 3.62 |
| 125-0671 | C150 | ¥ 14,162 | ¥ 14,990 | 150 | 150.0 | 26 | - | 3 | 5.50 |
| 125-0680 | C200 | ¥ 29,633 | ¥ 31,360 | 200 | 201.0 | 29 | - | 1 | 9.88 |

Contact us: 072-980-1111 <http://www.lobtex.co.jp/>

More reliable tightening with wrenches

