

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

C-Clamp (standard type)



TC-100S

- Features • Lighter than the clamp of the same dimension, and easy to work.
 Specs • Chrome Plate
 Materials • Cold Rolled Steel Material
 Origin • Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Opening (mm)	Jaw Depth (mm)	SPQ (piece)	Weight (kg)
490-1533	TC-50S	¥ 2,673	¥ 3,300	50	50	10	0.44
490-1541	TC-75S	¥ 3,054	¥ 3,770	75	50	10	0.63
490-1550	TC-100S	¥ 3,929	¥ 4,850	100	60	10	1.02
490-1568	TC-150S	¥ 4,973	¥ 6,140	150	75	10	1.46
490-1576	TC-200S	¥ 6,431	¥ 7,940	200	90	10	2.29
490-1584	TC-250S	¥ 10,125	¥ 12,500	250	100	5	4.12

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

C-Clamp (middle type)



TC-100M

- Features • Lighter than the clamp of the same dimension, and easy to work.
 Specs • Chrome Plate
 Materials • Cold Rolled Steel Material
 Origin • Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Opening (mm)	Jaw Depth (mm)	SPQ (piece)	Weight (kg)
490-1592	TC-50M	¥ 2,876	¥ 3,550	50	65	10	0.46
490-1606	TC-75M	¥ 3,289	¥ 4,060	75	80	10	0.74
490-1614	TC-100M	¥ 4,237	¥ 5,230	100	100	10	1.20
490-1622	TC-125M	¥ 5,200	¥ 6,420	125	125	10	1.60
490-1631	TC-150M	¥ 6,829	¥ 8,430	150	150	8	2.40
490-1649	TC-200M	¥ 9,558	¥ 11,800	200	200	4	4.08
490-1657	TC-250M	¥ 11,664	¥ 14,400	250	250	2	5.94

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

C-Clamp (long type)



TC-200L

- Features • Lighter than the clamp of the same dimension, and easy to work.
 Specs • Chrome Plate
 Materials • Cold Rolled Steel Material
 Origin • Taiwan

Order Unit: 1 Piece


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Opening (mm)	Jaw Depth (mm)	SPQ (piece)	Weight (kg)
490-1665	TC-100L	¥ 3,110	¥ 3,840	100	50	10	0.55
490-1673	TC-125L	¥ 3,240	¥ 4,000	125	65	10	0.63
490-1681	TC-150L	¥ 3,758	¥ 4,640	150	75	10	0.93
490-1690	TC-200L	¥ 4,860	¥ 6,000	200	100	10	1.54
490-1703	TC-250L	¥ 6,221	¥ 7,680	75 to 250	115	10	2.07
490-1711	TC-300L	¥ 7,954	¥ 9,820	100 to 300	125	8	2.91
490-1720	TC-350L	¥ 10,773	¥ 13,300	100 to 350	150	4	4.64
490-1738	TC-400L	¥ 12,879	¥ 15,900	150 to 400	175	2	6.14

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

C-Clamp (deep jaw type)

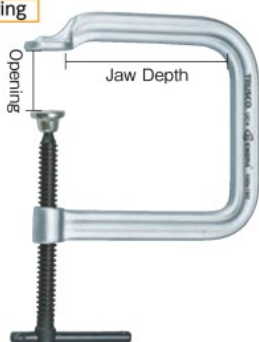

TC-100D

- Features • Lighter than the clamp of the same dimension, and easy to work.
 Specs • Chrome Plate
 Materials • Cold Rolled Steel Material
 Origin • Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Opening (mm)	Jaw Depth (mm)	SPQ (piece)	Weight (kg)
490-1746	TC-50D	¥ 3,054	¥ 3,770	50	100	10	0.56
490-1754	TC-75D	¥ 3,540	¥ 4,370	75	125	10	0.86
490-1762	TC-100D	¥ 4,568	¥ 5,640	100	160	10	1.40
490-1771	TC-125D	¥ 5,929	¥ 7,320	125	200	10	1.95
490-1789	TC-150D	¥ 8,505	¥ 10,500	150	250	6	2.96
490-1797	TC-200D	¥ 11,826	¥ 14,600	200	350	4	5.36
490-1801	TC-250D	¥ 14,337	¥ 17,700	250	400	2	7.45

Contact us: 0120-509-849 <http://www.orange-book.com/>

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps

Bar Clamps

Special Clamps

Vices

Parts for Vices