

L Type Clamps


The number next to the logo mark indicates items in stock for each brand.

TRUSCO **Stock 38,650 Items**

L Type Clamp (standard type)



- Features**
- Standard type with a wood handle for the shaft end.
 - Optimum for wide use of applications such as carpentry work and sheet metal processing.
- Materials**
- Special Steel
- Origin**
- Japan

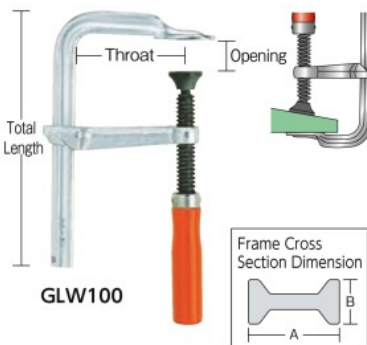

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
129-1513	GLW100	¥ 3,592	¥ 3,880	192	100	100	21.4	10.4	6	1.01
129-1521	GLW150	¥ 4,046	¥ 4,370	242	150	100	21.4	10.4	6	1.08
129-1530	GLW200	¥ 4,935	¥ 5,330	292	200	120	21.4	10.4	2	1.23
129-1548	GLW250	¥ 5,591	¥ 6,040	342	250	120	21.4	10.4	2	1.30
129-1556	GLW300	¥ 6,767	¥ 7,310	392	300	120	21.4	10.4	2	1.45
129-1564	GLW400	¥ 8,313	¥ 8,980	492	400	120	21.4	10.4	2	1.75
129-1572	GLW500	¥ 9,655	¥ 10,430	592	500	120	21.4	10.4	2	2.05
129-1581	GLW600	¥ 10,692	¥ 11,550	692	600	120	21.4	10.4	2	2.35
129-1599	GLW800	¥ 14,487	¥ 15,650	892	800	120	21.4	10.4	2	2.95
129-1602	GLW1000	¥ 18,468	¥ 19,950	1092	1000	120	21.4	10.4	2	3.55



Lightweight Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
128-9853	GLS100	¥ 2,527	¥ 2,730	168	100	60	15.6	7.5	6	400
128-9861	GLS150	¥ 2,916	¥ 3,150	218	150	60	15.6	7.5	6	450
128-9870	GLS200	¥ 3,315	¥ 3,580	268	200	80	15.6	7.5	6	510
128-9888	GLS250	¥ 3,795	¥ 4,100	318	250	80	15.6	7.5	6	560
128-9896	GLS300	¥ 4,378	¥ 4,730	368	300	80	15.6	7.5	6	600
128-9900	GLS400	¥ 4,860	¥ 5,250	468	400	80	15.6	7.5	6	700
128-9918	GLS500	¥ 5,980	¥ 6,460	568	500	80	15.6	7.5	6	800


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

L Type Clamp (economical type)



- Features**
- Economical type most suitable for carpentry work and sheet metal processing.
 - The frame is made of heat treated medium carbon steel (S45C) finished with nickel chrome plating.
- Materials**
- Medium Carbon Steel (S45C)
- Origin**
- Taiwan

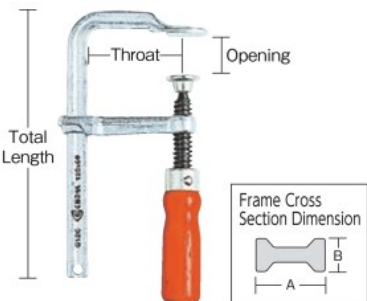

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
445-4481	G-10C	¥ 2,055	¥ 2,220	151	100	50	11.5	5.7	10	0.18
856-6696	G-30C5	¥ 2,944	¥ 3,180	351	300	50	11.5	5.7	10	0.27
162-0967	G-12C	¥ 2,629	¥ 2,840	172	120	60	13.5	6.5	10	0.30
856-6697	G-30C6	¥ 3,425	¥ 3,700	361	300	60	13.5	6.5	10	0.41
162-0975	G-16C	¥ 3,333	¥ 3,600	225	160	80	16.0	7.5	10	0.50
856-6698	G-30C8	¥ 3,963	¥ 4,280	365	300	80	16.0	7.5	10	0.63
162-0983	G-20C	¥ 4,249	¥ 4,590	278	200	100	19.5	9.5	10	0.88
856-6695	G-30C10	¥ 5,166	¥ 5,580	380	300	100	19.5	9.5	10	1.00
162-0991	G-25C	¥ 5,147	¥ 5,560	337	250	120	22.0	10.5	10	1.23
856-6704	G-40C12	¥ 6,314	¥ 6,820	487	400	120	22.0	10.5	10	1.47
856-6710	G-60C12	¥ 7,434	¥ 8,030	687	600	120	22.0	10.5	10	1.79
162-1009	G-30C	¥ 6,490	¥ 7,010	396	300	140	25.0	12.0	10	1.85
856-6736	SG-40C	¥ 7,434	¥ 8,030	496	400	120	25.0	12.0	10	1.97
856-6739	SG-60C	¥ 8,730	¥ 9,430	696	600	120	25.0	12.0	10	2.39
856-6730	SG-100C	¥ 12,367	¥ 13,360	1100	1000	120	27.0	13.0	6	3.75
856-6733	SG-150C	¥ 17,330	¥ 18,720	1600	1500	120	27.0	13.0	4	4.98
445-4570	G-40C	¥ 8,211	¥ 8,870	505	400	175	27.0	13.0	10	2.57

Warning
• PP pad is not included in.



PP Pad Materials • Polypropylene

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Applicable frame dimension A (mm)	SPQ (set)	Weight (g/set)
445-4502	G12C-P	¥ 185	¥ 200	13.5	10	4.0
445-4537	G16C-P	¥ 185	¥ 200	16.0	10	6.0
445-4545	G20C-P	¥ 185	¥ 200	19.5	10	8.5
445-4553	G25C-P	¥ 185	¥ 200	22.0	10	10.0
445-4561	G30C-P	¥ 185	¥ 200	25.0	10	13.0
445-4588	G40C-P	¥ 185	¥ 200	27.0	10	15.0

Cap Features • Can be easily mounted without tools.
Materials • Medium Carbon Steel (S45C)

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Applicable frame dimension A (mm)	Qty Per Set (piece)	SPQ (set)	Weight (g/set)
856-6742	19CPAD	¥ 463	¥ 500	19.5, 22.0	2	10	27
856-6743	25CPAD	¥ 509	¥ 550	25.0, 27.0	2	10	47
856-6744	30CPAD	¥ 602	¥ 650	30.0	2	10	65

Contact us: 0120-509-849 <http://www.orange-book.com/>