

Prices displayed include 8% tax.




Stock 38,650 Items


L Type Clamp



- Features**
- One-touch clamp light and cheap for carpentry works.
 - Optimum for carpentry works, furniture manufacturing and DIY teaching materials.
 - Light and excellent in tightening force.
- Materials**
- Cold Rolled Steel Material
- Accessories**
- PP Pad
- Origin**
- Taiwan

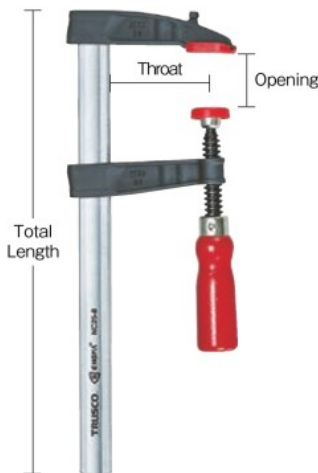

NA series

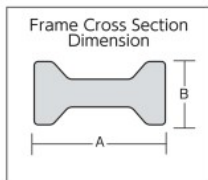

NA-P (pad)

Throat 50mm

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
445-4804	NA10-5	¥1,454	¥1,570	105	100	50	15.0	5.0	20	0.29
445-4812	NA15-5	¥1,583	¥1,710	155	150	50	15.0	5.0	20	0.32
445-4821	NA20-5	¥1,648	¥1,780	205	200	50	15.0	5.0	20	0.35
445-4839	NA25-5	¥1,685	¥1,820	255	250	50	15.0	5.0	20	0.38
445-4847	NA30-5	¥1,778	¥1,920	305	300	50	15.0	5.0	20	0.41

Throat 80mm

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
856-6713	NC16-8	¥2,314	¥2,500	245	160	80	25.0	6.0	10	0.74
856-6714	NC20-8	¥2,407	¥2,600	285	200	80	25.0	6.0	10	0.78
856-6715	NC25-8	¥2,499	¥2,700	335	250	80	25.0	6.0	10	0.84
856-6716	NC30-8	¥2,592	¥2,800	385	300	80	25.0	6.0	10	0.89
856-6717	NC40-8	¥2,823	¥3,050	485	400	80	25.0	6.0	10	1.00
856-6718	NC50-8	¥3,055	¥3,300	585	500	80	25.0	6.0	10	1.10
856-6719	NC60-8	¥3,286	¥3,550	685	600	80	25.0	6.0	10	1.12

Throat 120 mm

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
856-6722	NE20-12	¥3,703	¥4,000	302	200	120	29.0	9.0	10	1.39
856-6723	NE25-12	¥3,888	¥4,200	352	250	120	29.0	9.0	10	1.48
856-6724	NE30-12	¥4,073	¥4,400	402	300	120	29.0	9.0	10	1.57
856-6725	NE40-12	¥4,443	¥4,800	502	400	120	29.0	9.0	10	1.75
856-6726	NE50-12	¥4,721	¥5,100	602	500	120	29.0	9.0	6	1.92
856-6727	NE60-12	¥5,091	¥5,500	702	600	120	29.0	9.0	6	2.10
856-6728	NE80-12	¥5,739	¥6,200	902	800	120	29.0	9.0	6	2.46
856-6721	NE100-12	¥6,387	¥6,900	1102	1000	120	29.0	9.0	6	2.81

Pad Materials • Polypropylene

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Compatible Body	Q'ty Per Set (piece)	SPQ (set)	Weight (g/set)
445-4855	NA-P	¥185	¥200	NA series	2	10	3.5
856-6720	NCP	¥185	¥200	NC series	2	10	3.5
856-6729	NEP	¥185	¥200	NE series	2	10	3.5

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO

Orange Jr. Book

A pro-tool compact catalog that lists a wide variety of products all in one, including nearly every category on Orange-Book!

Published once every 2 years

Number of Products Listed: approx. **56,000** items

Number of Off-the-shelf Products: approx. **53,200**, off-the-shelf ratio **95%**

Number of Listed Manufacturers: approx. **1,419** companies

Number of Catalog Pages: approx. **2,700** pages

Order Code	Item No.	Price (tax not included)
858-5867	OBJM2018E	¥5,500

