

Vices (for drilling machine)

For Vise Cap Options, see p. 4-1812 to 1818

The number next to the logo mark indicates items in stock for each brand.

Clamps • Vices

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps

Bar Clamps

Special Clamps

Vices

Parts for Vices




Stock 38,650 Items

Drill Press Vise (powerful type)



Convenient V-shaped slotted base for clamping round bar

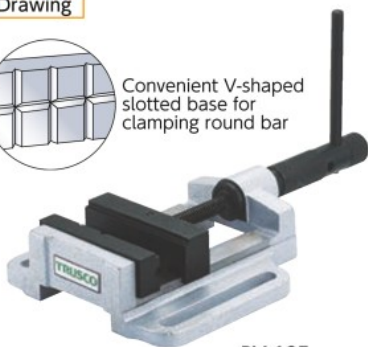


PV-125



- Features**
- Has excellent holding power with V groove mouthpiece (hardness HRC50 to 55) convenient for tightening round objects, irregular shapes, etc. as a standard equipment.
- Materials**
- Main Body: Cast Iron
- Origin**
- Taiwan



Machine finished (arrow part)

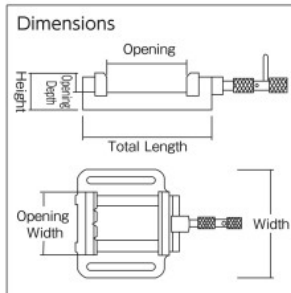


TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length x W x H (mm)	Opening Width (mm)	Opening (mm)	Opening Depth (mm)	Mounting Dimension (mm)	Clamping Force (kN)	SPQ (piece)	Weight (kg)
125-7455	PV-75	¥13,904	¥15,020	165 x 167 x 52	84	75	25	128	12	4	3.7
125-7463	PV-100	¥18,366	¥19,840	200 x 200 x 60	104	100	32	153	13	3	5.6
125-7471	PV-125	¥25,078	¥27,090	230 x 225 x 69	132	120	38	181	14	1	8.5

 Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items


Drilling Machine Vise with Rotating Base



TBVR-65



- Features**
- Can move the vise by just operating the lever.
 - Quickly detach the processed workpiece from the blade.
 - With a rotating base, can rotate 360° in parallel.
- Materials**
- Cast Iron
- Origin**
- Taiwan

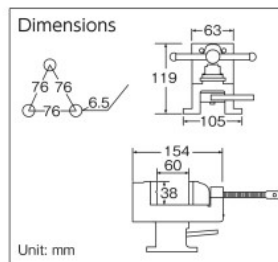

Unit: mm

Warning

- Do not use for uses other than drilling with a drill press. By the overload applied to the body fixing base part, possibly causing damage.

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length x W x H (mm)	Opening Width (mm)	Opening (mm)	Opening Depth (mm)	Mounting Hole Diameter (mm)	Clamping Force (kN)	SPQ (piece)	Weight (kg)
762-3216	TBVR-65	¥15,441	¥16,680	154 x 105 x 119	63	60	38	6.5	11	1	2.8

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Type A Vise for Medium-Size Drill Press




TBV-125



- Features**
- Ductile cast iron is hard to break even for strong work.
- Materials**
- Main Body: Ductile Cast Iron (FCD450)
- Origin**
- Taiwan

Warning

- Sole plane processing is not precisely finished.
- Do not use for uses other than drilling using a drill press. Overload may be applied to the body fixing base part, possibly causing damage.

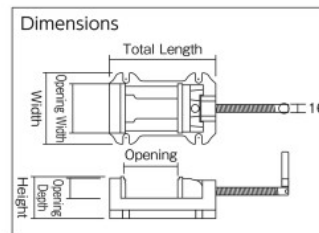

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length x W x H (mm)	Opening Width (mm)	Opening (mm)	Opening Depth (mm)	Mounting Dimension (mm)	Mounting Hole Diameter (mm)	Clamping Force (kN)	SPQ (piece)	Weight (kg)
490-0642	TBV-75	¥ 7,776	¥ 8,400	180 x 128 x 64	78	73	32	108 x 122	12	11	1	2.8
490-0651	TBV-100	¥ 9,350	¥10,100	200 x 150 x 66	103	98	32	132 x 147	12	13	1	4.0
490-0669	TBV-125	¥11,942	¥12,900	255 x 195 x 76	130	118	38	173 x 187	15	15	1	7.0
490-0677	TBV-150	¥16,385	¥17,700	280 x 225 x 76	154	143	38	202 x 203	15	18	1	9.0

Contact us:0120-509-849 <http://www.orange-book.com/>