


Prices displayed include 8% tax.

Internal Thread

Stock 38,650 Items



Origin • Taiwan

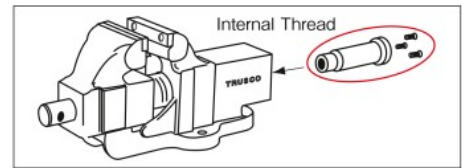

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Model	SPQ (piece)	Weight (g)
301-1062	RV100NM	¥ 9,850	¥10,640	RV-100N	1	1280
301-1071	RV130NM	¥15,450	¥16,690	RV-130N	1	2180
301-1089	RV150NM	¥18,329	¥19,800	RV-150N	1	2230
301-1038	LV100NM	¥ 2,841	¥ 3,070	LV-100N	1	330
301-1046	LV125NM	¥ 2,971	¥ 3,210	LV-125N	1	480
301-1054	LV150NM	¥ 3,046	¥ 3,290	LV-150N	1	530
819-1319	LV-200NM	¥ 3,703	¥ 4,000	LV-200N	1	300
819-1306	SLV-100M	¥ 2,870	¥ 3,100	SLV-100N	1	460
819-1307	SLV-125M	¥ 3,055	¥ 3,300	SLV-125N	1	500
819-1308	SLV-150M	¥ 3,333	¥ 3,600	SLV-150N	1	600
819-1309	SLV-200M	¥ 3,610	¥ 3,900	SLV-200N	1	720
445-6319	TSLV-100M	¥ 2,582	¥ 2,790	TSLV-100	1	260
445-6360	TSLV-125M	¥ 2,703	¥ 2,920	TSLV-125	1	320
445-6416	TSLV-150M	¥ 2,768	¥ 2,990	TSLV-150	1	500
445-6467	TSLV-175M	¥ 2,906	¥ 3,140	TSLV-175	1	500


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Model	SPQ (piece)	Weight (g)
445-5576	TDWV-165M	¥ 2,314	¥ 2,500	TDWV-165	1	620
445-5622	TDWV-200M	¥ 2,407	¥ 2,600	TDWV-200	1	760
336-2361	VRS080N003	¥ 2,240	¥ 2,420	VRS-080N	1	260
336-2370	VRS100N003	¥ 2,343	¥ 2,530	VRS-100N	1	260
336-2388	VRS125N003	¥ 2,444	¥ 2,640	VRS-125N	1	360
336-2396	VRS150N003	¥ 2,546	¥ 2,750	VRS-150N	1	520
336-2400	VRS200N003	¥ 2,647	¥ 2,860	VRS-200N	1	520
445-6904	VRS-250N003	¥ 2,527	¥ 2,730	VRS-250N	1	520
490-0502	VRS-300N003	¥ 2,527	¥ 2,730	VRS-300N	1	540
445-6211	TRV-100M	¥ 1,389	¥ 1,500	TRV-100	1	200
762-3208	TVRQ-150M	¥12,034	¥13,000	TVRQ-150, TVRQ-200	1	300
490-0588	TSUB-100M	¥ 7,406	¥ 8,000	TSUB-100	1	540
490-0596	TSUB-150M	¥ 9,257	¥10,000	TSUB-150	1	800

Contact us:0120-509-849 <http://www.orange-book.com/>

Cap Fixing Screw

Stock 38,650 Items

Origin • Taiwan

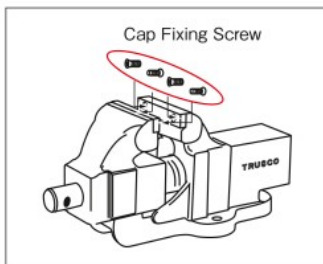

Order Unit: 1 Set

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Compatible Model	Q'ty Per Set (piece)	SPQ (set)	Weight (g/set)
301-0988	NEJIS	¥407	¥440	LV-100N, RV-100N	4	1	10.0
301-0996	NEJIM	¥407	¥440	LV-125N, LV-150N, RV-130N, RV-150N	4	1	20.0
819-1320	NEJIL	¥407	¥440	LV-200N	4	10	20.0
761-1510	TSRV200KNS	¥407	¥440	TSRV-200K	6	1	47.5
416-2625	SRV100N002	¥407	¥440	SRV-100-TSRV-100	4	1	10.0
416-2633	SRV125N002	¥447	¥483	SRV-125-TSRV-125	4	1	20.0
336-2299	SRV150N002	¥407	¥440	SRV-150-TSRV-150	4	1	44.0
336-2302	SRV200N002	¥447	¥483	SRV-200	4	1	80.0
445-6327	TSLV-100NS	¥370	¥400	TSLV-100	4	1	20.0
445-6378	TSLV-125NS	¥370	¥400	TSLV-125	4	1	20.0
445-6424	TSLV-150NS	¥370	¥400	TSLV-150	4	1	20.0
445-6475	TSLV-175NS	¥370	¥400	TSLV-175	4	1	20.0
445-5584	TDWV-165NS	¥407	¥440	TDWV-165	6	1	60.0
445-5631	TDWV-200NS	¥407	¥440	TDWV-200	6	1	60.0
762-3186	TVRQ-150NS	¥407	¥440	TVRQ-150	4	1	300.0
762-3194	TVRQ-200NS	¥407	¥440	TVRQ-200	4	1	300.0
761-1561	TMB-125NS	¥407	¥440	TMB-125	4	1	26.0
761-1579	TMB-150NS	¥407	¥440	TMB-150	4	1	25.5
336-2311	VRS080N002	¥407	¥440	VRS-080N	4	1	12.0
336-2329	VRS100N002	¥407	¥440	VRS-100N	4	1	13.0
336-2337	VRS125N002	¥407	¥440	VRS-125N	4	1	15.0
336-2345	VRS150N002	¥407	¥440	VRS-150N	4	1	15.0
336-2353	VRS200N002	¥407	¥440	VRS-200N	4	1	15.0
445-6891	VRS-250N002	¥370	¥400	VRS-250N	4	1	20.0
490-0481	VRS-300N002	¥370	¥400	VRS-300N	4	1	20.0
761-1668	CR-75NNS	¥407	¥440	CR-75N	4	1	24.0
761-1676	CR-100NNS	¥407	¥440	CR-100N	4	1	27.5
761-1684	CR-125NNS	¥407	¥440	CR-125N	4	1	27.0
761-1692	CR-150NNS	¥407	¥440	CR-150N	4	1	58.5
761-1749	FV-75NS	¥278	¥300	FV-75	4	1	19.5
761-1757	FV-100NS	¥278	¥300	FV-100	4	1	19.5
761-1765	FV-125NS	¥278	¥300	FV-125	4	1	22.5
761-1773	FV-150NS	¥278	¥300	FV-150	4	1	22.5
762-3232	TBVR-65NS	¥370	¥400	TBVR-65	4	1	300.0
490-0723	TBV-75NS	¥407	¥440	TBV-75	4	1	40.0
490-0731	TBV-100NS	¥407	¥440	TBV-100	4	1	40.0
490-0740	TBV-125NS	¥407	¥440	TBV-125	4	1	40.0
490-0758	TBV-150NS	¥407	¥440	TBV-150	4	1	40.0
761-1781	FQ-75NS	¥278	¥300	FQ-75	4	1	23.5
761-1790	FQ-100NS	¥278	¥300	FQ-100	4	1	23.5
761-1803	FQ-150NS	¥278	¥300	FQ-150	4	1	24.5
761-1811	FQ-200NS	¥278	¥300	FQ-200	4	1	33.0
761-1820	QU-75NS	¥278	¥300	QU-75	4	1	27.0
761-1838	QU-100NS	¥278	¥300	QU-100	4	1	51.0
490-0871	TMBT-80NS	¥204	¥220	TMBT-80	2	1	40.0
445-6220	TRV-100NS	¥370	¥400	TRV-100	4	1	20.0
762-3283	TLV-100NS	¥370	¥400	TLV-100	4	1	300.0
761-1978	BV-50SNNNS	¥407	¥440	BV-50SN	4	1	3.5
761-1986	BV-65SNNNS	¥407	¥440	BV-65SN	4	1	3.5
761-1528	TSUB100NS	¥407	¥440	TSUB-100	4	1	26.5
761-1536	TSUB150NS	¥407	¥440	TSUB-150	4	1	27.0
761-1544	TSUBR100NS	¥407	¥440	TSUBR-100	4	1	7.5
761-1552	TSUBR150NS	¥407	¥440	TSUBR-150	4	1	11.0

Contact us:0120-509-849 <http://www.orange-book.com/>

Clamps · Vices

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps

Bar Clamps

Special Clamps

Vices

Parts for Vices