

Prices displayed include 8% tax.


MITUTOYO
Mitutoyo Stock 466 Items

Digimatic Depth Gauge

Repairing OK Calibration OK
Approx. 2 Weeks



- Features**
- With carbide sphere probe(No.21JAA224).
 - With 5 adding rods(10, 20, 30, 30, 100mm).
 - CE standard product.
- Use**
- For depth measurement.
- Specs**
- Power supply: Button type silver oxide battery (SR44) x 1 (accessory)
 - Rod diameter: 5mm
 - With measurement data output terminal
- Origin**
- Japan

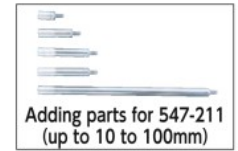

Order Unit: 1 Piece

MITUTOYO CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Length (mm)	Base Dimension (mm)	SPQ (piece)	Weight (g)
108-8122	547-211	¥35,538	¥35,100	547-211	0 to 200	±0.02	0.01	105	63.5	1	295

547-211

Contact us:050-3786-3214 <http://www.mitutoyo.co.jp/>

TECLOCK
TECLOCK CORPORATION Stock 81 Items

Digital Depth Gauge

Repairing OK Calibration OK
Approx. 2 Weeks



- Features**
- Widely-used model that is easy to use with narrowed-down functions.
 - Print output is possible.
- Use**
- For measuring the depth and level difference of the object to be measured.
- Specs**
- Power supply: Button type silver oxide battery (SR44) x 1 (accessory)
 - Rod diameter: Head Φ 0.3mm (needle shape)
- Origin**
- Japan

Order Unit: 1 Piece

TECLOCK Corporation

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Length (mm)	Base Dimension (mm)	SPQ (piece)	Weight (g)
451-4882	DMD-210S2	¥30,024	¥27,800	-	0 to 12	±0.02	0.01	115	75	1	270


DMD-210S2

Contact us:0266-22-5920 <http://www.teclock.co.jp/>

TECLOCK
TECLOCK CORPORATION Stock 81 Items

Depth Gauge

Repairing OK Calibration OK
Approx. 2 Weeks

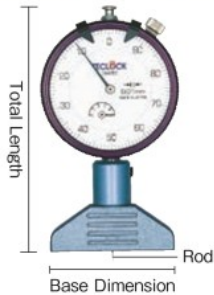

- Features**
- An easy to read dial type depth gauge.
- Use**
- For measuring the depth and level difference of the object to be measured.
- Origin**
- Japan

Item No.	Rod Diameter (mm)
DM-250	Tip Φ 0.3 (Needle shape)
DM-210	Tip Φ 0.3 (Needle shape)
DM-223	3.2 (steel ball)

Order Unit: 1 Piece

TECLOCK Corporation

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Length (mm)	Base Dimension (mm)	SPQ (piece)	Weight (g)
102-8651	DM-250	¥15,498	¥15,310	-	0 to 5	±0.010	0.01	98	50	1	230
102-8669	DM-210	¥15,782	¥15,590	-	0 to 10	±0.012	0.01	98	75	1	270
102-8677	DM-223	¥17,213	¥17,000	-	0 to 20	±0.015	0.01	100	75	1	275


DM-250

Contact us:0266-22-5920 <http://www.teclock.co.jp/>

TECLOCK
TECLOCK CORPORATION Stock 81 Items

Depth Gauge

Repairing OK Calibration OK
Approx. 2 Weeks

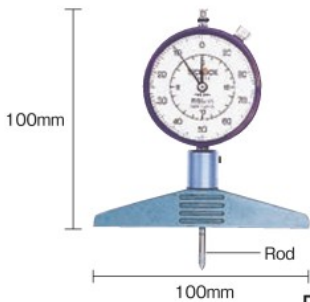

- Features**
- Using accessory adding parts, can be used up to 230mm of measuring depth.
- Use**
- For measuring the depth and level difference of the object to be measured.
- Specs**
- Rod diameter: 3.2mm (steel ball)
- Origin**
- Japan



Order Unit: 1 Piece

TECLOCK Corporation

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Length (mm)	Base Dimension (mm)	SPQ (piece)	Weight (g)
102-8685	DM-224	¥26,325	¥26,000	-	0 to 230	±0.015	0.01	100	100	1	340


DM-224

Contact us:0266-22-5920 <http://www.teclock.co.jp/>

SK
SK Stock 1,103 Items

Dial Depth Gauge

Repairing OK Calibration OK
Approx. 2 Weeks

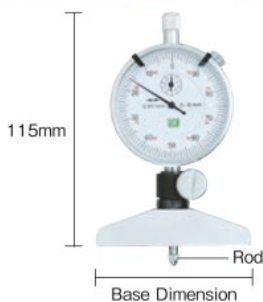

- Features**
- With combination of adding rods(10, 20, 40, 60, 80mm), measurement is possible up to 210mm at maximum.
 - Dial type that measured values are easy to read.
 - Wide measurement range
- Use**
- For depth measurement.
- Specs**
- Rod diameter: 4.5mm (steel ball tip)
- Origin**
- China

Order Unit: 1 Piece

(Price revision date: Jun, 2015) NIIGATASEIKI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Instrument Error (mm)	Minimum Display (mm)	Total Length (mm)	Base Dimension (mm)	SPQ (piece)	Weight (g)
377-5241	DD-1050	¥15,660	¥14,500	151711	0 to 210	±0.02	0.01	115	50	1	280
377-5232	DD-10100	¥15,660	¥14,500	151712	0 to 210	±0.02	0.01	115	100	1	350

DD-1050

Contact us:0256-31-5660 <http://www.sokuteikougou.com/>