





Stock 81 Items

## 0.1mm Scale Dial Gauge

Repairing OK

Calibration OK  
Approx. 2 Weeks

- Features** •Dial gauge that can read per 0.1mm.  
**Use** •Use for sizing machines, incorporating to dedicated machines, or in a small space.  
**Specs** •Dial diameter: 55mm  
**Origin** •Japan

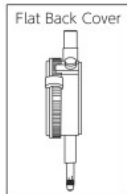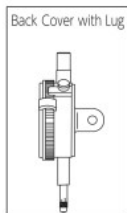

TM-91F  
(flat back cover type)

### Back Cover with Lug Type

Order Unit: 1 Piece

TECLOCK CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Minimum Display (mm)	Graduation Specification	Mount Shaft Diameter (mm)	Measuring Force (N)	SPQ (piece)	Weight (g)
336-6235	TM-91	¥6,021	¥5,950	-	0 to 10	0.1	±0-5-10	8	1.4 or less	1	140

### Flat Back Cover Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Minimum Display (mm)	Graduation Specification	Mount Shaft Diameter (mm)	Measuring Force (N)	SPQ (piece)	Weight (g)
296-0524	TM-91F	¥6,021	¥5,950	-	0 to 10	0.1	±0-5-10	8	1.4 or less	1	135

Contact us:0266-22-5920 <http://www.teclock.co.jp/>



Stock 466 Items

## Back Plunger Type Dial Gauge

Repairing OK

Calibration OK  
Approx. 2 Weeks

- Features** •Dial gauge with a scale surface at right angles with a spindle.  
**Use** •For leveling tables of machine tools or installing to jig of inspection machines.  
**Origin** •Japan



1160T

1960T



2990T-10

Item No.	Dial diameter (mm)
1160T	35
1960T	35
2990T-10	58

Order Unit: 1 Piece

MITUTOYO CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Minimum Display (mm)	Graduation Specification	Mount Shaft Diameter (mm)	Measuring Force (N)	SPQ (piece)	Weight (g)
452-3873	1160T	¥10,328	¥10,200	1160T	0 to 5.0	0.010	0-100	8	1.4 or less	1	85
452-3881	1960T	¥10,328	¥10,200	1960T	0 to 1.0	0.010	50-0-50	8	1.4 or less	1	85
452-3903	2990T-10	¥24,198	¥23,900	2990T-10	0 to 0.1	0.001	50-0-50	8	1.5 or less	1	220

Contact us:050-3786-3214 <http://www.mitutoyo.co.jp/>




Stock 81 Items

## Back Plunger Type Dial Gauge

Repairing OK

Calibration OK  
Approx. 2 Weeks

- Features** •A type in which the dials are parallel to the scale plate and viewed from the measuring surface.  
 •Convenient for root measurement and gear runout.  
**Use** •Unlike general dial gauge, for use in narrow places.  
**Specs** •Dial diameter: 38mm  
**Origin** •Japan

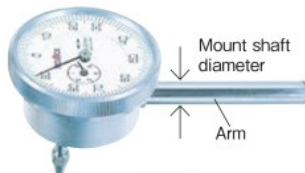

ST-305A  
(with arm)



ST-305B

Order Unit: 1 Piece

TECLOCK CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Manufacturer Code	Measurement Range (mm)	Minimum Display (mm)	Graduation Specification	Mount Shaft Diameter (mm)	Measuring Force (N)	SPQ (piece)	Weight (g)
336-6219	ST-305A	¥10,395	¥10,270	-	0 to 5	0.01	0-50-100	6.35	1.4 or less	1	75
336-6227	ST-305B	¥10,395	¥10,270	-	0 to 5	0.01	0-50-100	8.00	1.4 or less	1	70

Contact us:0266-22-5920 <http://www.teclock.co.jp/>