

Prices displayed include 8% tax.

For Batteries, see p. 10-461 to 474

TRUSCO **Stock 38,650 Items**

## Stand Loupe (universal type) RoHS




TL-SLU

- Features**
- A universal type in which the angle of the lens can be changed flexibly.
  - Since it is equipped with a base, it is very convenient to use both hands with fine work etc.
- Use**
- Assembly and inspection of parts and so on.
- Specs**
- W x D: 54 x 59mm
  - Total height: 76mm
- Materials Origin**
- Lens: Glass
  - Japan

TRUSCO **Stock 38,650 Items**

## Stand loupe (clip type)

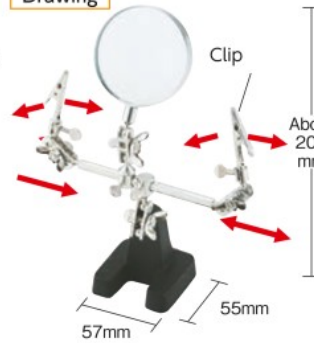

TL-CS65

- Features**
- The work can be held with the clip. It is convenient for being able to free both hands.
  - The lens is a flexible and universal type, which is optimal for detailed work and inspections.
- Use**
- Assembly and inspection of parts and so on.
- Specs**
- W x D: 57 x 55mm
  - Total height: 200mm
- Materials Origin**
- Lens: Glass
  - Taiwan

Order Unit: 1 Piece (Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	SPQ (piece)	Weight (g)
250-9253	TL-SLU	¥4,582	¥4,950	2.5	φ75	3	450

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece (Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	SPQ (piece)	Weight (g)
250-9113	TL-CS65	¥2,083	¥2,250	2.5	φ65	6	520

Contact us: 0120-509-849 <http://www.orange-book.com/>

HIKARI **Stock 1,144 Items**

## "SEBONEKUN Loupe" RoHS



SR5000B

- Features**
- The neck bends just like the back bone, enabling flexible adjustment of the direction of the frame.
- Use**
- Assembly and inspection of parts.
- Specs**
- W x D: 120 x 120mm
  - Arm length: 250mm
- Materials Origin**
- Lens: Acrylic
  - Japan

OTSUKA **Stock 32 Items**

## "Wide View Stand Loupe" RoHS



NO.1795

- Features**
- A set of 2 lenses - a square lens that has little aberration and a round lens that has high magnification.
  - The size of the loupe becomes A5 when folded.
- Use**
- In addition to processing and inspections, it can also be used for hobbies and reading.
- Specs**
- W x D: 205 x 160mm
  - Total height: 45mm (when folded)
- Materials Origin**
- Lens: Resin
  - Japan



Order Unit: 1 Piece HIKARI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	SPQ (piece)	Weight (g)
004-6248	SR5000B	¥4,443	¥4,800	1.8	193 x 140	5	356

Contact us: 06-6764-1531 <http://www.osaka-hikari.co.jp/>

Order Unit: 1 Piece OTSUKA OPTICS Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	SPQ (piece)	Weight (kg)
325-5069	NO.1795	¥17,280	¥16,000	2/4/7	144 x 108 (2x)	1	1.9

Contact us: 03-3491-4126 <http://www.otsuka-op.com/>

ILK **Stock 39 Items**

## Stand Loupe with LED Light



CMS-100

- Features**
- Power can be supplied from an outlet with the use of an adapter.
  - Power can also be supplied by batteries (AA x 4) or from a PC via USB connection.
  - With the non-step dimming dial type, brightness can be adjusted appropriately.
  - Equipped with a 100mm optical glass lens.
  - 24 pieces of LED make it bright and easy to inspect.
- Use**
- Assembly and inspection work, etc. that require the use of both hands.
- Specs**
- W x D: 160 x 160mm
  - Arm length: About 250mm
  - Power Supply: AA Dry Battery x 4 (sold separately)
  - Light source: LED x 24 pieces
- Materials Origin**
- Lens: Glass
  - China



Order Unit: 1 Piece Ikeda-lens CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Magnification (times)	Lens Dimension (mm)	SPQ (piece)	Weight (g)
855-2653	CMS-100	¥9,527	¥9,500	2	φ100	1	920

URL <http://www.ikeda-lens.co.jp/>