

The number next to the logo mark indicates items in stock for each brand.

TRUSCO  
Stock  
38,650  
Items

## "Safety Bar" (stainless steel, mirror finish)




ComEco  
Chemical Content  
Inspection  
Com  
Drawing



TSB-KType  
(mirror finish)

- Features
- A mirror finished surface.
  - Equipped with a cover for a clean appearance.
  - Can also be installed on a boat to be used as a hand rail.
  - Can also be attached to a tile or concrete wall. (The included PC plug or commercially available anchor will be necessary.)

- Materials • Stainless Steel (SUS304)  
Accessories • Stainless Steel, Phillips Head Tapping Screws: 6 screws  
• PC Plug: 6 pieces  
Origin • China

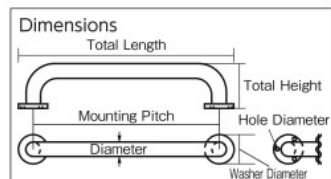

Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Total Height (mm)	Diameter (mm)	Washer Diameter (mm)	Hole Diameter (mm)	Mounting Pitch (mm)	Reference Working Load (kN)	SPQ (piece)	Weight (g)
284-7558	TSB-19-150K	¥2,185	¥2,360	196	56	19	46	5	150	0.78	12	180
284-7566	TSB-19-200K	¥2,472	¥2,670	246	56	19	46	5	200	0.78	12	210
284-7574	TSB-19-250K	¥2,888	¥3,120	296	56	19	46	5	250	0.78	12	240
284-7582	TSB-19-300K	¥3,185	¥3,440	346	56	19	46	5	300	0.78	12	270
284-7591	TSB-25-300K	¥6,091	¥6,580	352	75	25	52	5	300	0.78	12	367
284-7604	TSB-25-400K	¥6,610	¥7,140	452	75	25	52	5	400	0.78	12	446
284-7612	TSB-25-500K	¥7,063	¥7,630	552	75	25	52	5	500	0.78	12	526
284-7621	TSB-25-600K	¥8,110	¥8,760	652	75	25	52	5	600	0.78	12	609
284-7639	TSB-32-300K	¥6,832	¥7,380	365	75	32	65	5	300	0.78	12	485
284-7647	TSB-32-400K	¥7,313	¥7,900	465	75	32	65	5	400	0.78	12	590
284-7655	TSB-32-500K	¥7,776	¥8,400	565	75	32	65	5	500	0.78	12	695
284-7663	TSB-32-600K	¥8,730	¥9,430	665	75	32	65	5	600	0.78	12	832

Contact us:0120-509-849 <http://www.orange-book.com/>



Mirror Finish

TRUSCO  
Stock  
38,650  
Items

## "Safety Bar" (stainless steel, hairline finish)




ComEco  
Chemical Content  
Inspection  
Com  
Drawing



TSB-HLType  
(hairline finish)

- Features
- A hairline finish.
  - Equipped with a cover for a clean appearance.
  - Can also be installed on a boat to be used as a hand rail.
  - Can also be attached to a tile or concrete wall. (The included PC plug or commercially available anchor will be necessary.)

- Materials • Stainless Steel (SUS304)  
Accessories • Stainless Steel, Phillips Head Tapping Screws: 6 screws  
• PC Plug: 6 pieces  
Origin • China

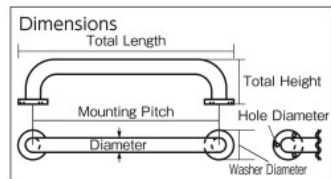

Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Total Height (mm)	Diameter (mm)	Washer Diameter (mm)	Hole Diameter (mm)	Mounting Pitch (mm)	Reference Working Load (kN)	SPQ (piece)	Weight (g)
284-7671	TSB-19-150HL	¥2,185	¥2,360	196	56	19	46	5	150	0.78	12	180
284-7680	TSB-19-200HL	¥2,472	¥2,670	246	56	19	46	5	200	0.78	12	210
284-7698	TSB-19-250HL	¥2,888	¥3,120	296	56	19	46	5	250	0.78	12	240
284-7701	TSB-19-300HL	¥3,185	¥3,440	346	56	19	46	5	300	0.78	12	270
284-7710	TSB-25-300HL	¥6,091	¥6,580	352	75	25	52	5	300	0.78	12	367
284-7728	TSB-25-400HL	¥6,610	¥7,140	452	75	25	52	5	400	0.78	12	446
284-7736	TSB-25-500HL	¥7,063	¥7,630	552	75	25	52	5	500	0.78	12	526
284-7744	TSB-25-600HL	¥8,110	¥8,760	652	75	25	52	5	600	0.78	12	609
284-7752	TSB-32-300HL	¥6,832	¥7,380	365	75	32	65	5	300	0.78	12	485
284-7761	TSB-32-400HL	¥7,313	¥7,900	465	75	32	65	5	400	0.78	12	590
284-7779	TSB-32-500HL	¥7,776	¥8,400	565	75	32	65	5	500	0.78	12	695
284-7787	TSB-32-600HL	¥8,730	¥9,430	665	75	32	65	5	600	0.78	12	832

Contact us:0120-509-849 <http://www.orange-book.com/>



Hairline Finish

SUGATSUNE  
Stock  
766  
Items

## Handle (stainless steel)




Com  
CAD



XL-JSRType

- Features
- Stainless steel SUS316 is used.
  - A beautiful finishes using a combination of a mirror finish and a satin finish.
- Materials • Stainless Steel (SUS316)  
Accessories • Cross Recess Truss Small Screw M4 x 25 (stainless steel)  
Origin • Japan

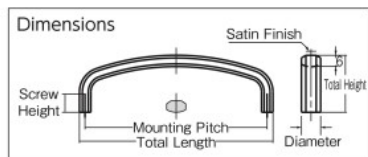

Order Unit: 1 Piece

(Price revision date: Feb, 2015) SUGATSUNE KOGYO Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Total Height (mm)	Screw Dimension	Diameter (mm)	Screw Height (mm)	Mounting Pitch (mm)	SPQ (piece)	Weight (g)
344-9157	XL-JSR40TT	¥2,646	¥2,450	38	27	M4	10	10	32	1	26
344-9165	XL-JSR70TT	¥2,808	¥2,600	70	30	M4	10	10	64	1	35
344-9131	XL-JSR100TT	¥3,132	¥2,900	102	30	M4	10	10	96	1	51
344-9149	XL-JSR135TT	¥3,456	¥3,200	134	30	M4	10	10	128	1	63

Contact us:03-3851-1122 <http://www.sugatsune.co.jp/>