

Prices displayed include 8% tax.



Stock 38,650 Items

Panel Fix Bar




Bolt

- Features • Can be used for various purposes by combining parts.
 Use • For photo stand, pamphlet stand, card stand, etc.
 Origin • Japan



Nominal Diameter	Thickness of Mounting Object
M4	6mm or less
M5	8mm or less

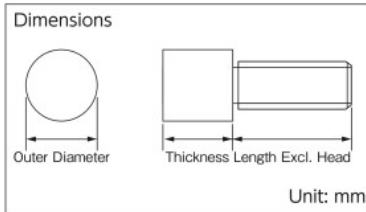


Bolt Materials • Brass
 • Surface Treatment: Chrome-Plated Finishing

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Outer Diameter x Thickness (mm)	Length Excl. Head (mm)	Nominal Diameter	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
855-5772	PF-AB050	¥463	¥500	6 x 2	10	M4	4	10	6
855-5773	PF-AB051	¥463	¥500	6 x 6	10	M4	4	10	10
855-5787	PF-AB080	¥972	¥1,050	8 x 3	12	M5	4	10	11
855-5788	PF-AB081	¥972	¥1,050	8 x 7	12	M5	4	10	18



Single-Sided Nut

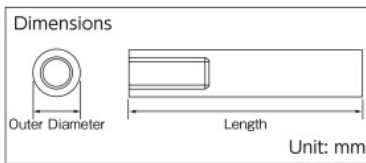

Single-Sided Nut Materials • Brass
 • Surface Treatment: Chrome-Plated Finishing

Mounting Method


1: Put the photo between panel and the panel.
 2: Pass bolts through holes in panel, fix with single-sided nut of your choice.

Used parts: Bolt, Single-Sided Nut

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Outer Diameter x L (mm)	Screw Length (mm)	Nominal Diameter	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
855-5774	PF-AB052	¥500	¥540	6 x 10	7.0	M4	4	10	7
855-5775	PF-AB053	¥630	¥680	6 x 20	10.0	M4	4	10	15
855-5776	PF-AB054	¥713	¥770	6 x 30	10.0	M4	4	10	24
855-5777	PF-AB055	¥814	¥880	6 x 40	10.0	M4	4	10	35
855-5778	PF-AB056	¥897	¥970	6 x 50	10.0	M4	4	10	44
855-5779	PF-AB070	¥1,306	¥1,410	6 x 75	10.0	M4	4	10	67
855-5780	PF-AB071	¥1,500	¥1,620	6 x 100	10.0	M4	4	10	93
855-5789	PF-AB082	¥972	¥1,050	8 x 12	10.0	M5	4	10	14
855-5790	PF-AB083	¥1,055	¥1,140	8 x 20	12.5	M5	4	10	25
855-5791	PF-AB084	¥1,092	¥1,180	8 x 30	12.5	M5	4	10	42
855-5792	PF-AB085	¥1,130	¥1,220	8 x 40	12.5	M5	4	10	58
855-5793	PF-AB086	¥1,221	¥1,320	8 x 50	12.5	M5	4	10	75



Double-Sided Nut

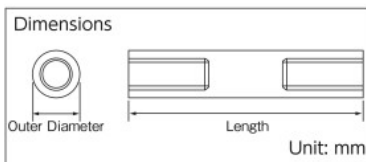

Double-Sided Nut Materials • Brass
 • Surface Treatment: Chrome-Plated Finishing

Mounting Method


1: Insert double-sided nut between panel and the panel, and secure with bolts.

Used parts: Bolt, Double-Sided Nut

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Outer Diameter x L (mm)	Screw Length (mm)	Nominal Diameter	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
855-5781	PF-AB057	¥648	¥700	6 x 20	Penetrated	M4	4	10	13
855-5782	PF-AB058	¥814	¥880	6 x 30	10.0	M4	4	10	19
855-5783	PF-AB059	¥897	¥970	6 x 40	10.0	M4	4	10	29
855-5784	PF-AB060	¥1,018	¥1,100	6 x 50	10.0	M4	4	10	39
855-5794	PF-AB087	¥1,259	¥1,360	8 x 20	Penetrated	M5	4	10	22
855-5795	PF-AB088	¥1,306	¥1,410	8 x 30	12.5	M5	4	10	33
855-5796	PF-AB089	¥1,306	¥1,410	8 x 40	12.5	M5	4	10	50
855-5797	PF-AB090	¥1,500	¥1,620	8 x 50	12.5	M5	4	10	54



Connecting Screw

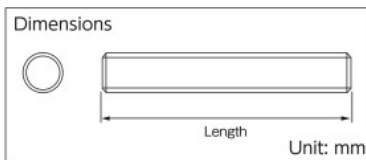

Connecting Screw Materials • Surface Treatment: Nickel Plate Finishing

Mounting Method

1: Put the panel between the double-sided nut, use connection screws for connection.

Used parts: Bolt, Single-Sided Nut, Connecting Screw (M4 x 25)

Please use connection screw M4 x 25 when using acrylic board and using φ 6 bar.

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Length (mm)	Nominal Diameter	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
855-5785	PF-AB064	¥158	¥170	15	M4	4	10	5
855-5786	PF-AB065	¥204	¥220	25	M4	4	10	7
855-5798	PF-AB095	¥241	¥260	25	M5	4	10	12

Contact us: 0120-509-849 <http://www.orange-book.com/>