

Plate Type Urethane Casters (for light/medium load)

The number next to the logo mark indicates items in stock for each brand.

TRUSCO




Stock 38,650 Items

Plate Type Caster "TYS Series" (nylon wheel urethane tire)

Casters

- Features**
- A standard type caster for light/medium load with driveability and load capacity.
 - A standard dimension caster used a lot for transportation dollies, roll box pallets and other general work uses.
- Specs**
- Plate Type
- Materials**
- Metal Fitting: Steel
 - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 - Wheel: Nylon Wheel, Urethane
- Origin**
- Japan

Bearing structure of pivot portion

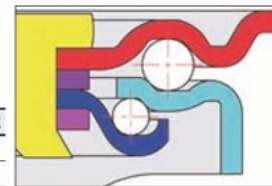

Wheel Diameter (mm)	wheel color	Bearing
50-65-75	White wheel brown urethane	None
100/125/150	Black wheel gray urethane	Yes

Flexible Specs • Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
474-8344	TYSU-50	¥ 741	¥ 800	60 61.2	50	25	70	70 x 58	55 x 42	8.8	20	550
474-8352	TYSU-65	¥ 713	¥ 770	60 61.2	65	25	85	70 x 58	55 x 42	8.8	20	600
474-8361	TYSU-75	¥ 750	¥ 810	70 71.4	75	26	93	70 x 58	55 x 42	8.8	20	650
474-8379	TYSU-100	¥ 1,685	¥ 1,820	100 102.0	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	16	700
474-8387	TYSU-125	¥ 2,120	¥ 2,290	130 132.6	125	40	168	102 x 102	75 to 80 x 75 to 80	11.0	8	750
474-8395	TYSU-150	¥ 2,667	¥ 2,880	140 142.8	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	800

TRUSCO NAKAYAMA CORPORATION



TYSU-150

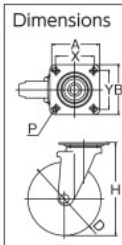


Flexible with stopper Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
474-8409	TYSUB-50	¥ 861	¥ 930	60 61.2	50	25	70	70 x 58	55 x 42	8.8	20	550
474-8417	TYSUB-65	¥ 814	¥ 880	60 61.2	65	25	85	70 x 58	55 x 42	8.8	20	600
474-8425	TYSUB-75	¥ 852	¥ 920	70 71.4	75	26	93	70 x 58	55 x 42	8.8	20	650
474-8433	TYSUB-100	¥ 2,129	¥ 2,300	100 102.0	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	16	700
474-8441	TYSUB-125	¥ 2,638	¥ 2,850	130 132.6	125	40	168	102 x 102	75 to 80 x 75 to 80	11.0	8	750
474-8450	TYSUB-150	¥ 3,194	¥ 3,450	140 142.8	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	800



TYSUB-150

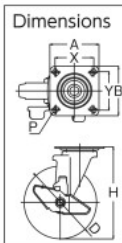


Fixed Specs • Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
474-8468	TYSUK-50	¥ 638	¥ 690	60 61.2	50	25	70	70 x 47	55 x 28	8.8	20	850
474-8476	TYSUK-65	¥ 593	¥ 640	60 61.2	65	25	85	70 x 47	55 x 28	8.8	20	900
474-8484	TYSUK-75	¥ 630	¥ 680	70 71.4	75	26	93	70 x 47	55 x 28	8.8	20	950
474-8492	TYSUK-100	¥ 1,389	¥ 1,500	100 102.0	100	32	132	110 x 78	80 to 90 x 45 to 50	11.0	16	700
474-8506	TYSUK-125	¥ 1,805	¥ 1,950	130 132.6	125	40	168	140 x 94	100 to 112 x 53 to 56	11.0	8	750
474-8514	TYSUK-150	¥ 2,426	¥ 2,620	140 142.8	150	40	190	140 x 94	100 to 112 x 53 to 56	11.0	8	800



TYSUK-150

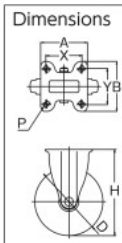


Replacement wheel Specs • A double ball bearing included

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Hub Width B (mm)	Hole Diameter d (mm)	SPQ (piece)	Weight (g)
484-7563	TYSUW-100	¥ 1,092	¥ 1,180	100 102.0	100	32	42	12	32	260
484-7571	TYSUW-125	¥ 1,371	¥ 1,480	130 132.6	125	43	55	12	16	350
493-1891	TYSUW-150	¥ 1,731	¥ 1,870	140 142.8	150	40	55	12	16	670



TYSUW-100

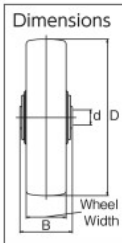

Contact us: 0120-509-849 <http://www.orange-book.com/>



Plate Type Caster

Fixed metal Casters equipped with Flexible metal Casters equipped with
fitting caster fixed metal stoppers fitting caster flexible metal stoppers



<Using plate type casters>

Used for handcarts, furniture carts and various apparatus.



Features

• Moves only front and rear.

Features

• The wheels freely move front and rear, right and left.

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers