

# Threaded Type Urethane Casters

The number next to the logo mark indicates items in stock for each brand.

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers




Stock 38,650 Items

## Threaded Type Caster (nylon wheel urethane tire)



TYST-100NU

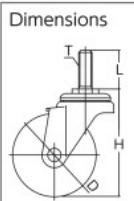

- Features • Excellent in oil resistance.  
• Does not pollute the floor surface.  
Specs • Threaded type

- Materials • Metal Fitting: Steel  
• Metal Fitting Surface Treatment: Trivalent Unichrome Plated  
• Wheel: Nylon Wheel, Urethane Origin • Japan

**Flexible** Specs • Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
278-3126	TYST-75NU	¥ 759	¥ 820	70	71.4	75	26	97	35	M12	1.75	20	360
278-3142	TYST-100NU	¥1,055	¥1,140	60	61.2	100	28	126	40	M16	2.00	20	435

TRUSCO NAKAYAMA CORPORATION



TYST-100NUS

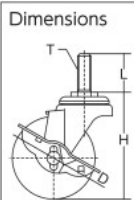

**Flexible with stopper** Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
278-3134	TYST-75NUS	¥ 889	¥ 960	70	71.4	75	26	97	35	M12	1.75	20	395
278-3151	TYST-100NUS	¥1,213	¥1,310	60	61.2	100	28	126	40	M16	2.00	20	505

Contact us:0120-509-849 <http://www.orange-book.com/>




Stock 793 Items

## Threaded Type Caster "420EA Series" (nylon wheel urethane tire)



420EA-UR75-BAR01

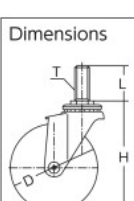

- Features • Resin bush is used, inexpensive finish.  
Specs • Threaded type

- Materials • Metal Fitting: Steel  
• Wheel: Nylon Wheel, Thermoplastic Urethane  
Origin • Japan

**Flexible** Specs • Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
367-1003	420EA-UR40-BAR01	¥ 366	-	30	30.6	38	16	59	35	M12	1.75	8	128
367-1011	420EA-UR50-BAR01	¥ 555	-	40	40.8	50	21	68	35	M12	1.75	4	164
367-1020	420EA-UR65-BAR01	¥ 814	-	40	40.8	65	21	85	35	M12	1.75	4	204
367-1038	420EA-UR75-BAR01	¥ 875	-	50	51.0	75	21	95	35	M12	1.75	4	229
367-1046	420EA-UR85-BAR01	¥1,429	-	60	61.2	85	27	107	40	M16	2.00	4	427
367-0988	420EA-UR100-BAR01	¥1,484	-	60	61.2	100	27	126	40	M16	2.00	2	473
367-0996	420EA-UR125-BAR01	¥1,800	-	70	71.4	125	27	152	40	M16	2.00	2	601

HAMMER CASTER Co.Ltd.

**Flexible with stopper** Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
367-0643	415EA-UR40-BAR01	¥ 435	-	30	30.6	38	16	59	35	M12	1.75	4	159
367-0651	415EA-UR50-BAR01	¥ 616	-	40	40.8	50	21	68	35	M12	1.75	4	200
367-0660	415EA-UR65-BAR01	¥ 872	-	40	40.8	65	21	85	35	M12	1.75	4	241
367-0678	415EA-UR75-BAR01	¥ 939	-	50	51.0	75	21	95	35	M12	1.75	4	268
367-0686	415EA-UR85-BAR01	¥1,522	-	60	61.2	85	27	107	40	M16	2.00	4	493
367-0627	415EA-UR100-BAR01	¥1,576	-	60	61.2	100	27	126	40	M16	2.00	2	538
367-0635	415EA-UR125-BAR01	¥1,889	-	70	71.4	125	27	152	40	M16	2.00	2	673

URL <http://www.hammer-caster.co.jp/>



Stock 793 Items


## Threaded Type Caster "420SA Series" (nylon wheel urethane tire)

- Features • With roller bearings, durable.  
Specs • Threaded type  
• Wheel Diameter 100 to 150mm Equipped with Radial Ball Bearing

- Materials • Metal Fitting: Steel  
• Wheel: Nylon Wheel, Thermoplastic Urethane  
Origin • Japan



420SA-UB75-BAR01

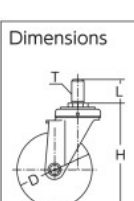

**Flexible** Specs • Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
367-1429	420SA-UB65-BAR01	¥1,209	-	70	71.4	65	27	89	40	M16	2.0	2	0.39
367-1437	420SA-UB75-BAR01	¥1,317	-	80	81.6	75	27	97	40	M16	2.0	2	0.42
367-1399	420SA-UB100-BAR01	¥2,779	-	100	102.0	100	32	138	40	M20	2.5	1	1.10
367-1402	420SA-UB125-BAR01	¥3,985	-	130	132.6	125	38	173	40	M20	2.5	1	1.51
367-1411	420SA-UB150-BAR01	¥4,832	-	140	142.8	150	38	196	40	M20	2.5	1	1.71

HAMMER CASTER Co.Ltd.

**Flexible with stopper** Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (kg)
				(daN)	(kgf)								
367-0392	413SA-UB65-BAR01	¥1,347	-	70	71.4	65	27	89	40	M16	2.0	2	0.44
367-0406	413SA-UB75-BAR01	¥1,419	-	80	81.6	75	27	97	40	M16	2.0	2	0.48
367-0368	413SA-UB100-BAR01	¥3,161	-	100	102.0	100	32	138	40	M20	2.5	1	1.24
367-0376	413SA-UB125-BAR01	¥4,373	-	130	132.6	125	38	173	40	M20	2.5	1	1.76
367-0384	413SA-UB150-BAR01	¥5,220	-	140	142.8	150	38	196	40	M20	2.5	1	1.98

URL <http://www.hammer-caster.co.jp/>