

# Pipe Inserted Type Casters (rubber wheel)

Stock 45Items

2-723

Prices displayed include 8% tax.


TRUSCO  
  
**Stock 38,650 Items**

## Pipe Inserted Type Caster (rubber wheel)

Com Drawing



TYLTF-75RHS

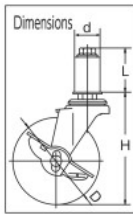

- Features** • A pipe inserted type caster able to be attached to indoor use transportation apparatus easily.  
**Specs** • Pipe inserted type  
 • Flexible Type (with stopper)  
**Materials** • Metal Fitting: Steel  
 • Metal Fitting Surface Treatment: Trivalent Unichrome Plated  
 • Wheel: Rubber  
**Origin** • Japan

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Pipe Diameter d (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)							
278-3231	TYLTF-75RHS	¥741	¥800	40	40.8	75	21	97	38	16	20	295

TRUSCO NAKAYAMA CORPORATION  
 Contact us: 0120-509-849 <http://www.orange-book.com/>


HAMMER CASTER  
  
**Stock 793 Items**

## Pipe Inserted Type Caster "K Series" (rubber wheel)

RoHS



420K-R65-BAR01

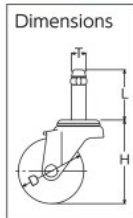

- Features** • An inserted type caster able to choose the installation method and installation location by selecting a socket and a bracket.  
**Specs** • Pipe inserted type  
**Materials** • Metal Fitting: Steel  
 • Metal fitting surface treatment: Chrome plated finishing  
 • Wheel: Rubber  
**Origin** • Japan

**Flexible** Specs • Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Mounting Pipe Outer Diameter T (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)							
398-4851	420K-R50-BAR01	¥446	-	30	30.6	50	20	64	38.5	11	8	188
398-4869	420K-R65-BAR01	¥608	-	30	30.6	65	21	81	38.5	11	4	247
398-4877	420K-R75-BAR01	¥685	-	40	40.8	75	21	91	38.5	11	4	290

**Flexible with stopper** Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Mounting Pipe Outer Diameter T (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)							
398-4702	415K-R50-BAR01	¥500	-	30	30.6	50	20	64	38.5	11	4	222
398-4711	415K-R65-BAR01	¥647	-	30	30.6	65	21	81	38.5	11	4	281
398-4729	415K-R75-BAR01	¥738	-	40	40.8	75	21	91	38.5	11	4	325

- Dedicated bracket** Features • The caster can be installed at various locations by using a socket and a bracket.  
**Materials** • Metal Fitting: Steel  
 • Metal fitting surface treatment: Trivalent chromium chemical conversion treatment

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Model		Item Name	SPQ (piece)	Weight (g)
				(daN)	(kgf)			
398-5059	KOOSKT-S15-BAR01	¥187	-	420	415K Type	Socket	1	62
398-5041	KOGBK-T-S50-BAR01	¥145	-	420	415K Type	Bracket	1	58

URL <http://www.hammer-caster.co.jp/>


HAMMER CASTER  
  
**Stock 793 Items**

## Pipe Inserted Type Caster "EN Series" (rubber wheel)

RoHS



4202EN-R75-BAR01

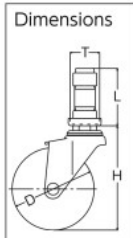

- Features** • An attaching-to-pipe caster able to be easily attached and detached by using dedicated spanner.  
**Specs** • Pipe inserted type • Attached pipe thickness: possible up to 1.8mm  
**Materials** • Metal Fitting: Steel  
 • Metal fitting surface treatment: Chrome plated finishing  
 • Wheel: Rubber  
**Origin** • Japan

**Flexible** Specs • Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Mounting Pipe Outer Diameter T (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)							
398-4753	4202EN-R75-BAR01	¥ 872	-	40	40.8	75	21	95	52	38	4	376
398-4737	4202EN-R100-BAR01	¥1,347	-	50	51.0	100	27	126	52	38	2	690
398-4745	4202EN-R125-BAR01	¥1,873	-	60	61.2	125	27	152	52	38	2	875

**Flexible with stopper** Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Mounting Pipe Outer Diameter T (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)							
398-4621	4152EN-R75-BAR01	¥ 936	-	40	40.8	75	21	95	52	38	4	411
398-4605	4152EN-R100-BAR01	¥1,436	-	50	51.0	100	27	126	52	38	2	763
398-4613	4152EN-R125-BAR01	¥1,966	-	60	61.2	125	27	152	52	38	2	951

URL <http://www.hammer-caster.co.jp/>

4152EN-R100-BAR01

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers