

Plate Type Anti-static Casters (press made rubber wheel/urethane wheel)

The number next to the logo mark indicates items in stock for each brand.

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers


TRUSCO Stock 38,650 Items

Plate Type electric conductive Caster (press made rubber wheel)

Com Drawing



TYEJ-150

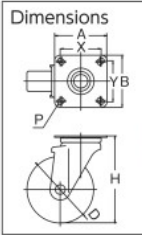

- Features**
- Discharge of static electric is easy due to usage of electro conductive rubber wheel, also excellent in dust absorption prevention effect.
- Specs**
- Plate Type
 - Surface Resistivity: $10^2 \Omega$ (measured value, not guaranteed value)
 - With Commercial Bearing
- Materials**
- Metal Fitting: Steel
 - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 - Wheel: Steel Wheel, Conductive Rubber
- Origin**
- Japan

Flexible Specs •Flexible Type


Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-1158	TYEJ-100	¥2,629	¥2,840	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.09
278-1166	TYEJ-130	¥3,722	¥4,020	180 183.6	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	1.90
278-1174	TYEJ-150	¥4,054	¥4,380	200 204.0	150	40	198	120 x 120	87 to 94 x 87 to 94	11	8	2.27



TYEJB-100A

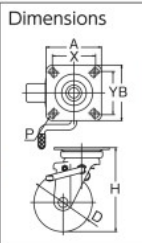


Flexible with double stopper Specs •Flexible Type (with double stopper)
•Simultaneously lock the turning part and the wheel

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
450-9919	TYEJB-100A	¥3,175	¥3,430	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.22
450-9927	TYEJB-130A	¥4,351	¥4,700	180 183.6	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	2.00
450-9935	TYEJB-150A	¥4,694	¥5,070	200 204.0	150	40	198	120 x 120	87 to 94 x 87 to 94	11	8	2.17



TYEK-150

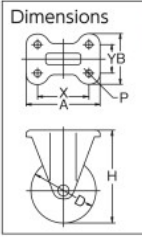

Fixed Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-1484	TYEK-100	¥2,250	¥2,430	100 102.0	100	32	144	115 x 80	80 x 45	11	16	0.84
278-1492	TYEK-130	¥3,129	¥3,380	180 183.6	130	40	177	137 x 93	100 x 56	11	8	1.50
278-1506	TYEK-150	¥3,444	¥3,720	200 204.0	150	40	198	137 x 93	100 x 56	11	8	1.71

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO Stock 38,650 Items

Plate Type Anti-static Caster (press made urethane wheel)

Com Drawing



TYUEJ-150

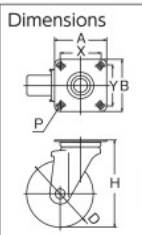

- Features**
- Electrification of static electric is prevented by using anti-static urethane car, a caster wherein dust does not easily adhere.
- Specs**
- Plate Type
 - Surface Resistivity: $10^8 \Omega$ (It is actually measured value, not guaranteed value.)
 - With Commercial Bearing
- Materials**
- Metal Fitting: Steel
 - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 - Wheel: Steel wheel, anti-static urethane
- Origin**
- Japan

Flexible Specs •Flexible Type

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-1620	TYUEJ-100	¥3,833	¥4,140	180 183.6	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.18
278-1638	TYUEJ-130	¥5,591	¥6,040	250 255.0	130	35	177	105 x 105	75 to 82 x 75 to 82	11	8	2.04
278-1646	TYUEJ-150	¥6,258	¥6,760	300 306.0	150	38	198	120 x 120	87 to 94 x 87 to 94	11	8	2.41


Flexible with double stopper Specs •Flexible Type (with double stopper)
•Simultaneously lock the turning part and the wheel

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
450-9854	TYUEJB-100A	¥4,378	¥4,730	180 183.6	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.32
450-9862	TYUEJB-130A	¥6,239	¥6,740	250 255.0	130	35	177	105 x 105	75 to 82 x 75 to 82	11	8	2.33
450-9871	TYUEJB-150A	¥6,943	¥7,500	300 306.0	150	38	198	120 x 120	87 to 94 x 87 to 94	11	8	2.71



TYUEJB-100A

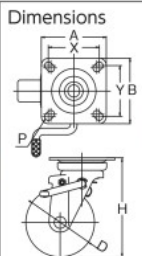

Fixed Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-1913	TYUEK-100	¥3,444	¥3,720	180 183.6	100	32	144	115 x 80	80 x 45	11	16	0.93
278-1921	TYUEK-130	¥4,999	¥5,400	250 255.0	130	35	177	137 x 93	100 x 56	11	8	1.66
278-1930	TYUEK-150	¥5,638	¥6,090	300 306.0	150	38	198	137 x 93	100 x 56	11	8	1.92

Contact us:0120-509-849 <http://www.orange-book.com/>