

Hinges (stainless steel)

For machine parts hinges, see p. 2-330 to 340

The number next to the logo mark indicates items in stock for each brand.

TRUSCO





Stock 38,650 Items

Thin Hinge



- Specs**
- Surface treatment: Electrolytic polished finishing
 - Thin type
 - Mounting Method: Wood Screws (accessory)
- Materials** •Stainless Steel (SUS430)
- Origin** •Japan

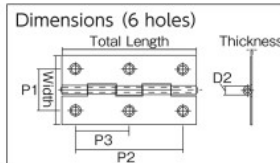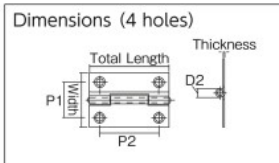

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Number of Wood Screws	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-6812	ST-550-25	¥ 583	¥ 630	25.5	21	0.8	3.8	4	3.0	40	1	10	45
233-6821	ST-550-32	¥ 648	¥ 700	31.5	22	0.8	3.8	4	3.3	40	1	10	50
233-6839	ST-550-38	¥ 713	¥ 770	38.0	26	0.8	4.0	4	3.5	40	2	10	90
233-6847	ST-550-51	¥1,037	¥1,120	51.0	30	0.8	4.4	6	3.8	60	3	10	150
233-6855	ST-550-64	¥1,389	¥1,500	64.0	33	0.8	4.4	6	3.8	60	6	10	200

Contact us:0120-509-849 <http://www.orange-book.com/>

Door Closers

Door Stoppers

Hinges

Dimensions Table (Unit: mm)

Total Length	P1	P2	P3	Wood Screw Size (D x L)
25.5	13.0	15.5	-	2.1 x 10
31.5	14.0	21.5	-	2.1 x 10
38.0	16.0	27.0	-	2.4 x 10
51.0	18.0	37.0	18.5	2.4 x 16
64.0	20.6	46.0	23.0	2.4 x 16

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers

TRUSCO



Stock 38,650 Items

Medium Thick Hinge






ST-999-51HL (without nylon rings)

Dimensions Table (Unit: mm)

Total Length	P1	P2	P3	Wood Screw Size (D x L)
51	20	36	-	2.7 x 13
64	22	50	25	2.7 x 16

- Specs**
- Surface treatment: Hair line finishing
 - Mounting Method: Wood Screws (accessory)
- Materials** •Stainless Steel (SUS430)
- Origin** •Japan

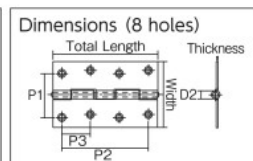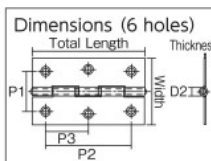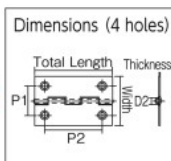

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Number of Wood Screws	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-6863	ST-999-51HL	¥1,111	¥1,200	51	34	0.8	4.8	4	4.2	40	3	10	160
233-6871	ST-999-64HL	¥1,481	¥1,600	64	38	0.8	5.3	6	4.2	60	5	10	250

With nylon ring Specs •With Nylon Ring

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Number of Wood Screws	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-7151	ST-999NR-76HL	¥ 907	¥ 980	76	45	1.00	6.0	6	4.5	24	8	4	152
233-7169	ST-999NR-89HL	¥1,259	¥1,360	89	56	1.20	7.0	6	5.5	24	10	4	248
233-7177	ST-999NR-102HL	¥1,695	¥1,830	102	65	1.50	8.0	8	5.4	32	13	4	384

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO






Stock 38,650 Items

Thick Hinge



ST-888-76HL (without nylon ring)

- Specs**
- Surface treatment: Hair line finishing
 - Mounting Method: Wood Screws (accessory)
- Materials** •Stainless Steel (SUS304)
- Origin** •Japan

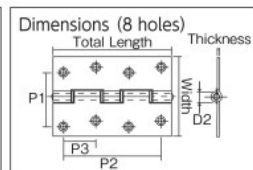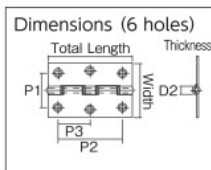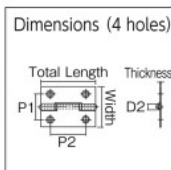

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Number of Wood Screws	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-5328	ST-888-51HL	¥ 861	¥ 930	51	38	1.2	6.2	4	4.2	16	5	4	108
233-5336	ST-888-64HL	¥1,065	¥1,150	64	42	1.2	6.2	6	5.0	24	8	4	148
233-5344	ST-888-76HL	¥1,481	¥1,600	76	49	1.5	7.5	6	5.2	24	12	4	240
233-5352	ST-888-89HL	¥2,037	¥2,200	89	55	1.5	9.0	6	5.2	24	16	4	376
233-5361	ST-888-102HL	¥2,638	¥2,850	102	70	2.0	10.0	8	5.8	32	20	4	528

With nylon ring Specs •With Nylon Ring

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Number of Wood Screws	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-5506	ST-888NR-51HL	¥ 972	¥1,050	51	38	1.2	6.2	4	4.2	16	5	4	108
233-5514	ST-888NR-64HL	¥1,157	¥1,250	64	42	1.2	6.2	6	5.0	24	8	4	140
233-5522	ST-888NR-76HL	¥1,648	¥1,780	76	49	1.5	7.5	6	5.2	24	12	4	232
233-5531	ST-888NR-89HL	¥2,268	¥2,450	89	55	1.5	9.0	6	5.2	24	16	4	364
233-5549	ST-888NR-102HL	¥2,916	¥3,150	102	70	2.0	10.0	8	5.8	32	20	4	564
233-5557	ST-888NR-127HL	¥2,314	¥2,500	127	79	2.0	12.2	8	6.2	16	30	2	464

Contact us:0120-509-849 <http://www.orange-book.com/>