

Prices displayed include 8% tax.


For machine parts hinges, see p. 2-330 to 340

TRUSCO **Stock 38,650 Items**

Super Thick Welding Hinge



- Specs • Surface Treatment: Fabric Finishing
 • Mounting Method: Welding Type
 Materials • Steel (SPHC)
 Origin • Japan

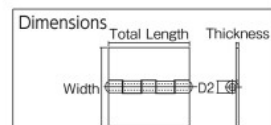

1000W-64

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | Total Length (mm) | Width (mm) | Thickness (mm) | D2 (mm) | Load Capacity (kg) when 2 pieces used | Q'ty Per Bag (piece) | Weight (kg/bag) |
|------------|-----------|-----------------|----------------|-------------------|------------|----------------|---------|---------------------------------------|----------------------|-----------------|
| 233-5875 | 1000W-51 | ¥ 889 | ¥ 960 | 51 | 47 | 2.5 | 10.2 | 15 | 4 | 0.30 |
| 233-5883 | 1000W-64 | ¥ 1,074 | ¥ 1,160 | 64 | 62 | 3.0 | 12.2 | 18 | 4 | 0.54 |
| 233-5891 | 1000W-76 | ¥ 1,435 | ¥ 1,550 | 76 | 72 | 3.5 | 14.0 | 25 | 4 | 0.95 |
| 233-5905 | 1000W-89 | ¥ 1,926 | ¥ 2,080 | 89 | 85 | 3.8 | 15.1 | 35 | 4 | 1.27 |
| 233-5913 | 1000W-102 | ¥ 2,407 | ¥ 2,600 | 102 | 100 | 4.0 | 16.0 | 45 | 4 | 1.74 |
| 233-5921 | 1000W-127 | ¥ 2,175 | ¥ 2,350 | 127 | 124 | 4.5 | 19.0 | 60 | 2 | 1.44 |
| 233-5930 | 1000W-153 | ¥ 3,194 | ¥ 3,450 | 153 | 142 | 5.0 | 22.0 | 80 | 2 | 2.38 |


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Super Thick Welding Flag Hinge



- Specs • Surface Treatment: Fabric Finishing
 • Mounting Method: Welding Type
 Materials • Steel (SPHC)
 Origin • Japan

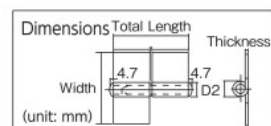

2000W-102R (for right)



2000W-102L (for left)

For right

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | Total Length (mm) | Width (mm) | Thickness (mm) | D2 (mm) | Load Capacity (kg) when 2 pieces used | Q'ty Per Bag (piece) | Weight (kg/bag) |
|------------|------------|-----------------|----------------|-------------------|------------|----------------|---------|---------------------------------------|----------------------|-----------------|
| 512-7971 | 2000W-76R | ¥ 2,314 | ¥ 2,500 | 75 | 108 | 3.0 | 18 | 25 | 4 | 0.94 |
| 512-7980 | 2000W-102R | ¥ 2,592 | ¥ 2,800 | 102 | 108 | 4.0 | 20 | 40 | 4 | 1.61 |
| 512-7998 | 2000W-127R | ¥ 1,574 | ¥ 1,700 | 127 | 104 | 4.5 | 22 | 50 | 2 | 1.08 |
| 512-8005 | 2000W-153R | ¥ 1,898 | ¥ 2,050 | 149 | 104 | 4.5 | 22 | 65 | 2 | 1.22 |

For left

Order Unit: 1 Bag

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | Total Length (mm) | Width (mm) | Thickness (mm) | D2 (mm) | Load Capacity (kg) when 2 pieces used | Q'ty Per Bag (piece) | Weight (kg/bag) |
|------------|------------|-----------------|----------------|-------------------|------------|----------------|---------|---------------------------------------|----------------------|-----------------|
| 233-5948 | 2000W-76L | ¥ 2,314 | ¥ 2,500 | 75 | 108 | 3.0 | 18 | 25 | 4 | 0.94 |
| 233-5956 | 2000W-102L | ¥ 2,592 | ¥ 2,800 | 102 | 108 | 4.0 | 20 | 40 | 4 | 1.61 |
| 233-5964 | 2000W-127L | ¥ 1,574 | ¥ 1,700 | 127 | 104 | 4.5 | 22 | 50 | 2 | 1.08 |
| 233-5972 | 2000W-153L | ¥ 1,898 | ¥ 2,050 | 149 | 104 | 4.5 | 22 | 65 | 2 | 1.22 |


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Unichrome Long Hinge



- Specs • Surface treatment: Trivalent unichrome-plated finishing
 • Mounting Method: Welding Type
 Materials • Steel (SPCC)
 Origin • Japan

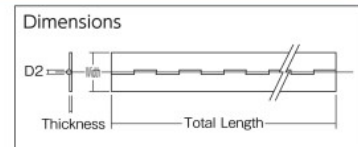

THN-1650-1000

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Total Length (mm) | Width (mm) | Thickness (mm) | D2 (mm) | SPQ (piece) | Weight (kg) |
|------------|---------------|-------------------|------------------|-------------------|------------|----------------|---------|-------------|-------------|
| 285-3337 | THN-1025-300 | ¥ 528 | ¥ 570 | 300 | 25 | 1.0 | 2.5 | 20 | 0.09 |
| 285-3329 | THN-1025-600 | ¥ 926 | ¥ 1,000 | 600 | 25 | 1.0 | 2.5 | 20 | 0.17 |
| 285-3311 | THN-1025-1000 | ¥ 1,296 | ¥ 1,400 | 1000 | 25 | 1.0 | 2.5 | 20 | 0.28 |
| 285-3302 | THN-1025-1800 | ¥ 2,916 | ¥ 3,150 | 1800 | 25 | 1.0 | 2.5 | 10 | 0.50 |
| 285-3167 | THN-1032-600 | ¥ 972 | ¥ 1,050 | 600 | 32 | 1.0 | 2.5 | 20 | 0.21 |
| 285-3159 | THN-1032-1000 | ¥ 1,462 | ¥ 1,580 | 1000 | 32 | 1.0 | 2.5 | 20 | 0.33 |
| 285-3141 | THN-1032-1800 | ¥ 2,916 | ¥ 3,150 | 1800 | 32 | 1.0 | 2.5 | 10 | 0.60 |
| 285-3183 | THN-1038-1000 | ¥ 1,500 | ¥ 1,620 | 1000 | 38 | 1.0 | 2.5 | 20 | 0.66 |
| 285-3175 | THN-1038-1800 | ¥ 3,240 | ¥ 3,500 | 1800 | 38 | 1.0 | 2.5 | 10 | 0.70 |
| 285-3264 | THN-1632-300 | ¥ 630 | ¥ 680 | 300 | 32 | 1.6 | 3.5 | 20 | 0.18 |
| 285-3256 | THN-1632-350 | ¥ 666 | ¥ 720 | 350 | 32 | 1.6 | 3.5 | 20 | 0.21 |
| 285-3248 | THN-1632-450 | ¥ 796 | ¥ 860 | 450 | 32 | 1.6 | 3.5 | 20 | 0.26 |
| 285-3230 | THN-1632-600 | ¥ 1,000 | ¥ 1,080 | 600 | 32 | 1.6 | 3.5 | 20 | 0.35 |
| 285-3221 | THN-1632-750 | ¥ 1,157 | ¥ 1,250 | 750 | 32 | 1.6 | 3.5 | 20 | 0.44 |
| 285-3213 | THN-1632-850 | ¥ 1,203 | ¥ 1,300 | 850 | 32 | 1.6 | 3.5 | 20 | 0.50 |
| 285-3205 | THN-1632-900 | ¥ 1,342 | ¥ 1,450 | 900 | 32 | 1.6 | 3.5 | 20 | 0.53 |
| 285-3191 | THN-1632-1000 | ¥ 1,555 | ¥ 1,680 | 1000 | 32 | 1.6 | 3.5 | 20 | 0.60 |
| 285-3272 | THN-1638-1800 | ¥ 3,888 | ¥ 4,200 | 1800 | 38 | 1.6 | 3.5 | 10 | 1.18 |
| 285-3299 | THN-1650-1000 | ¥ 2,499 | ¥ 2,700 | 1000 | 50 | 1.6 | 3.5 | 20 | 0.79 |
| 285-3281 | THN-1650-1800 | ¥ 4,305 | ¥ 4,650 | 1800 | 50 | 1.6 | 3.5 | 10 | 1.44 |

Contact us: 0120-509-849 <http://www.orange-book.com/>