

Welded Hinges (stainless steel) / Double Acting Spring Hinges

Stock 232 Items

2-843

Prices displayed include 8% tax.

For machine parts hinges, see p. 2-330 to 340

Hardware

TRUSCO Stock 38,650 Items


Thick Welded Hinge

Com Drawing



ST-888W-64HL

- Specs
- Surface treatment: Hair line finishing
 - Mounting Method: Welding Type
- Materials
- Stainless Steel (SUS304)
- Origin
- Japan

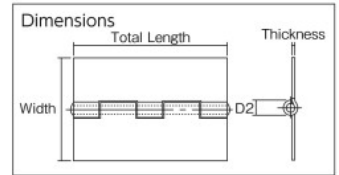

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Load Capacity (kg) when 2 pieces used	Q'ty Per Bag (piece)	Weight (g/bag)
233-5689	ST-888W-51HL	¥1,944	¥2,100	51	38.0	1.2	6.2	5	10	280
233-5697	ST-888W-64HL	¥2,407	¥2,600	64	42.0	1.2	6.2	8	10	400
233-5701	ST-888W-76HL	¥1,389	¥1,500	76	49.0	1.5	7.5	12	4	260
233-5719	ST-888W-89HL	¥1,944	¥2,100	89	56.0	1.5	9.0	16	4	388
233-5727	ST-888W-102HL	¥1,296	¥1,400	102	69.5	2.0	10.0	20	2	274

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items


Flat Hinge

Com Drawing



TLS-90A

- Specs
- Surface treatment: Mirror buffing process finishing
 - Mounting Method: Welding Type
- Materials
- Stainless Steel (SUS304)
- Origin
- China

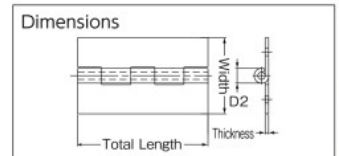

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

(Price revision date: Jan, 2016)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Load Capacity (kg) when 2 pieces used	SPQ (piece)	Weight (g)
279-5825	TLS-40A	¥ 352	¥ 380	40	35	1.5	6.3	6	100	25
279-5833	TLS-50A	¥ 407	¥ 440	50	35	1.5	6.3	8	100	30
279-5841	TLS-65A	¥ 713	¥ 770	65	50	2.0	8.8	13	50	66
279-5850	TLS-75A	¥ 787	¥ 850	75	50	2.0	8.8	15	40	76
279-5868	TLS-90A	¥1,435	¥1,550	90	60	3.0	12.3	25	10	190
279-5876	TLS-100A	¥1,545	¥1,670	100	60	3.0	12.3	30	10	200

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items



Double Acting Spring Hinge (double opening)

Com Drawing



THN-100-64

- Specs
- Surface Treatment: Black Coated Finishing
 - Mounting Method: Wood Screws (accessory)
 - Double Type
 - With opening and closing strength adjustment.
- Materials
- Steel (SPCC)
- Origin
- Taiwan

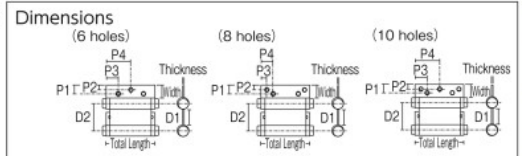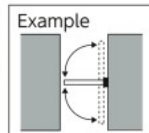

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Box

Dimensions Table (Unit: mm)

Total Length	P1	P2	P3	P4	Wood Screw Size (D x L)
64	13	7	9	32.0	M3.1 x 20 6 Pieces
76	15	8	9	21.0	M3.1 x 20 8 Pieces
102	15	9	13	30.0	M3.1 x 20 8 Pieces
127	21	10	38	63.5	M3.5 x 25 10 Pieces
153	24	12	45	76.5	M3.5 x 25 10 Pieces

Order Code	Item No.	Price (per box)	MSRP (per box)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	D1 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	Q'ty Per Box (piece)	Weight (kg/box)
285-2861	THN-100-64	¥1,722	¥1,860	64	20	1.6	45	22	6	4	5	2	0.45
285-2870	THN-100-76	¥1,778	¥1,920	76	21	1.6	49	24	8	5	7	2	0.57
285-2888	THN-100-102	¥2,083	¥2,250	102	25	1.6	52	28	8	5	10	2	0.78
285-2896	THN-100-127	¥3,572	¥3,859	127	30	2.0	66	35	10	5	13	2	1.45
285-2900	THN-100-153	¥4,434	¥4,790	153	34	2.0	70	40	10	5	15	2	1.78

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items



Double Acting Spring Hinge (double opening)

Com Drawing



TFSH-150-64

- Specs
- Surface treatment: Buffing polishing
 - Mounting Method: Wood Screws (accessory)
 - Double Type
 - With opening/closing torque adjustment
- Materials
- Main Body: Stainless Steel (SUS304)
 - Spring: SWC spring steel
- Origin
- Taiwan

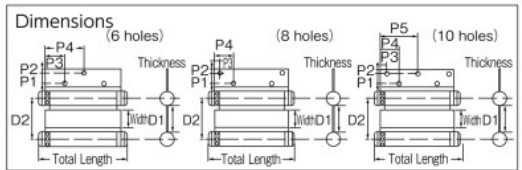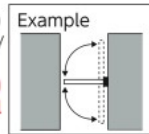

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Box

Dimensions Table (Unit: mm)

Total Length	P1	P2	P3	P4	P5	Wood Screw Size (D x L)
64	13.0	7.5	10.7	32.0	-	3.1 x 20 6 Pieces
76	14.0	7.5	10.5	19.0	-	3.5 x 22 8 Pieces
102	17.5	8.5	11.2	27.7	-	3.5 x 22 8 Pieces
127	20.5	9.5	15.0	38.0	63.5	3.8 x 32 10 Pieces
153	24.0	11.5	15.0	45.0	76.0	3.8 x 32 10 Pieces

Order Code	Item No.	Price (per box)	MSRP (per box)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	D1 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	Q'ty Per Box (piece)	SPQ (box)	Weight (kg/box)
496-0351	TFSH-150-64	¥ 4,443	¥ 4,800	64	22	1.5	44.7	19	6	5	5	2	20	0.47
496-0360	TFSH-150-76	¥ 5,628	¥ 6,080	76	24	1.5	51.0	23	8	5	7	2	20	0.64
496-0327	TFSH-150-102	¥ 6,517	¥ 7,040	102	28	1.5	57.0	29	8	5	10	2	20	0.85
496-0335	TFSH-150-127	¥10,072	¥10,880	127	35	1.8	66.0	29	10	5	13	2	20	1.48
496-0343	TFSH-150-153	¥14,219	¥15,360	153	38	1.8	72.0	40	10	5	15	2	15	1.73

Contact us:0120-509-849 <http://www.orange-book.com/>