

The number next to the logo mark indicates items in stock for each brand.

TRUSCO




Stock 38,650 Items

Ground Hook



TGF-A3

- Features** • Since the ring part collapses, it does not get in the way when not in use.
Use • As a bracket of thin wire, rope, and such of terminal process of tent rope, vertical banner and the like.
Materials • **Stainless Steel (SUS304)**
Origin • China

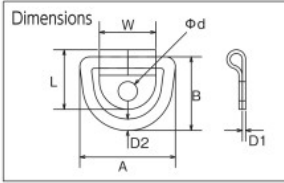

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | D1 (mm) | L (mm) | W (mm) | d (mm) | D2 (mm) | A (mm) | B (mm) | Working Load (kN) | Qty Per Bag (piece) | SPQ (bag) | Weight (g/bag) |
|------------|----------|-----------------|----------------|---------|--------|--------|--------|---------|--------|--------|-------------------|---------------------|-----------|----------------|
| 300-8614 | TGF-A2 | ¥444 | ¥480 | 1.0 | 11 | 10 | 3.8 | 2.0 | 17 | 14 | 0.05 | 2 | 50 | 5 |
| 300-8622 | TGF-A25 | ¥518 | ¥560 | 1.0 | 15 | 13 | 3.8 | 2.5 | 22 | 19 | 0.07 | 2 | 50 | 9 |
| 300-8631 | TGF-A3 | ¥611 | ¥660 | 1.0 | 18 | 15 | 4.8 | 3.0 | 27 | 23 | 0.10 | 2 | 20 | 15 |
| 300-8649 | TGF-A4 | ¥787 | ¥850 | 1.2 | 21 | 20 | 6.8 | 4.0 | 34 | 26 | 0.15 | 2 | 20 | 30 |

Contact us: 0120-509-849 <http://www.orange-book.com/>

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers

TRUSCO




Stock 38,650 Items

Ground Hook



TGF-B3

- Features** • Since the ring part collapses, it does not get in the way when not in use.
Use • As a bracket of thin wire, rope, and such of terminal process of tent rope, vertical banner and the like.
Materials • **Stainless Steel (SUS304)**
Origin • China

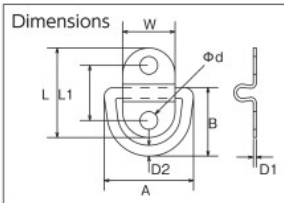

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | D1 (mm) | L (mm) | L1 (mm) | W (mm) | d (mm) | D2 (mm) | A (mm) | B (mm) | Working Load (kN) | Qty Per Bag (piece) | SPQ (bag) | Weight (g/bag) |
|------------|----------|-----------------|----------------|---------|--------|---------|--------|--------|---------|--------|--------|-------------------|---------------------|-----------|----------------|
| 300-8657 | TGF-B2 | ¥490 | ¥530 | 1.0 | 17 | 9.5 | 10 | 3.8 | 2.0 | 17 | 14 | 0.05 | 2 | 50 | 5 |
| 300-8665 | TGF-B25 | ¥593 | ¥640 | 1.0 | 25 | 17.0 | 13 | 3.8 | 2.5 | 22 | 19 | 0.07 | 2 | 50 | 9 |
| 300-8673 | TGF-B3 | ¥676 | ¥730 | 1.0 | 30 | 20.0 | 15 | 4.8 | 3.0 | 27 | 23 | 0.10 | 2 | 20 | 15 |
| 300-8681 | TGF-B4 | ¥879 | ¥950 | 1.2 | 34 | 21.0 | 20 | 6.8 | 4.0 | 34 | 26 | 0.15 | 2 | 20 | 30 |

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO




Stock 38,650 Items

Hanger Unit D Type



THUD-2613

- Features** • Since the ring part collapses, it is hard to get in the way when not in use.
Use • It is used as a hook by attaching on a wall or a floor like an eye plate.
Materials • **Stainless Steel (SUS304)**
Accessories • Stainless steel countersunk wood screw
Origin • China

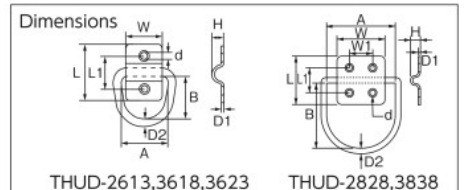

THUD-2613,3618,3623 THUD-2828,3838

Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | D1 (mm) | L x W (mm) | L1 (mm) | W1 (mm) | H (mm) | d (mm) | D2 (mm) | A (mm) | B (mm) | Working Load (kN) | SPQ (piece) | Weight (g) |
|------------|-----------|-------------------|------------------|---------|------------|---------|---------|--------|--------|---------|--------|--------|-------------------|-------------|------------|
| 380-3856 | THUD-2613 | ¥379 | ¥410 | 1.5 | 26 x 13 | 15.5 | - | 6.5 | 3.2 | 4 | 20 | 17 | 0.1 | 20 | 12 |
| 380-3872 | THUD-3618 | ¥407 | ¥440 | 1.5 | 36 x 18 | 21.0 | - | 7.5 | 3.2 | 4 | 20 | 17 | 0.1 | 20 | 16 |
| 380-3881 | THUD-3623 | ¥528 | ¥570 | 1.5 | 36 x 23 | 21.0 | - | 7.5 | 4.2 | 5 | 30 | 27 | 0.1 | 20 | 26 |
| 380-3864 | THUD-2828 | ¥565 | ¥610 | 1.5 | 28 x 28 | 17.0 | 14 | 7.5 | 3.2 | 5 | 35 | 32 | 0.1 | 20 | 29 |
| 380-3899 | THUD-3838 | ¥648 | ¥700 | 1.5 | 38 x 38 | 22.5 | 19 | 8.5 | 3.5 | 5 | 45 | 42 | 0.1 | 20 | 43 |

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO




Stock 38,650 Items

Round Ring Plate



TMP-5

- Features** • Since it has a round hook, it is easy to pass thick ropes and the like.
Use • Set up on the wall, floor, pillar, etc., as a terminal metal fitting for the chain, wire, and rope.
Materials • **Stainless Steel (SUS304)**
Origin • China

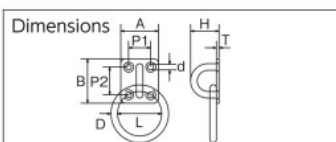

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | D (mm) | L (mm) | A x B (mm) | P1 x P2 (mm) | H (mm) | d (mm) | T (mm) | Working Load (kN) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|--------|--------|------------|--------------|--------|--------|--------|-------------------|-------------|------------|
| 328-5871 | TMP-5 | ¥731 | ¥790 | 5 | 30 | 30 x 34 | 18 x 22 | 19.5 | 4.2 | 2.5 | 0.15 | 20 | 39 |
| 328-5880 | TMP-6 | ¥852 | ¥920 | 6 | 40 | 34 x 40 | 20 x 25 | 25.5 | 5.2 | 2.5 | 0.20 | 20 | 66 |
| 328-5898 | TMP-8 | ¥1,371 | ¥1,480 | 8 | 50 | 39 x 50 | 25 x 35 | 32.0 | 5.2 | 3.0 | 0.29 | 10 | 135 |

Contact us: 0120-509-849 <http://www.orange-book.com/>