


Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items


Domestic Carabiner Piton NS Type



TSKH-8NS

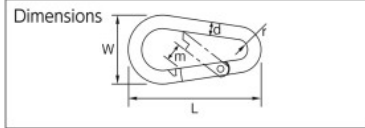

- Features**
- High quality carabiner manufactured in Japan.
 - Since it did final adjustment by handy work, it realizes smooth opening/closing.
 - Smooth barrel polished finishing that is gentle for bare hands.
 - More excellent in wear resistance compared with aluminum alloy products.
 - For a connection hook to chains, wires, or ropes. For joint of edge brackets.
- Use**
- Materials**
- Stainless Steel (SUS304)**
 - Surface treatment: Barrel polished finishing**
- Origin**
- Japan

 

Warning
•Do not directly use for securing a human body.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | d (mm) | L (mm) | W (mm) | r (mm) | m (mm) | Working Load (kN) | SPQ (piece) | Weight (g) |
|------------|-----------|-------------------|------------------|--------|--------|--------|--------|--------|-------------------|-------------|------------|
| 819-1380 | TSKH-6NS | ¥1,574 | ¥1,700 | 6 | 60 | 31 | 4.5 | 8 | 0.34 | 20 | 27.5 |
| 819-1379 | TSKH-8NS | ¥1,805 | ¥1,950 | 8 | 80 | 40 | 5.0 | 9 | 0.74 | 20 | 65.0 |
| 819-1382 | TSKH-10NS | ¥3,610 | ¥3,900 | 10 | 110 | 55 | 7.5 | 15 | 1.47 | 10 | 142.0 |
| 819-1381 | TSKH-12NS | ¥5,369 | ¥5,800 | 12 | 140 | 70 | 10.0 | 20 | 1.96 | 5 | 266.0 |


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Domestic Carabiner Piton NS Type



TKH-8NS

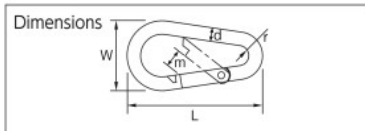

- Features**
- High quality carabiner manufactured in Japan.
 - Since it did final adjustment by handy work, it realizes smooth opening/closing.
 - Nickel plating finishing that is gentle even for bare hands.
 - More excellent in wear resistance compared with aluminum alloy products.
 - For a connection hook to chains, wires, or ropes. For joint of edge brackets.
- Use**
- Materials**
- Steel**
 - Surface Treatment: Nickel Plate Finishing**
- Origin**
- Japan



Warning
•Do not directly use for securing a human body.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | d (mm) | L (mm) | W (mm) | r (mm) | m (mm) | Working Load (kN) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|--------|--------|--------|--------|--------|-------------------|-------------|------------|
| 819-1392 | TKH-6NS | ¥ 833 | ¥ 900 | 6 | 60 | 31 | 4.5 | 8 | 0.25 | 20 | 27.5 |
| 819-1391 | TKH-8NS | ¥ 907 | ¥ 980 | 8 | 80 | 40 | 5.0 | 9 | 0.64 | 20 | 65.0 |
| 819-1394 | TKH-10NS | ¥1,166 | ¥1,260 | 10 | 110 | 55 | 7.5 | 15 | 1.47 | 10 | 142.0 |
| 819-1393 | TKH-12NS | ¥1,814 | ¥1,960 | 12 | 140 | 70 | 10.0 | 20 | 1.96 | 5 | 266.0 |


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items


Snap Hook A Type with Ring



TSF-6A (no ring)

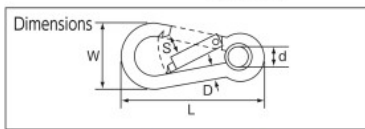

 - Features**
- Since it has a ring, it prevents entanglement.
- Use**
- Suitable for connection of chain/wire/rope, etc., and joint of terminal metal fittings.
- Materials**
- Stainless Steel (SUS304)**
- Origin**
- China



Example

Order Unit: 1 Bag

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | D (mm) | L (mm) | W (mm) | S (mm) | d (mm) | Working Load (kN) | Q'ty Per Bag (piece) | SPQ (bag) | Weight (g/bag) |
|------------|----------|-----------------|----------------|--------|--------|--------|--------|--------|-------------------|----------------------|-----------|----------------|
| 275-4274 | TSF-4A | ¥1,074 | ¥1,160 | 4 | 45 | 22.0 | 7.0 | 5.5 | 0.29 | 2 | 20 | 18 |
| 275-4282 | TSF-5A | ¥1,389 | ¥1,500 | 5 | 53 | 26.0 | 7.0 | 6.0 | 0.59 | 2 | 20 | 36 |
| 275-4291 | TSF-6A | ¥1,610 | ¥1,740 | 6 | 61 | 31.5 | 9.0 | 7.5 | 0.78 | 2 | 20 | 58 |
| 275-4304 | TSF-7A | ¥1,102 | ¥1,190 | 7 | 70 | 36.0 | 9.5 | 8.0 | 0.98 | 1 | 20 | 46 |
| 275-4312 | TSF-8A | ¥1,342 | ¥1,450 | 8 | 80 | 40.0 | 11.0 | 10.0 | 1.18 | 1 | 20 | 68 |
| 275-4321 | TSF-10A | ¥2,083 | ¥2,250 | 10 | 102 | 50.0 | 13.0 | 14.0 | 1.47 | 1 | 10 | 132 |
| 275-4339 | TSF-11A | ¥2,777 | ¥3,000 | 11 | 120 | 60.0 | 17.0 | 16.0 | 1.96 | 1 | 10 | 193 |
| 275-4347 | TSF-12A | ¥3,240 | ¥3,500 | 12 | 140 | 68.0 | 21.0 | 16.0 | 2.45 | 1 | 10 | 265 |


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items


Snap Hook B Type



TSF-6B

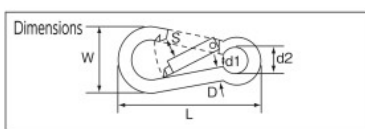

 - Features**
- Standard spring hook.
- Use**
- Suitable for connection of chain/wire/rope, etc., and joint of terminal metal fittings.
- Materials**
- Stainless Steel (SUS304)**
- Origin**
- China



Example

Order Unit: 1 Bag

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per bag) | MSRP (per bag) | D (mm) | L (mm) | W (mm) | S (mm) | d1 (mm) | d2 (mm) | Working Load (kN) | Q'ty Per Bag (piece) | SPQ (bag) | Weight (g/bag) |
|------------|----------|-----------------|----------------|--------|--------|--------|--------|---------|---------|-------------------|----------------------|-----------|----------------|
| 275-0678 | TSF-3B | ¥ 926 | ¥1,000 | 3 | 38 | 19.0 | 6.0 | 4.5 | 7.0 | 0.10 | 2 | 20 | 8 |
| 275-0686 | TSF-4B | ¥ 897 | ¥ 970 | 4 | 45 | 22.0 | 7.0 | 4.5 | 6.5 | 0.29 | 2 | 20 | 18 |
| 275-0694 | TSF-5B | ¥1,185 | ¥1,280 | 5 | 53 | 26.0 | 7.0 | 5.5 | 8.0 | 0.59 | 2 | 20 | 34 |
| 275-0708 | TSF-6B | ¥1,416 | ¥1,530 | 6 | 61 | 31.5 | 9.0 | 6.5 | 9.0 | 0.78 | 2 | 20 | 56 |
| 275-0716 | TSF-7B | ¥ 962 | ¥1,040 | 7 | 70 | 36.0 | 9.5 | 8.0 | 11.0 | 0.98 | 1 | 20 | 43 |
| 275-0724 | TSF-8B | ¥1,083 | ¥1,170 | 8 | 80 | 40.0 | 11.0 | 9.0 | 12.0 | 1.18 | 1 | 20 | 66 |
| 275-0732 | TSF-10B | ¥1,907 | ¥2,060 | 10 | 102 | 50.0 | 13.0 | 11.0 | 16.0 | 1.47 | 1 | 10 | 131 |
| 275-0741 | TSF-11B | ¥2,944 | ¥3,180 | 11 | 120 | 60.0 | 17.0 | 14.0 | 19.0 | 1.96 | 1 | 10 | 193 |
| 275-0759 | TSF-12B | ¥3,518 | ¥3,800 | 12 | 140 | 68.0 | 21.0 | 13.0 | 19.0 | 2.45 | 1 | 10 | 261 |

Contact us:0120-509-849 <http://www.orange-book.com/>