

Joint Fittings

The number next to the logo mark indicates items in stock for each brand.

Hardware

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers


TRUSCO **Stock 38,650 Items**

"Joint Metal Fitting 19 Type Flat"

Com **eco** Chemical Content Inspection
Com **Drawing**

Features • A simple and versatile combination.
Use • Connecting metal fitting. • Car parts mounting metal fitting.

Specs • Hole Pitch: 25mm
Origin • Japan

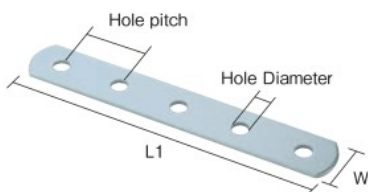

TK19-F5C (steel)



TK19-F5B (steel (black finishing))



TK19-F5S (stainless steel)

Steel Materials • Steel
• Surface Treatment: Chrome Plated Finishing

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
284-0758	TK19-F2C	¥139	¥150	2	19	50	6.5	2	20	13
284-0766	TK19-F3C	¥148	¥160	2	19	75	6.5	3	20	20
284-0774	TK19-F4C	¥176	¥190	2	19	100	6.5	4	20	26
284-0782	TK19-F5C	¥194	¥210	2	19	125	6.5	5	20	33
284-0791	TK19-F6C	¥204	¥220	2	19	150	6.5	6	20	40
284-0804	TK19-F7C	¥231	¥250	2	19	175	6.5	7	20	47
284-0812	TK19-F8C	¥241	¥260	2	19	200	6.5	8	20	54

Steel (black coating finishing) Materials • Steel
• Surface Treatment: Black Coated Finishing

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0436	TK19-F2B	¥139	¥150	2	19	50	6.5	2	20	12
482-0444	TK19-F3B	¥148	¥160	2	19	75	6.5	3	20	19
482-0452	TK19-F4B	¥176	¥190	2	19	100	6.5	4	20	25
482-0461	TK19-F5B	¥194	¥210	2	19	125	6.5	5	20	31
482-0479	TK19-F6B	¥204	¥220	2	19	150	6.5	6	20	38
482-0487	TK19-F7B	¥231	¥250	2	19	175	6.5	7	20	45
482-0495	TK19-F8B	¥241	¥260	2	19	200	6.5	8	20	51

Stainless Steel Materials • Stainless Steel (SUS304)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
284-0847	TK19-F2S	¥204	¥220	2	19	50	6.5	2	20	12
284-0855	TK19-F3S	¥241	¥260	2	19	75	6.5	3	20	19
284-0863	TK19-F4S	¥241	¥260	2	19	100	6.5	4	20	25
284-0871	TK19-F5S	¥278	¥300	2	19	125	6.5	5	20	31
284-0880	TK19-F6S	¥306	¥330	2	19	150	6.5	6	20	38
284-0898	TK19-F7S	¥334	¥360	2	19	175	6.5	7	20	45
284-0901	TK19-F8S	¥370	¥400	2	19	200	6.5	8	20	51

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

"Joint Metal Fitting 19 Type U"

Com **eco** Chemical Content Inspection
Com **Drawing**

Features • A simple and versatile combination.
Use • Connecting metal fitting. • Car parts mounting metal fitting.

Origin • Japan

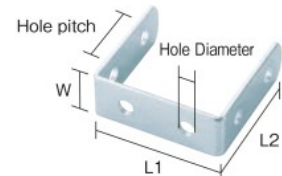

TK19-U6AC (steel)



TK19-U6AB (steel (black coating finishing))



TK19-U6AS (stainless steel)

Steel Materials • Steel
• Surface Treatment: Chrome Plated Finishing

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1716	TK19-U3C	¥185	¥200	2	19	28	27	6.5	3	5	20
283-1724	TK19-U4C	¥194	¥210	2	19	53	27	6.5	4	5	27
283-1732	TK19-U5C	¥231	¥250	2	19	78	27	6.5	5	5	33
287-9069	TK19-U6C	¥278	¥300	2	19	103	27	6.5	6	5	40
283-1741	TK19-U6AC	¥287	¥310	2	19	53	52	6.5	6	5	40
283-1759	TK19-U7AC	¥296	¥320	2	19	78	52	6.5	7	5	47
283-1767	TK19-U8AC	¥306	¥330	2	19	103	52	6.5	8	5	54

Steel (black coating finishing) Materials • Steel
• Surface Treatment: Black Coated Finishing

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0673	TK19-U3B	¥185	¥200	2	19	28	27	6.5	3	5	20
482-0681	TK19-U4B	¥194	¥210	2	19	53	27	6.5	4	5	27
482-0690	TK19-U5B	¥231	¥250	2	19	78	27	6.5	5	5	33
482-0711	TK19-U6B	¥278	¥300	2	19	103	27	6.5	6	5	40
482-0703	TK19-U6AB	¥287	¥310	2	19	53	52	6.5	6	5	40
482-0720	TK19-U7AB	¥296	¥320	2	19	78	52	6.5	7	5	47
482-0738	TK19-U8AB	¥306	¥330	2	19	103	52	6.5	8	5	54

Stainless Steel Materials • Stainless Steel (SUS304)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1961	TK19-U3S	¥287	¥310	2	19	28	27	6.5	3	5	19
283-1970	TK19-U4S	¥306	¥330	2	19	53	27	6.5	4	5	25
283-1988	TK19-U5S	¥352	¥380	2	19	78	27	6.5	5	5	32
283-1996	TK19-U6S	¥426	¥460	2	19	103	27	6.5	6	5	39
283-2003	TK19-U6AS	¥435	¥470	2	19	53	52	6.5	6	5	38
287-9042	TK19-U7AS	¥500	¥540	2	19	78	52	6.5	7	5	45
287-9051	TK19-U8AS	¥555	¥600	2	19	103	52	6.5	8	5	51

Contact us:0120-509-849 <http://www.orange-book.com/>

Item No.	Hole Pitch (mm)
TK19-U3C	-
TK19-U4C to TK19-U8AC	25
TK19-U3B	-
TK19-U4B to TK19-U8AB	25
TK19-U3S	-
TK19-U4S to TK19-U8AS	25