


Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

## "Joint Metal Fitting 19 Type C"

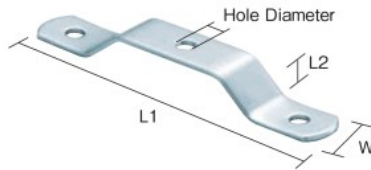

TK19-C3C (steel)



TK19-C3B (steel (black coating finishing))



TK19-C6S (stainless steel)

Item No.	Hole Pitch (mm)
TK19-C3C	-
TK19-C4C·TK19-C6C	25
TK19-C3B	-
TK19-C4B·TK19-C6B	25
TK19-C3S	-
TK19-C4S·TK19-C6S	25

- Features**
- It is small, lightweight, compact, and has high rigidity, and can be used as a multi-purpose tool for each type of joint, reinforcing, and connection.
  - A simple and versatile combination.
- Use**
- Connecting metal fitting.
  - Car parts mounting metal fitting.
- Origin**
- Japan

**Steel** Materials •Steel •Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-0841	TK19-C3C	¥278	¥300	2	19	118	13.5	6.5	3	10	34
283-0850	TK19-C4C	¥306	¥330	2	19	143	13.5	6.5	4	10	41
283-0868	TK19-C6C	¥314	¥340	2	19	193	13.5	6.5	6	10	55

**Steel (black coating finishing)** Materials •Steel •Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0363	TK19-C3B	¥278	¥300	2	19	118	13.5	6.5	3	10	34
482-0371	TK19-C4B	¥306	¥330	2	19	143	13.5	6.5	4	10	41
482-0401	TK19-C6B	¥314	¥340	2	19	193	13.5	6.5	6	10	55

**Stainless Steel** Materials •Stainless Steel (SUS304)


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-0922	TK19-C3S	¥389	¥420	2	19	118	13.5	6.5	3	10	33
283-0931	TK19-C4S	¥389	¥420	2	19	143	13.5	6.5	4	10	40
283-0949	TK19-C6S	¥500	¥540	2	19	193	13.5	6.5	6	10	52

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

## "Joint Metal Fitting 19 Type C"

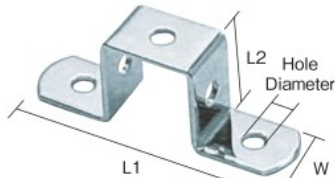

TK19-C5AC (steel)



TK19-C5AB (steel (black coating finishing))



TK19-C7AS (stainless steel)

Item No.	Hole Pitch (mm)
TK19-C5AC	-
TK19-C6AC to TK19-C8AC	25
TK19-C5AB	-
TK19-C6AB to TK19-C8AB	25
TK19-C5AS	-
TK19-C6AS to TK19-C8AS	25

- Features**
- It is small, lightweight, compact, and has high rigidity, and can be used as a multi-purpose tool for each type of joint, reinforcing, and connection.
  - A simple and versatile combination.
- Use**
- Connecting metal fitting.
  - Car parts mounting metal fitting.
- Origin**
- Japan

**Steel** Materials •Steel •Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-0876	TK19-C5AC	¥278	¥300	2	19	78	28	6.5	5	5	33
283-0884	TK19-C6AC	¥278	¥300	2	19	104	28	6.5	6	5	40
283-0892	TK19-C7AC	¥334	¥360	2	19	129	28	6.5	7	5	47
287-9034	TK19-C8AC	¥324	¥350	2	19	154	28	6.5	8	5	53

**Steel (black coating finishing)** Materials •Steel •Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0380	TK19-C5AB	¥278	¥300	2	19	78	28	6.5	5	5	33
482-0398	TK19-C6AB	¥278	¥300	2	19	104	28	6.5	6	5	40
482-0410	TK19-C7AB	¥334	¥360	2	19	129	28	6.5	7	5	47
482-0428	TK19-C8AB	¥324	¥350	2	19	154	28	6.5	8	5	53

**Stainless Steel** Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-0957	TK19-C5AS	¥389	¥420	2	19	78	28	6.5	5	5	32
283-0965	TK19-C6AS	¥435	¥470	2	19	104	28	6.5	6	5	38
283-0973	TK19-C7AS	¥463	¥500	2	19	129	28	6.5	7	5	45
283-0981	TK19-C8AS	¥509	¥550	2	19	154	28	6.5	8	5	51

Contact us:0120-509-849 <http://www.orange-book.com/>

- Door Closers
- Door Stoppers
- Hinges
- Slide Bolt Latches
- Catches
- Handles
- Keys
- Chains
- Wire Ropes
- Metal Fittings for Handling
- Suspension Metal Fittings
- Shelf Peg Metal Fittings
- Joint Fittings
- Steel Wires
- Wire Nets
- Inspection Doors, Air Inlet/Outlets
- Handrails, Slopes
- Corrugated Plates
- Plastic Materials
- Metal Materials
- Construction Materials
- Sash Rollers
- Door Hangers