

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers

TRUSCO

TRUSCO

Stock


38,650 Items

Joint Plate

Com Chemical Content Inspection

Com Drawing

- Features** • It is used for various usages such as a mount or supports for pipes, or others by combination.
- Use**
- Connecting metal fitting.
 - Car parts mounting metal fitting.
- Specs**
- Hole Pitch: 25mm
- Origin**
- Japan

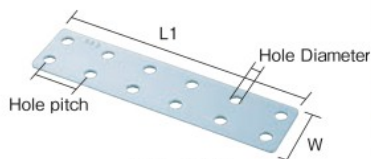

TKA-140C (steel)



TKA-140B (steel (black coating finishing))



TKA-140S (stainless steel)

Steel

Materials • Steel • Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1155	TKA-40C	¥269	¥290	2	34	40	6.5	4	5	20
283-1163	TKA-90C	¥342	¥370	2	34	90	6.5	8	5	43
283-1171	TKA-140C	¥417	¥450	2	34	140	6.5	12	5	69

Steel (black coating finishing)

Materials • Steel • Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0932	TKA-40B	¥269	¥290	2	34	40	6.5	4	5	20
482-0959	TKA-90B	¥342	¥370	2	34	90	6.5	8	5	43
482-0916	TKA-140B	¥417	¥450	2	34	140	6.5	12	5	69

Stainless Steel

Materials • Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1228	TKA-40S	¥296	¥320	2	34	40	6.5	4	5	18
283-1236	TKA-90S	¥407	¥440	2	34	90	6.5	8	5	42
283-1244	TKA-140S	¥500	¥540	2	34	140	6.5	12	5	65

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO

TRUSCO


Stock

38,650 Items

"Joint Bracket L"

Com Drawing

- Features** • Easy and fine adjustment is possible even after temporarily attaching in advance when installing equipment.
- Use**
- Extensible adjustments are possible with a single screwdriver.
 - Connecting metal fitting.
 - Car parts mounting metal fitting.
- Origin**
- Japan

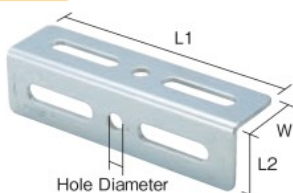

TK27-L4C (steel)



TK27-L4B (steel (black coating finishing))



TK27-L4S (stainless steel)

Steel

Materials • Steel • Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-0914	TK27-L4C	¥334	¥360	2.3	27	100	27	7.0	6	20	74
283-0906	TK46-L4C	¥694	¥750	3.2	46	130	46	8.5	6	20	227

Steel (black coating finishing)

Materials • Steel • Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0851	TK27-L4B	¥334	¥360	2.3	27	100	27	7.0	6	20	74
482-0908	TK46-L4B	¥694	¥750	3.2	46	130	46	8.5	6	20	227

Stainless Steel

Materials • Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1082	TK27-L4S	¥546	¥590	2	27	100	27	7.0	6	20	61
283-1074	TK46-L4S	¥1,342	¥1,450	3	46	130	46	8.5	6	20	224

Contact us:0120-509-849 <http://www.orange-book.com/>

Item No.	Long hole diameter (mm)
TK27-L4C	7.0 x 30
TK46-L4C	8.5 x 35
TK27-L4B	7.0 x 30
TK46-L4B	8.5 x 35
TK27-L4S	7.0 x 35
TK46-L4S	8.5 x 35