

Door Rollers (for wooden fittings)

Stock 276Items

2-1077

Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items

Bearing Door Roller Round Type (U-shaped frame)

.Com Drawing




THS-15-30M

Round Type



- Use • Indoor wooden fittings. (for core rail)
 Materials • **Frame: Stainless Steel (SUS304)**
 • **Wheel: Stainless steel (with 626ZZ bearing)**
 Origin • China

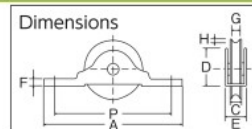

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Wheel Diameter (mm)	A (mm)	P (mm)	C (mm)	D (mm)	E (mm)	F (mm)	G (mm)	H (mm)	Load Capacity (kg) when 2 pieces used	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-2560	THS-15-30M	¥2,777	¥3,000	30	68	57	8.6	20	14	5.0	6.0	2.5	35	2	6	114
285-2578	THS-15-36M	¥3,981	¥4,300	36	76	66	8.6	20	14	5.0	6.0	2.5	40	2	6	154
285-2586	THS-15-42M	¥4,906	¥5,300	42	101	85	9.0	30	14	5.5	6.5	2.5	45	2	6	240

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

Bearing Roller Type Flat Type (U-shaped frame)

.Com Drawing




THS-15-30F

Flat Type



- Use • Indoor wooden fittings. (for silling)
 Materials • **Frame: Stainless Steel (SUS304)**
 • **Wheel: Stainless steel (with 626ZZ bearing)**
 Origin • China

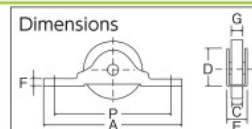

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Wheel Diameter (mm)	A (mm)	P (mm)	C (mm)	D (mm)	E (mm)	F (mm)	G (mm)	H (mm)	Load Capacity (kg) when 2 pieces used	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-2535	THS-15-30F	¥2,777	¥3,000	30	68	57	8.5	20	14	5.0	8.6		35	2	6	130
285-2543	THS-15-36F	¥3,981	¥4,300	36	76	66	8.5	20	14	5.0	8.6		40	2	6	172
285-2551	THS-15-42F	¥4,906	¥5,300	42	101	85	9.0	30	14	5.5	9.0		45	2	6	260

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

Bearing Door Roller Type Flat Type (flat plate frame)

.Com Drawing




THS-25-30M

Round Type



- Use • Indoor wooden fittings. (for core rail)
 Materials • **Frame: Stainless Steel (SUS304)**
 • **Wheel: Polyacetal Resin (626ZZ bearing included)**
 Origin • China

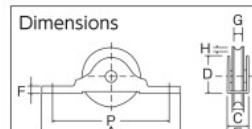

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Wheel Diameter (mm)	A (mm)	P (mm)	C (mm)	D (mm)	E (mm)	F (mm)	G (mm)	H (mm)	Load Capacity (kg) when 2 pieces used	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-2641	THS-25-30M	¥1,296	¥1,400	30	68	57	9	18	14	1.5	6.5	2.5	30	2	10	62
285-2659	THS-25-35M	¥1,666	¥1,800	35	76	66	9	21	14	1.5	6.5	2.5	35	2	10	76

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

 
Bearing Door Roller Round Type (U-shaped frame)

.Com Drawing




THS-10-30M

Round Type



- Use • Indoor wooden fittings. (for core rail)
 Materials • **Frame: Stainless Steel (SUS304)**
 • **Wheel: Polyacetal Resin (626ZZ bearing included)**
 Origin • China

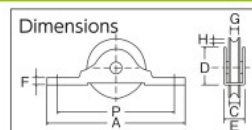

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Wheel Diameter (mm)	A (mm)	P (mm)	C (mm)	D (mm)	E (mm)	F (mm)	G (mm)	H (mm)	Load Capacity (kg) when 2 pieces used	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-2691	THS-10-30M	¥2,592	¥2,800	30	68	57	9	20	14	5.0	6.5	2.5	35	2	6	70
285-2705	THS-10-35M	¥2,870	¥3,100	35	76	66	9	20	14	5.0	6.5	2.5	40	2	6	80
285-2713	THS-10-45M	¥4,166	¥4,500	45	101	85	9	30	14	5.5	6.5	2.5	45	2	6	130

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

Bearing Roller Type Flat Type (flat plate frame)

.Com Drawing




THS-25-30F

Flat Type



- Use • Indoor wooden fittings. (for silling)
 Materials • **Frame: Stainless Steel (SUS304)**
 • **Wheel: Polyacetal Resin (626ZZ bearing included)**
 Origin • China

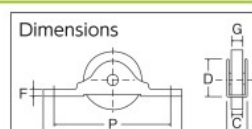

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Wheel Diameter (mm)	A (mm)	P (mm)	C (mm)	D (mm)	E (mm)	F (mm)	G (mm)	H (mm)	Load Capacity (kg) when 2 pieces used	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-2624	THS-25-30F	¥1,296	¥1,400	30	68	57	9	18	14	1.5	9.0		30	2	10	66
285-2632	THS-25-35F	¥1,666	¥1,800	35	76	66	9	21	14	1.5	9.0		35	2	10	80

Contact us: 0120-509-849 <http://www.orange-book.com/>

Hardware

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Self Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers